



Middle Atlantic Products

EXCEPTIONAL SUPPORT & PROTECTION™

96-01050 / rev 1e / 07-21-11

LT-1Rx Rackmount Lights



EIA Compliant

Rackmount lights provide ambient lighting for front and rear of rackmount components

Features

- Retractable LED light shelf
- Dimmable LED light bar provides evenly distributed illumination for component viewing
- Constructed of 18-gauge steel
- Available in durable flat black powder coat or a black brushed and anodized finish
- 2 rear USB style output ports for connection of LED gooseneck work lights
- Aesthetically pleasing dimmable LED logo optional (LT-1RA)
- UL Listed plug-in power supply



(LT-1R) Front View



(LT-1RA) Front View



Rear View



Architects' and Engineers' Specifications

Rackmount light shall be Middle Atlantic Products model # LT-1RX (X = finish, refer to chart). One rackspace rackmount light shall contain retractable light shelf with LED light bar containing a total of ten white and amber lights for color balance. Rackmount light shall include front mounted dimmer knob (LT-1R only). Hidden dimmer switches to control logo and light brightness on bottom of retractable light shelf (LT-1RA). Light shelf shall extend and light bar shall illuminate automatically when pressed. Rackmount light shall have ball bearing slides for retractable light shelf and shall have a weight capacity of 20 lbs. Rackmount light shall be constructed of 18-gauge steel. Unit shall provide two rear USB style, 5 volt DC output ports for use with optional gooseneck LED light. Rackmount light shall be RoHS EU Directive 2002/95/EC compliant. Rackmount light shall be warranted to be free from defects in material or workmanship under normal use and conditions for a period of 3 years.

OPTIONS

- Rear Gooseneck light shall be Middle Atlantic Products model # LT-GN



LT-GN

CUSTOMIZABLE SPECIFICATION CLIPS AVAILABLE AT MIDDLEATLANTIC.COM



LT-1R Series basic dimensions

All dimensions in inches [Bracketed dimensions in millimeters]




TOP VIEW

(LT-1R shown)

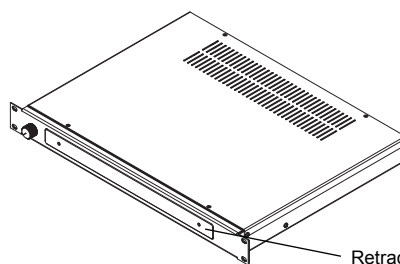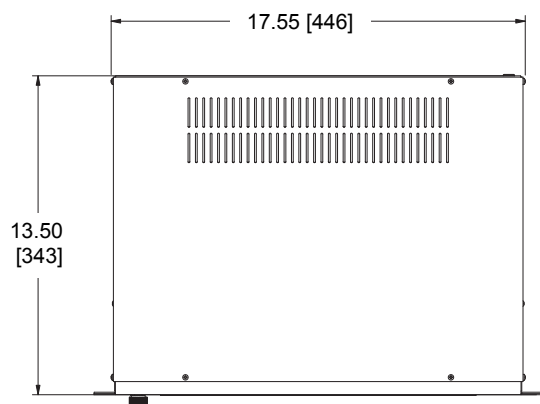

LT-1R

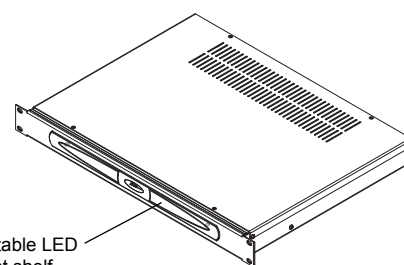


LT-1RA

(Includes hidden dimmer switches to adjust brightness of logo and light)

FRONT VIEW


(LT-1R shown)

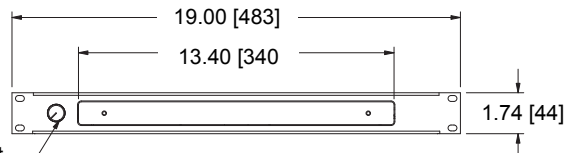

FRONT VIEW

(LT-1RA)

 Light
dimmer
control



REAR VIEW

 
Dimmable LED
logo



USB ports for
gooseneck light,
part # LT-GN

SIDE VIEW

(LT-1R shown)



SIDE VIEW, OPEN POSITION



Model #	Finish
LT-1R	Flat black powder coat
LT-1RA	Black brushed and anodized