



**Middle Atlantic Products**

EXCEPTIONAL SUPPORT & PROTECTION™

96-01120 / rev. 1c / 07-27-10

# RM-LCD Series LCD Rackmount




**EIA/TIA Compliant**

**LCD Rackmount available in three styles to mount monitors up to 32"**

## Features


- Mounts monitors with VESA 75 and VESA 100 patterns
- Adjustable depth allows for recessing of monitor
- Models with a flat plate, tilt and telescoping arm available
- Models with flat plate and knuckle mount most monitors up to 20", depending on overall size
- Model with telescoping arm mounts monitors up to 32"

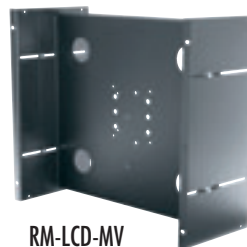

RM-LCD-MV



RM-LCD-MK

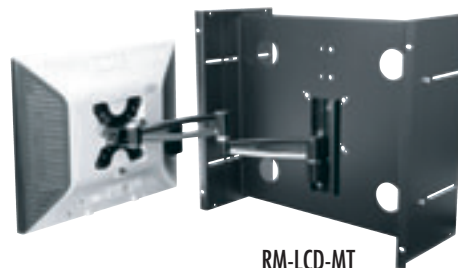

RM-LCD-MT



RM-LCD-PNLV



RM-LCD-PNLK

## Architects and Engineers' Specifications


EIA Compliant 19" LCD Rackmount shall be Middle Atlantic Products model # RM-LCD-(MV and PNLV for flat plate, MK and PNLK for tilt, MT for Telescoping arm). RM-LCD shall accept monitors with a VESA 75 or 100 mounting pattern. RM-LCD shall have a weight capacity of 35 lbs. for MV, MK and MT models and 27 lbs. for PNLV and PNLK models. RM-LCD shall have a durable black powder coat finish. RM-LCD shall be constructed from 16-gauge steel. RM-LCD shall recess from 2" to 9" from the face of the rackrail. RM-LCD-MT and RM-LCD-PNLK shall tilt 160°. RM-LCD-MK shall have an arm with a range of 2.5" to 16.5". RM-LCD-(MV, MT, PNLV, PNLK) shall accept monitors of up to 20", with an overall width of no more than 17.38". RM-LCD-MK shall accept monitors of up to 32". RM-LCD shall be GREENGUARD Indoor Air Quality Certified for Children and Schools. RM-LCD shall be RoHS EU Directive 2002/95/EC Compliant. RM-LCD shall be manufactured by an ISO 9001 and ISO 14001 registered company. RM-LCD shall be warranted to be free from defects in material and workmanship under normal use and conditions for the lifetime of the product.

96-01120 / rev. 1c / 07-27-10 / RM-LCD Series LCD Rackmount




**CUSTOMIZABLE SPECIFICATION CLIPS AVAILABLE AT MIDDLEATLANTIC.COM**

US: New Jersey • California • Illinois • Voice: 973-839-1011 Fax: 973-839-1976 • middleatlantic.com  
Canada: Ontario • British Columbia • Voice: 613-836-2501 Fax: 613-836-2690 • middleatlantic.ca





## RM-LCD Series LCD Rackmount dimensions

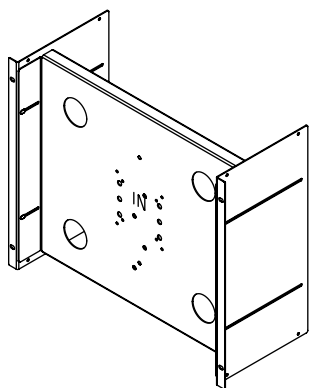



**RM-LCD-MV**

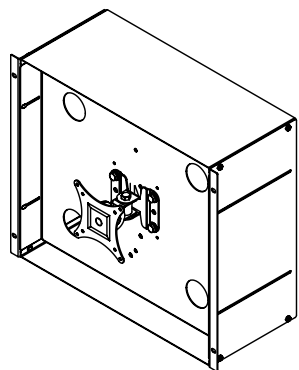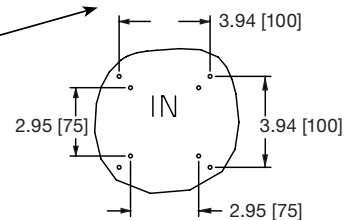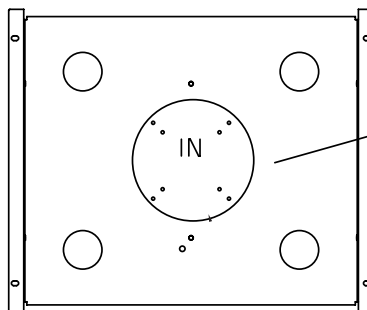

**RM-LCD-MK**

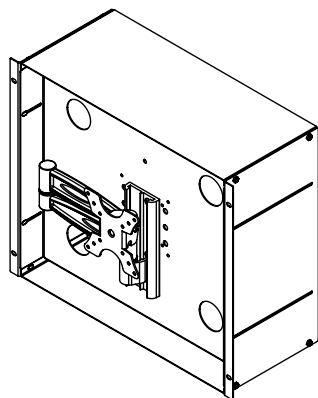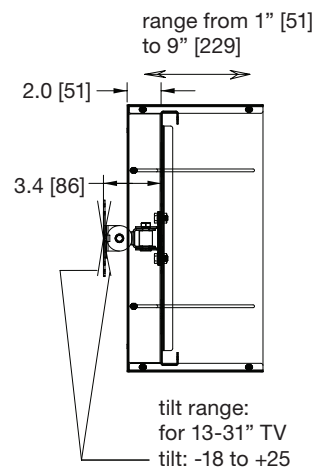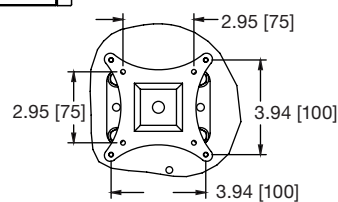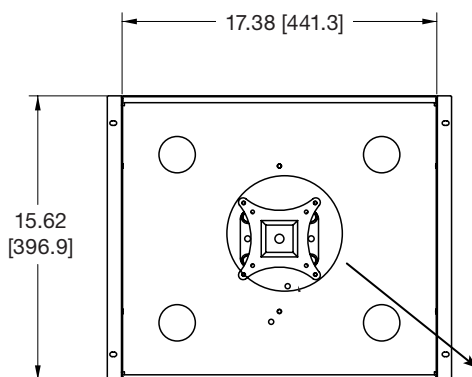




**RM-LCD-MT**

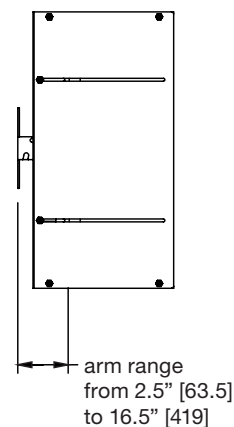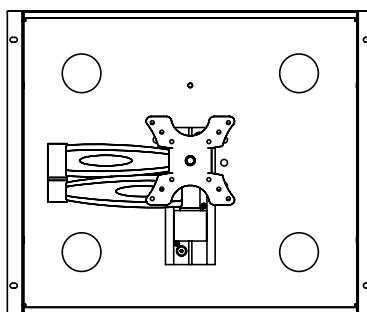



All dimensions in inches unless otherwise noted [All dimensions in brackets are in millimeters]

## RM-LCD-PNLV dimensions





All dimensions in inches unless otherwise noted [All dimensions in brackets are in millimeters]

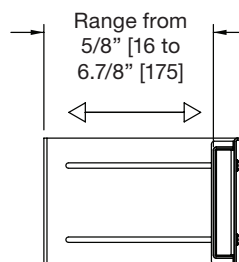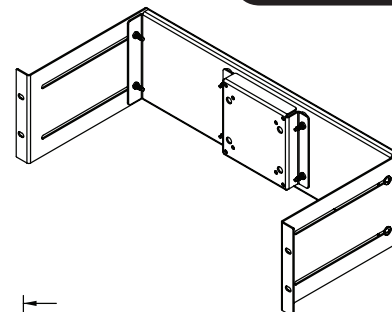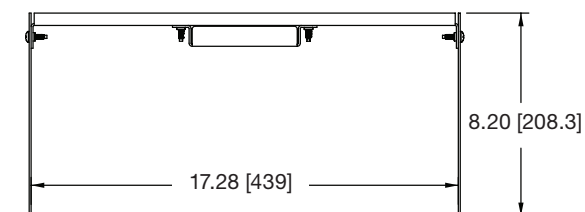

SECTION B

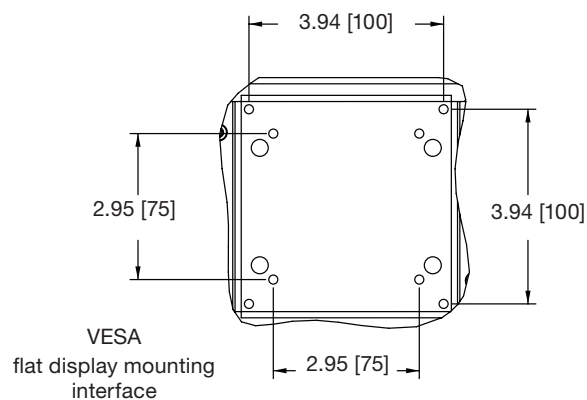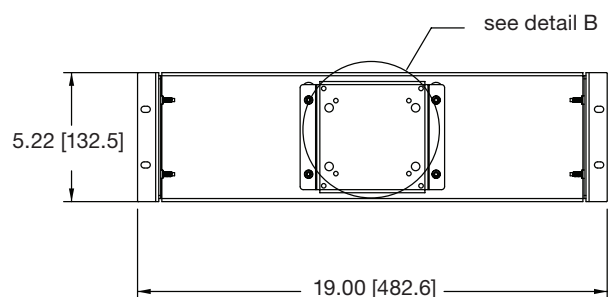






### REVERSED MOUNTING PAD

 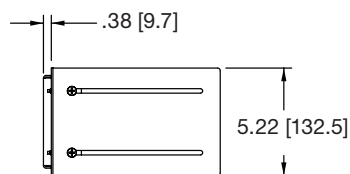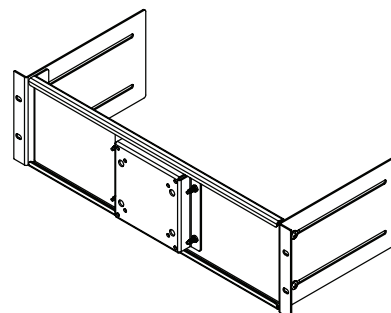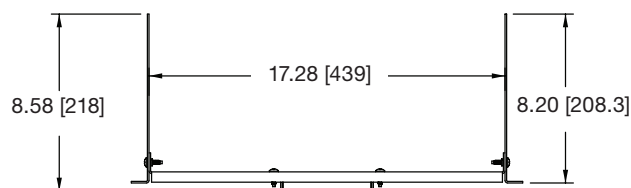

reversed mount allows monitor to protrude .38

## RM-LCD-PNLK dimensions

All dimensions in inches unless otherwise noted [All dimensions in brackets are in millimeters]

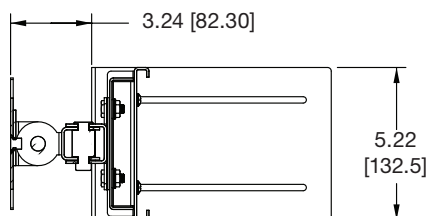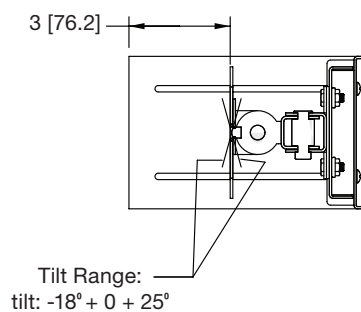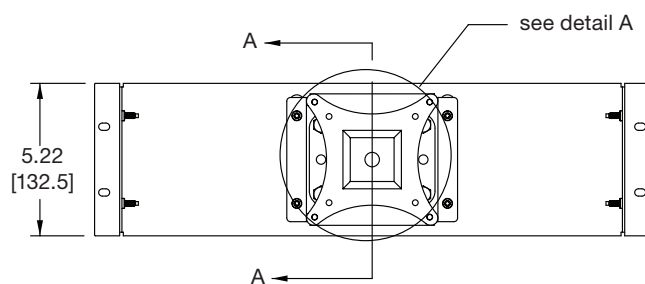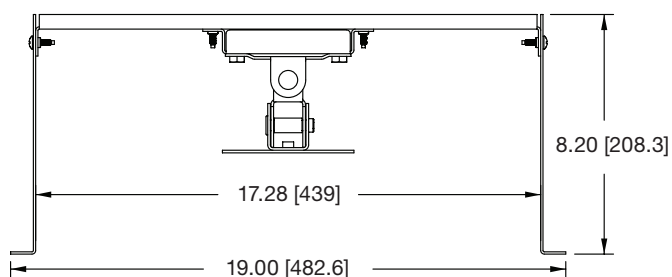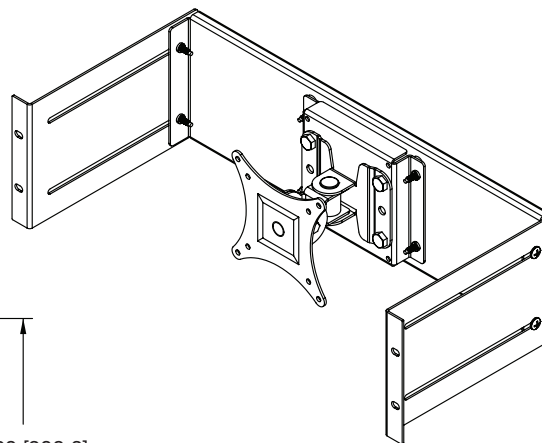

SECTION A-A

