

SCV-3120



1/4" High Resolution 12x WDR Vandal-Resistant
Dome Camera



Key Features

- High resolution of 600TV lines (Color), 700TV lines (B/W)
- Min. illumination 0.7Lux@F1.65 (Color), 0.07Lux (B/W)
- Powerful 12x zoom (3.69 ~ 44.32mm), digital 16x
- WDR, VPS, True Day / Night (ICR), Intelligent video, MD
- IP66, Coax : CCVC, RS-485
- Dual power, 24V AC & 12V DC


Accessories (Optional)



SCX-300WM SCX-300CM SCX-300HM SCX-300LM SCX-300PM SCX-300KM

Dimensions

Unit : mm (inch)

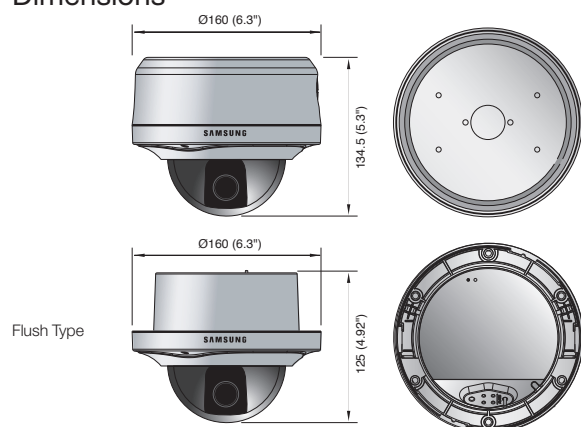

Flush Type

Technical Specifications

	SCV-3120N	SCV-3120P
VIDEO		
Imaging Device	1/4" Double scan CCD	
Total Pixels	811(H) x 508(V)	795(H) x 596(V)
Effective Pixels	768(H) x 494(V)	752(H) x 582(V)
Scanning System	2 : 1 Interlace	
Synchronization	Internal	
Frequency	H : 15.734KHz / V : 59.94Hz	H : 15.625KHz / V : 50Hz
Horizontal Resolution	Color : 600TV lines, B/W : 700TV lines	
Min. Illumination	Color : 0.7Lux@F1.65 (50IRE), 0.001Lux (Sens-up, 512x) B/W : 0.07Lux@F1.65 (50IRE), 0.0001Lux (Sens-up, 512x)	
S / N Ratio	52dB (AGC off, Weight on)	
Video Output	CVBS : 1.0 Vp-p / 75Ω composite	
LENS		
Focal Length (Zoom Ratio)	3.69 ~ 44.32mm (12x)	
Max. Aperture Ratio	1 : 1.65(Wide) ~ 3.7(Tele)	
Angular Field of View	H : 54.44°(Wide) ~ 4.64°(Tele) / V : 41.42°(Wide) ~ 3.52°(Tele)	
Min. Object Distance	1m (3.28ft)	
Focus Control	Auto / Manual / One-AF	
Zoom Movement Speed	1.9sec (Wide to tele)	
PAN / TILT		
Pan Range	0° ~ 355°	
Tilt Range	0° ~ 90°	
Rotate Range	0° ~ 355°	
OPERATIONAL		
On Screen Display	English, Japanese, Spanish, French, Portuguese, Taiwanese, Korean	English, French, German, Spanish, Italian, Chinese, Russian, Polish, Czech, Romanian, Serbian, Swedish, Danish, Turkish, Portuguese
Camera Title	Off / On (Displayed 54 characters)	
Day & Night	Day / Night / Auto / Ext	
Backlight Compensation	Off / On (Area setting)	
Wide Dynamic Range	128x (52dB)	160x (52dB)
Contrast Enhancement	XDR (Off / Low / Mid / High)	
Digital Noise Reduction	Adaptive 3D+2D (Off / Low / Mid / High / User)	
Digital Image Stabilization	Off / On	
Motion Detection	Off / Tracking / Detection	
Privacy Masking	Off / On (12 programmable zones with polygonal masking)	
Sens-up (Frame Integration)	2x ~ 512x	
Gain Control	Off / On	
White Balance	ATW1 / ATW2 / AWC (Manual) / 3200K / 5600K	
Electronic Shutter Speed	1/60 ~ 1/120,000sec	1/50 ~ 1/120,000sec
Digital Zoom	Off / On (1x ~ 16x)	
Profile	Standard / ITS / Backlight / Day & Night / Gaming / Custom	
VPS	Off / On	
Intelligent Video	Fixed / Moved	
PIP	Off / On	
Alarm	1 Out	
Communication	Coaxial control, RS-485	
Protocol	Coax : CCVC RS-485 : Samsung-T/E, Pelco-D/P, Panasonic, Bosch, Honeywell, Vicon	
ENVIRONMENTAL		
Operating Temperature / Humidity	-50°C ~ +50°C (-58°F ~ +122°F) / Up to 100% RH	
Ingress Protection	IP66	
ELECTRICAL		
Input Voltage	Dual (24V AC & 12V DC ±10%)	
Power Consumption	Max. 6W	
MECHANICAL		
Color / Material	Light gray / Aluminum	
Dome Cover	Polycarbonate / Clear	
Dimensions (WxH)	Ø160.0 x 134.5mm (Ø6.3" x 5.3")	
Weight	1.28Kg (2.82 lb)	