

SPC-1010

PTZ Control Keyboard



Technical Specifications

		SPC-1010
LCD Display		16 x 2 character LCD
Speed Control		Joystick (3-axis twist zoom)
Protocol	PTZ	Samsung-T/E, Pelco-D/P, Panasonic, Vicon, AD, Honeywell
	Receiver	Samsung-T
Control Capacity		Up to 255 Cameras (Suitable for Mid-, Large- size system)
Communications	Standards	RS-485/422 (Remote control : 1Km)
	Transfer Speed	2,400 ~ 57,600bps
Voltage		12V DC, 140mA
Operating Temperature		0°C ~ +45°C (+32°F ~ +113°F)
Operating Humidity		10% ~ 70%
Dimensions (WxHxD)		280.0 x 100.0 x 180.0mm (10.63" x 3.94" x 7.09")
Weight		Approx. 0.7Kg (1.54 lb) (Without adapter)


CONTROLLER

Key Features


- Control up to 255 PTZ cameras
- Superior system compatibility : Multi protocols support
- OSD menu, 3D joystick control
- RS-485 and RS-422 compatibility

Dimensions

Unit : mm (inch)

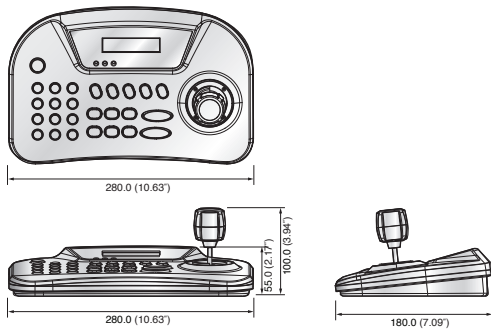

System Configuration

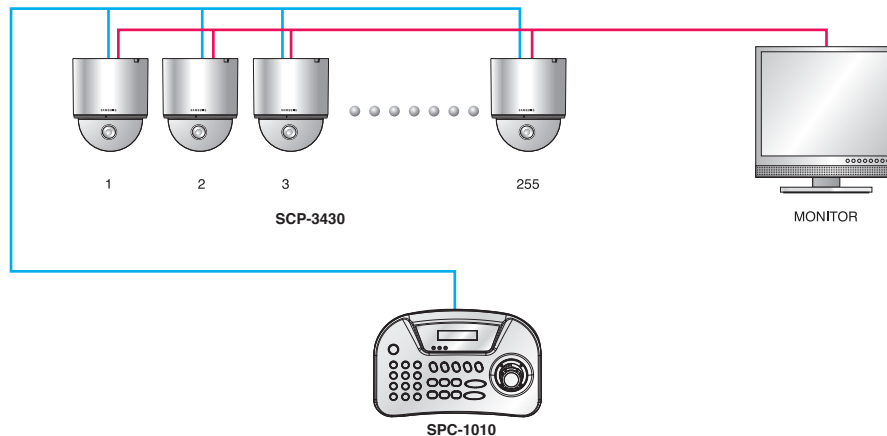

— Video Line
 — Control Line : RS-485/422