


SPE-400B/1600R

4CH Network Video Encoder
(Blade Type) / Extension Rack

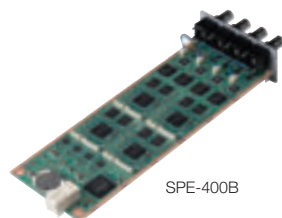

SPE-400B



SPE-1600R

4CH

16CH


4CIF

Key Features


- Max. 30(25)fps at 4CIF resolution
- H.264, MPEG-4, MJPEG multiple codec
- Multiple streaming simultaneously
- 10/100/1000BASE-T
- SPE-1600R : extension rack, 4 slots for SPE-400B

Dimensions

Unit : mm (inch)

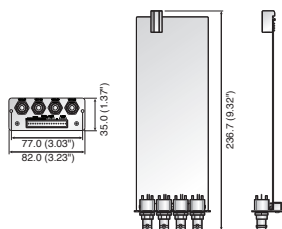

SPE-400B

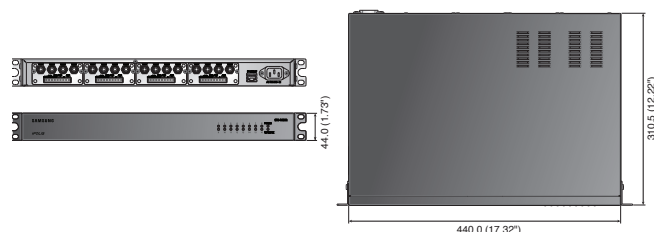

SPE-1600R

Technical Specifications

	SPE-400BN		SPE-400BP	
OPERATIONAL				
Video In	4 CVBS : 1.0 Vp-p / 75Ω composite, NTSC/PAL auto detection			
De-interlacing Filter	Built-in			
Event Trigger	Motion detection, Alarm input, Video loss			
Alarm I/O	Input 4ea / Output 4ea (Relay)			
Remote Control Interface	4ea RS-485 (Half duplex)			
RS-485 Protocol	Samsung-T/E, Pelco-P/D			
NETWORK				
Ethernet	RJ-45 (10/100/1000BASE-T)			
Video Compression Format	H.264, MPEG-4, MJPEG			
Resolution	704 x 480, 640 x 480, 352 x 240, 320 x 240		704 x 576, 640 x 480, 352 x 288, 320 x 240	
Max. Framerate	30fps per channel		25fps per channel	
Video Quality Adjustment	H.264, MPEG-4 : Compression level, Target bitrate level control			
	MJPEG : Quality level control			
Bitrate Control Method	H.264, MPEG-4 : CBR or VBR, MJPEG : VBR			
Streaming Capability	Multiple streaming (Up to 10 profiles)			
IP	IPv4, IPv6			
Protocol	TCP/IP, UDP/IP, RTP(UDP), RTP(TCP), RTSP, NTP, HTTP, HTTPS, SSL, DHCP, PPPOE FTP, SMTP, ICMP, IGMP, SNMPV1/V2C/V3(MIB-2), ARP, DNS, DDNS, ONVIF			
Security	HTTPS(SSL) login authentication, Digest login authentication			
	IP address filtering, User access log			
Streaming Method	Unicast / Multicast			
Max. User Access	10 users at unicast mode			
ONVIF Conformance	Yes			
Web Viewer	Supported OS : Windows XP / VISTA / 7, MAC OS			
	Supported Browser : Internet Explorer 6.0 or Higher, Firefox, Google Chrome, Apple Safari			
Central Management Software	NET-i viewer			
ENVIRONMENTAL				
Operating Temperature / Humidity	0°C ~ +40°C (+32°F ~ +104°F) / 20% ~ 80% RH			
ELECTRICAL				
Input Voltage / Current	5V DC			
Power Consumption	Max. 11W			
MECHANICAL				
Color / Material	Black / Metal			
Dimensions (WxHxD)	210.2 x 82.0 x 35.0mm (8.27" x 3.23" x 1.38")			
Weight	165.9g (0.37 lb)			

SPE-1600R

CONNECTION	
Expansion Slots	4 Slots for SPE-400B
Connector	RJ-45 (10/100/1000BASE-T)
ENVIRONMENTAL	
Operating Temperature	0°C ~ +40°C (+32°F ~ +104°F)
Operating Humidity	20% ~ 80% RH
ELECTRICAL	
Input Voltage	100 ~ 240V AC ±10%, 50/60Hz / 0.5A
Power Consumption	Max. 50W (with SPE-400B x 4)
MECHANICAL	
Color / Material	Black / Metal
Dimensions (WxHxD)	478.0 x 310.5 x 44.0mm (18.82" x 12.22" x 1.73")
Weight	3Kg (6.61 lb)