

Weather/Vandal Resistant Intense Light Miniature Color Camera with 3mm Fixed Lens



CVC61iLTB
CVC61iLTW

3mm fixed lens, black housing

3mm fixed lens, white housing

Features

- Day & night camera without using IR's
- 1/3" Sony Super-HAD™ CCD
- 600 TV lines super high resolution
- Compact Size - Only 1.89" in diameter!
- Vandal resistant housing
- Cast aluminum construction
- Integrated 3mm fixed lens
- Extreme low light functionality
- IP66 rated
- 5 year warranty




Shown at actual size

Specifications

Image Sensor	1/3" Sony Super-HAD™ CCD
Resolution.....	600 TV lines
Sensitivity	0.00001 lux
Effective Pixels	768 (H) x 494 (V)
Electronic Shutter Speed.....	Auto (1/60 sec. - 1/100,000 sec.)
Scanning System.....	2:1 interlace
Synchronization	Internal
Video Output.....	1.0Vp-p / 75 Ohm
S/N Ratio	>52dB (AGC Off)
Gain Control	Auto
White Balance	Auto
Sense-Up.....	Auto (x32)
IP Rating.....	IP66
Operating Temperature.....	-14° F - 120° F
Power Supply	12VDC (power supply not included)
Power Consumption	120mA max.
Dimensions.....	1.89" (W) x 1.46" (H) x 1.89" (D)
Weight	4 oz.

Perfect for use in all vehicles or anywhere that a miniature, aesthetically pleasing, high resolution camera is desired.

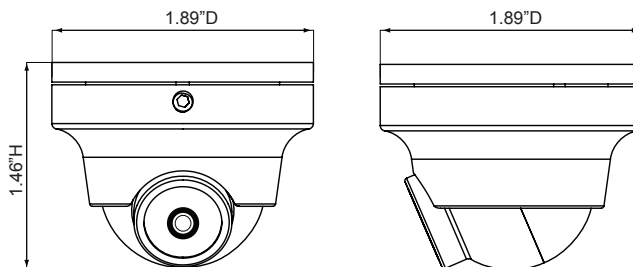

Optional Accessory



PSW5
Power Supply

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.

Rev. 1/18/12

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
www.specotech.com