

Weather/Vandal Resistant Miniature Color Camera with 4.3mm Fixed Lens

CVC62HRB CVC62HRW

4.3mm fixed lens, black housing

4.3mm fixed lens, white housing

Features

- 1/3" Sony Super-HAD™ CCD
- 540 TV lines super high resolution
- Compact Size - Only 1.89" in diameter!
- Vandal resistant housing
- Cast aluminum construction
- Integrated 4.3mm fixed lens
- Impressive picture quality
- IP66 rated
- 12VDC required




Shown at actual size

Perfect for use in all vehicles or anywhere that a miniature, aesthetically pleasing, high resolution camera is desired.

Specifications

Image Sensor	1/3" Sony Super-HAD™ CCD
Resolution.....	540 TV lines
Sensitivity	0.1 lux
Effective Pixels	768 (H) x 594 (V)
Electronic Shutter Speed.....	Auto (1/60 sec. - 1/120,000 sec.)
Scanning System.....	2:1 interlace
Synchronization.....	Internal
Frequency.....	15.734KHz (H) / 60Hz (V)
Video Output.....	1.0Vp-p / 75 Ohm
S/N Ratio	>50dB (AGC Off)
Gain Control	Auto
White Balance	Auto
IP Rating.....	IP66
Operating Temperature.....	-14° F - 120° F
Power Supply	12VDC required
Power Consumption	120mA max.
Dimensions.....	1.46" (H) x 1.89" (D)
Weight	4 oz.

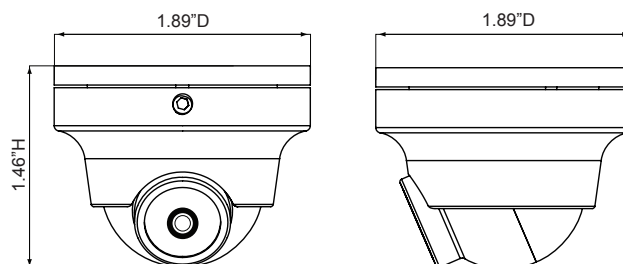

Optional Accessory



PSW5
Power Supply

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.

Rev. 7/14/11

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
www.specotech.com