

HT7246iHR
HT7247iHR
HT7250iHR

2.8 - 12mm auto iris varifocal lens dark grey housing

9 - 22mm auto iris varifocal lens dark grey housing

5 - 50mm auto iris varifocal lens dark grey housing


Features

- 650 lines of color resolution
- Amplify existing light with no distance limitations
- No problems caused by objects that reflect or absorb IR light sources
- Minimum illumination 0.00002 lux (Intensifier3™ @ 512x)
- Chameleon Cover: Snap-on cover converts the housing from standard dark grey to decorator white and can be painted to match any décor.
- 12VDC / 24VAC dual voltage operation
- Full OSD operation
- Wall or ceiling mount
- S/N Ratio more than 52dB (weight on)
- Weather resistant operation
- EZ mount system simplifies installation
- Relay outputs for motion detection
- 5 year warranty

Now with Presets:
Outdoor, Indoor, Elevator,
Lobby, Hallway & Dark



Shown with included paintable,
snap-on Chameleon™ cover

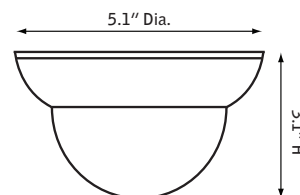

Specifications

Image Sensor	1/3" Sony Super-HAD II™ CCD
Resolution	650 TV lines
Minimum Illumination	CDS Off: 0.15 lux CDS On: 0.00002 lux
Effective Pixels	768 (H) x 494 (V)
Total Pixels	811 (H) x 508 (V)
TV System	NTSC, PAL
Scanning Frequency	15.734KHz (H) & 59.94Hz (V)
Scanning System	2:1 interlace
Synchronization	Internal
S/N Ratio	More than 52dB
Video Output	CVBS: 1.0Vp-p / 75 Ohm
Electronic Shutter Speed	1/60 sec. - 1/120,000 sec.
OSD	Available
WDR	On / Off (level adjustable)
Backlight Compensation	BLC / HLC / Off
Day & Night	Color / BW / Auto
Gain Control	High / Low / Off
White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700°K - 11,000°K)
Intensifier3™	Auto / Off (selectable x2 - x512)
Motion Detection	On / Off (8 programmable zones)
Privacy Masking	On / Off (12 programmable zones)

Speco DNR	On / Off (level adjustable)
Digital Zoom	On / Off (1x - 16x)
DIS	On / Off
Sharpness	On / Off (level adjustable)
Flip / Mirror	On / Off
Power Supply	12VDC / 24VAC (dual voltage) (power supply not included)
Power Consumption	12VDC, 250mA / 24VAC, 100mA
Operating Temperature	14° F - 122° F
Storage Temperature	-4° F - 140° F
Dimensions	3.1" (H) x 5.1" (Dia.)
Weight	1 lb.

Optional Accessories



Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.

Rev. 2/1/12

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
www.specotech.com