

Current Transformer Cabinets

Current Transformer, Hinged Cover, Type 3R



Double Door (A484814HCT only)

Industry Standards

UL 50, 50E Listed; Type 3R; File No. E27525
cUL Listed per CSA C22.2 No 94; Type 3R; File No. E27525

NEMA Type 3R
IEC 60529, IP32

Application

Current Transformer Cabinets provide outdoor protection and security for instrument current transformers, which are frequently required for transformer-rated watt-hour metering. Cabinets can also be used as junction or service boxes and house meter, transformer, relay or terminal assemblies.

Features

- Dripshield top and seam-free sides, front and back
- Mounting holes on back of enclosure
- Mounting studs are provided on the enclosure body
- Cover is removable in the open position
- Door handles provided
- Provisions for padlocking
- No gasketing or knockouts
- Ground lug
- Mounting provisions for optional door stop

Specifications

- 14 or 12 gauge galvanized steel

Finish

ANSI 61 gray polyester powder paint finish inside and out over galvanized surfaces.

Accessories

See also *Accessories*.
Industrial Corrosion Inhibitors
Grounding Device
Touch-Up Paint
Large Enclosure Door Stop Kit


Bulletin: A90CT

Standard Product

Catalog Number	AxBxC in./mm	Gauge	D in./mm	E in./mm	F in./mm	G in./mm	H in./mm
A36201HCT	36.00 x 20.00 x 11.00	14	18.75	15.00	6.67	8.00	—
	914 x 508 x 279		476	381	169	203	—
A30241HCT	30.00 x 24.00 x 11.00	14	15.75	12.00	8.00	8.00	—
	762 x 610 x 279		400	305	203	203	—
A48241HCT	48.00 x 24.00 x 11.00	14	24.75	21.00	8.00	8.00	—
	1219 x 610 x 279		629	533	203	203	—
A36301HCT	36.00 x 30.00 x 11.00	12	18.75	15.00	7.00	8.00	8.00
	914 x 762 x 279		476	381	178	203	203
A48301HCT	48.00 x 30.00 x 11.00	12	24.75	21.00	7.00	8.00	8.00
	1219 x 762 x 279		629	533	178	203	203
A36361HCT	36.00 x 36.00 x 11.00	12	18.75	15.00	10.00	8.00	8.00
	914 x 914 x 279		476	381	254	203	203
A48361HCT	48.00 x 36.00 x 11.00	12	24.75	21.00	10.00	8.00	8.00
	1219 x 914 x 279		629	533	254	203	203
A484814HCT	48.00 x 48.00 x 14.00	12	—	21.00	16.00	8.00	8.00
	1220 x 1220 x 356		—	533	406	203	203

A484814HCT is a double-door cabinet.

Single-Door Cabinet

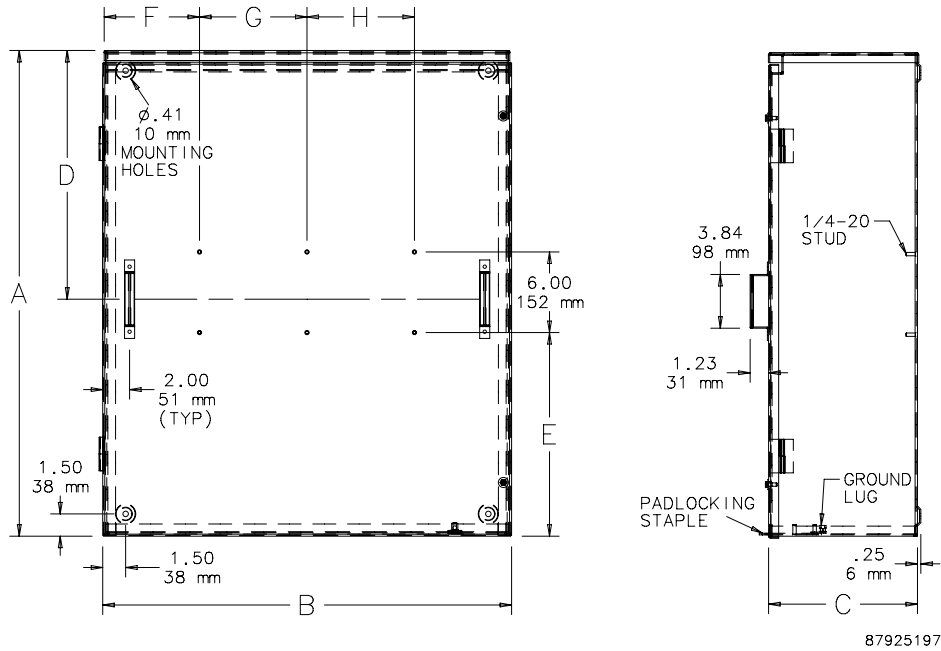

Double-Door Cabinet (A484814HCT only)

