

## Wall-Mount Enclosures and Accessories

### Continuous Hinge with Clamps, Type 4X



#### Industry Standards

UL 508A Listed; Type 3R, 4, 4X, 12; File No. E61997  
cUL Listed per CSA C22.2 No 94; Type 3R, 4, 4X, 12; File No. E61997

NEMA/EEMAC Type 3, 3R, 4, 4X, 12, 13  
CSA File No. 42186: Type 4, 4X, 12  
IEC 60529, IP66  
Meets NEMA Type 3RX requirements

#### Standard Product

Catalog Number	AxBxC in./mm	Stainless Steel Type	Steel Panel	Conductive Steel Panel	Stainless Steel Panel	Panel Size D x E in./mm	F in./mm	Clamps Qty.	Data Pocket
A16H1206SSLP	16.00 x 12.00 x 6.00 406 x 305 x 152	304	A16P12	A16P12G	A16P12SS6	13.00 x 9.00 330 x 229	1.25 32	4	Small
A16H1206SS6LP	16.00 x 12.00 x 6.00 406 x 305 x 152	316L	A16P12	A16P12G	A16P12SS6	13.00 x 9.00 330 x 229	1.25 32	4	Small
A16H1606SSLP	16.00 x 16.00 x 6.00 406 x 406 x 152	304	A16P16	A16P16G	A16P16SS6	13.00 x 13.00 330 x 330	3.00 76	4	Small
A16H1606SS6LP	16.00 x 16.00 x 6.00 406 x 406 x 152	316L	A16P16	A16P16G	A16P16SS6	13.00 x 13.00 330 x 330	3.00 76	4	Small
A16H2006SSLP	16.00 x 20.00 x 6.00 406 x 508 x 152	304	A20P16	A20P16G	A20P16SS6	17.00 x 13.00 432 x 330	3.00 76	4	Small
A16H2006SS6LP	16.00 x 20.00 x 6.00 406 x 508 x 152	316L	A20P16	A20P16G	A20P16SS6	17.00 x 13.00 432 x 330	3.00 76	4	Small
A20H1606SSLP	20.00 x 16.00 x 6.00 508 x 406 x 152	304	A20P16	A20P16G	A20P16SS6	17.00 x 13.00 432 x 330	3.00 76	4	Small
A20H1606SS6LP	20.00 x 16.00 x 6.00 508 x 406 x 152	316L	A20P16	A20P16G	A20P16SS6	17.00 x 13.00 432 x 330	3.00 76	4	Small
A20H2006SSLP	20.00 x 20.00 x 6.00 508 x 508 x 152	304	A20P20	A20P20G	A20P20SS6	17.00 x 17.00 432 x 432	3.00 76	4	Small
A20H2006SS6LP	20.00 x 20.00 x 6.00 508 x 508 x 152	316L	A20P20	A20P20G	A20P20SS6	17.00 x 17.00 432 x 432	3.00 76	4	Small
A24H2006SSLP	24.00 x 20.00 x 6.00 610 x 508 x 152	304	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	3.00 76	5	Small
A24H2006SS6LP	24.00 x 20.00 x 6.00 610 x 508 x 152	316L	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	3.00 76	5	Small
A24H2406SSLP	24.00 x 24.00 x 6.00 610 x 610 x 203	304	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	3.00 76	5	Small
A24H2406SS6LP	24.00 x 24.00 x 6.00 610 x 610 x 152	316L	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	3.00 76	5	Small
A16H1208SSLP	16.00 x 12.00 x 8.00 406 x 305 x 203	304	A16P12	A16P12G	A16P12SS6	13.00 x 9.00 330 x 229	1.25 32	4	Small

#### Application

For use in indoor and outdoor corrosive environments that require a water-tight seal, this enclosure's seamless foam-in-place gasket and screw-down clamps provide a secure seal against contaminants.

#### Specifications

- 14 gauge Type 304 or Type 316L stainless steel bodies and doors
- Seams continuously welded and ground smooth
- Seamless foam-in-place gasket
- Rolled lip around three sides of door
- Stainless steel door clamp assembly
- Hasp and staple for padlocking
- Door removed by pulling stainless steel continuous hinge pin
- Data pocket is high-impact thermoplastic
- Collar studs provided for mounting optional panels
- Exterior hardware on Type 316L stainless steel enclosures matches enclosure material
- Bonding provision on door; grounding stud on body

#### Finish

Door, sides, top and bottom have smooth #4 brushed finish.

#### Accessories

See also Accessories.

Fast-Operating Clamp Assembly

Panels for Type 3R, 4, 4X, 12 and 13 Enclosures

Junction Box and Wall-Mount Enclosure Swing Out Panel Kit

Steel and Stainless Steel Window Kits

H<sub>2</sub>OMIT™ Vent Drains, Type 4X

H<sub>2</sub>OMIT™ Thermoelectric Dehumidifier

#### Modification and Customization

Hoffman excels at modifying and customizing products to your specifications. Contact your local Hoffman sales office or distributor for complete information.

Bulletin: A4S

## Wall-Mount Enclosures and Accessories


Catalog Number	AxBxC in./mm	Stainless Steel Type	Steel Panel	Conductive Steel Panel	Stainless Steel Panel	Panel Size D x E in./mm	F in./mm	Clamps Qty.	Data Pocket
<b>A16H1208SS6LP</b>	16.00 x 12.00 x 8.00 406 x 305 x 203	316L	A16P12	A16P12G	A16P12SS6	13.00 x 9.00 330 x 229	1.25 32	4	Small
<b>A20H1608SSLP</b>	20.00 x 16.00 x 8.00 508 x 406 x 203	304	A20P16	A20P16G	A20P16SS6	17.00 x 13.00 432 x 330	3.00 76	4	Small
<b>A20H1608SS6LP</b>	20.00 x 16.00 x 8.00 508 x 406 x 203	316L	A20P16	A20P16G	A20P16SS6	17.00 x 13.00 432 x 330	3.00 76	4	Small
<b>A20H2008SSLP</b>	20.00 x 20.00 x 8.00 508 x 508 x 203	304	A20P20	A20P20G	A20P20SS6	17.00 x 17.00 432 x 432	3.00 76	4	Small
<b>A20H2008SS6LP</b>	20.00 x 20.00 x 8.00 508 x 508 x 203	316L	A20P20	A20P20G	A20P20SS6	17.00 x 17.00 432 x 432	3.00 76	4	Small
<b>A20H2408SSLP</b>	20.00 x 24.00 x 8.00 508 x 610 x 203	304	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	3.00 76	5	Small
<b>A20H2408SS6LP</b>	20.00 x 24.00 x 8.00 508 x 610 x 203	316L	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	3.00 76	5	Small
<b>A24H1608SSLP</b>	24.00 x 16.00 x 8.00 610 x 406 x 203	304	A24P16	A24P16G	A24P16SS6	21.00 x 13.00 533 x 330	3.00 76	4	Small
<b>A24H1608SS6LP</b>	24.00 x 16.00 x 8.00 610 x 406 x 203	316L	A24P16	A24P16G	A24P16SS6	21.00 x 13.00 533 x 330	3.00 76	4	Small
<b>A24H2008SSLP</b>	24.00 x 20.00 x 8.00 610 x 508 x 203	304	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	3.00 76	5	Small
<b>A24H2008SS6LP</b>	24.00 x 20.00 x 8.00 610 x 508 x 203	316L	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	3.00 76	5	Small
<b>A24H2408SSLP</b>	24.00 x 24.00 x 8.00 610 x 610 x 203	304	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	3.00 76	5	Small
<b>A24H2408SS6LP</b>	24.00 x 24.00 x 8.00 610 x 610 x 203	316L	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	3.00 76	5	Small
<b>A24H3008SSLP</b>	24.00 x 30.00 x 8.00 610 x 762 x 203	304	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	7	Large
<b>A24H3008SS6LP</b>	24.00 x 30.00 x 8.00 610 x 762 x 203	316L	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	7	Large
<b>A30H2008SSLP</b>	30.00 x 20.00 x 8.00 762 x 508 x 203	304	A30P20	A30P20G	A30P20SS6	27.00 x 17.00 686 x 432	3.00 76	5	Small
<b>A30H2008SS6LP</b>	30.00 x 20.00 x 8.00 762 x 508 x 203	316L	A30P20	A30P20G	A30P20SS6	27.00 x 17.00 686 x 432	3.00 76	5	Small
<b>A30H2408SSLP</b>	30.00 x 24.00 x 8.00 762 x 610 x 203	304	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	5	Large
<b>A30H2408SS6LP</b>	30.00 x 24.00 x 8.00 762 x 610 x 203	316L	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	5	Large
<b>A30H3008SSLP</b>	30.00 x 30.00 x 8.00 762 x 762 x 203	304	A30P30	A30P30G	A30P30SS6	27.00 x 27.00 686 x 686	3.00 76	7	Large
<b>A30H3008SS6LP</b>	30.00 x 30.00 x 8.00 762 x 762 x 203	316L	A30P30	A30P30G	A30P30SS6	27.00 x 27.00 686 x 686	3.00 76	7	Large
<b>A36H2408SSLP</b>	36.00 x 24.00 x 8.00 914 x 610 x 203	304	A36P24	A36P24G	A36P24SS6	33.00 x 21.00 838 x 533	3.00 76	5	Large
<b>A36H2408SS6LP</b>	36.00 x 24.00 x 8.00 914 x 610 x 203	316L	A36P24	A36P24G	A36P24SS6	33.00 x 21.00 838 x 533	3.00 76	5	Large
<b>A36H3008SSLP</b>	36.00 x 30.00 x 8.00 914 x 762 x 203	304	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	3.00 76	7	Large
<b>A36H3008SS6LP</b>	36.00 x 30.00 x 8.00 914 x 762 x 203	316L	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	3.00 76	7	Large
<b>A42H3608SSLP</b>	42.00 x 36.00 x 8.00 1067 x 914 x 203	304	A42P36	A42P36G	A42P36SS6	39.00 x 33.00 991 x 838	3.00 76	8	Large
<b>A42H3608SS6LP</b>	42.00 x 36.00 x 8.00 1067 x 914 x 203	316L	A42P36	A42P36G	A42P36SS6	39.00 x 33.00 991 x 838	3.00 76	8	Large
<b>A48H3608SSLP</b>	48.00 x 36.00 x 8.00 1219 x 914 x 203	304	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	3.00 76	8	Large
<b>A48H3608SS6LP</b>	48.00 x 36.00 x 8.00 1219 x 914 x 203	316L	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	3.00 76	8	Large
<b>A20H1610SSLP</b>	20.00 x 16.00 x 10.00 508 x 406 x 254	304	A20P16	A20P16G	A20P16SS6	17.00 x 13.00 432 x 330	3.00 76	4	Small
<b>A20H1610SS6LP</b>	20.00 x 16.00 x 10.00 508 x 406 x 254	316L	A20P16	A20P16G	A20P16SS6	17.00 x 13.00 432 x 330	3.00 76	4	Small
<b>A24H2010SSLP</b>	24.00 x 20.00 x 10.00 610 x 508 x 254	304	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	3.00 76	5	Small
<b>A24H2010SS6LP</b>	24.00 x 20.00 x 10.00 610 x 508 x 254	316L	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	3.00 76	5	Small
<b>A30H2410SSLP</b>	30.00 x 24.00 x 10.00 762 x 610 x 254	304	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	5	Large
<b>A30H2410SS6LP</b>	30.00 x 24.00 x 10.00 762 x 610 x 254	316L	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	5	Large
<b>A36H2410SSLP</b>	36.00 x 24.00 x 10.00 914 x 610 x 254	304	A36P24	A36P24G	A36P24SS6	33.00 x 21.00 838 x 533	3.00 76	5	Large
<b>A36H2410SS6LP</b>	36.00 x 24.00 x 10.00 914 x 610 x 254	316L	A36P24	A36P24G	A36P24SS6	33.00 x 21.00 838 x 533	3.00 76	5	Large
<b>A36H3010SSLP</b>	36.00 x 30.00 x 10.00 914 x 762 x 254	304	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	3.00 76	7	Large

## Wall-Mount Enclosures and Accessories


Catalog Number	AxBxC in./mm	Stainless Steel Type	Steel Panel	Conductive Steel Panel	Stainless Steel Panel	Panel Size		Clamps Qty.	Data Pocket
						D x E in./mm	F in./mm		
<b>A36H3010SS6LP</b>	36.00 x 30.00 x 10.00 914 x 762 x 254	316L	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	3.00 76	7	Large
<b>A42H3010SSLP</b>	42.00 x 30.00 x 10.00 1067 x 762 x 254	304	A42P30	A42P30G	A42P30SS6	39.00 x 27.00 991 x 686	3.00 76	8	Large
<b>A42H3010SS6LP</b>	42.00 x 30.00 x 10.00 1067 x 762 x 254	316L	A42P30	A42P30G	A42P30SS6	39.00 x 27.00 991 x 686	3.00 76	8	Large
<b>A48H3610SSLP</b>	48.00 x 36.00 x 10.00 1219 x 914 x 254	304	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	3.00 76	8	Large
<b>A48H3610SS6LP</b>	48.00 x 36.00 x 10.00 1219 x 914 x 254	316L	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	3.00 76	8	Large
<b>A24H2412SSLP</b>	24.00 x 24.00 x 12.00 610 x 610 x 305	304	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	3.00 76	5	Small
<b>A24H2412SS6LP</b>	24.00 x 24.00 x 12.00 610 x 610 x 305	316L	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	3.00 76	5	Small
<b>A30H2412SSLP</b>	30.00 x 24.00 x 12.00 762 x 610 x 305	304	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	5	Large
<b>A30H2412SS6LP</b>	30.00 x 24.00 x 12.00 762 x 610 x 305	316L	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	5	Large
<b>A36H3012SSLP</b>	36.00 x 30.00 x 12.00 914 x 762 x 305	304	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	3.00 76	7	Large
<b>A36H3012SS6LP</b>	36.00 x 30.00 x 12.00 914 x 762 x 305	316L	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	3.00 76	7	Large
<b>A36H3612SSLP</b>	36.00 x 36.00 x 12.00 914 x 914 x 305	304	A36P36	A36P36G	A36P36SS6	33.00 x 33.00 838 x 838	3.00 76	7	Large
<b>A36H3612SS6LP</b>	36.00 x 36.00 x 12.00 914 x 914 x 305	316L	A36P36	A36P36G	A36P36SS6	33.00 x 33.00 838 x 838	3.00 76	7	Large
<b>A48H3612SSLP</b>	48.00 x 36.00 x 12.00 1219 x 914 x 305	304	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	3.00 76	8	Large
<b>A48H3612SS6LP</b>	48.00 x 36.00 x 12.00 1219 x 914 x 305	316L	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	3.00 76	8	Large
<b>A60H3612SSLP</b>	60.00 x 36.00 x 12.00 1524 x 914 x 305	304	A60P36	A60P36G	A60P36SS6	57.00 x 33.00 1448 x 838	3.00 76	9	Large
<b>A60H3612SS6LP</b>	60.00 x 36.00 x 12.00 1524 x 914 x 305	316L	A60P36	A60P36G	A60P36SS6	57.00 x 33.00 1448 x 838	3.00 76	9	Large
<b>A30H2416SSLP</b>	30.00 x 24.00 x 16.00 762 x 610 x 406	304	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	5	Large
<b>A30H2416SS6LP</b>	30.00 x 24.00 x 16.00 762 x 610 x 406	316L	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	3.00 76	5	Large
<b>A36H3016SSLP</b>	36.00 x 30.00 x 16.00 914 x 762 x 406	304	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	3.00 76	7	Large
<b>A36H3016SS6LP</b>	36.00 x 30.00 x 16.00 914 x 762 x 406	316L	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	3.00 76	7	Large
<b>A48H3616SSLP</b>	48.00 x 36.00 x 16.00 1219 x 914 x 406	304	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	3.00 76	8	Large
<b>A48H3616SS6LP</b>	48.00 x 36.00 x 16.00 1219 x 914 x 406	316L	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	3.00 76	8	Large
<b>A60H3616SSLP</b>	60.00 x 36.00 x 16.00 1524 x 914 x 406	304	A60P36	A60P36G	A60P36SS6	57.00 x 33.00 1448 x 838	3.00 76	9	Large
<b>A60H3616SS6LP</b>	60.00 x 36.00 x 16.00 1524 x 914 x 406	316L	A60P36	A60P36G	A60P36SS6	57.00 x 33.00 1448 x 838	3.00 76	9	Large

Purchase panels separately. Optional composite and aluminum panels are available for most sizes.

### Wall-Mount Enclosures and Accessories

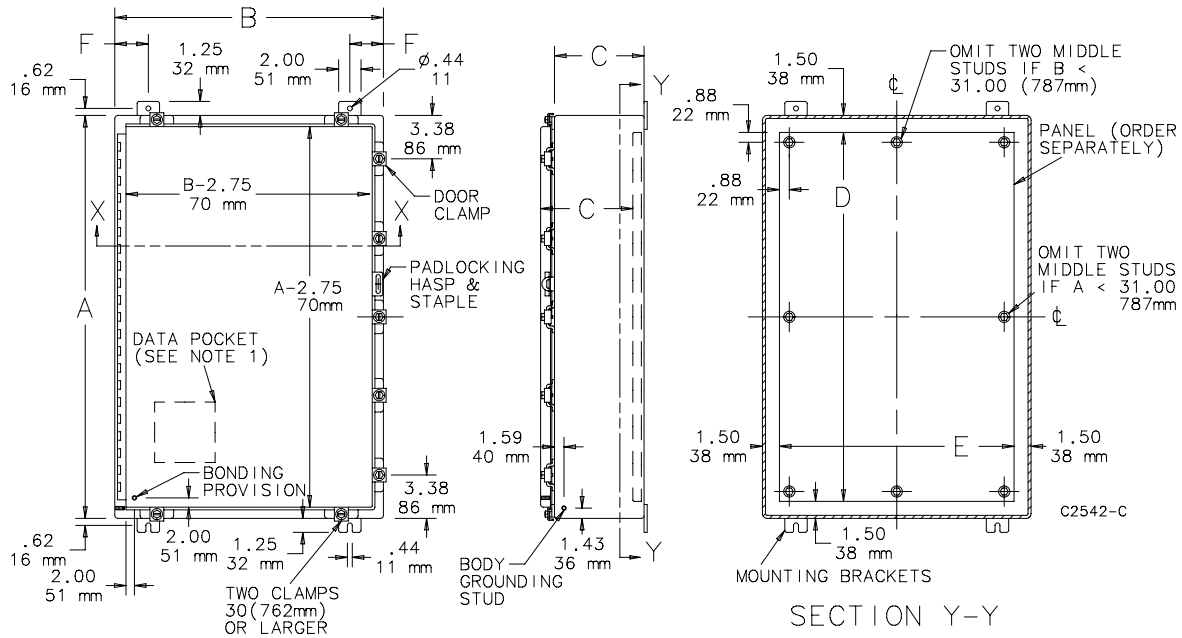

SECTION Y-Y

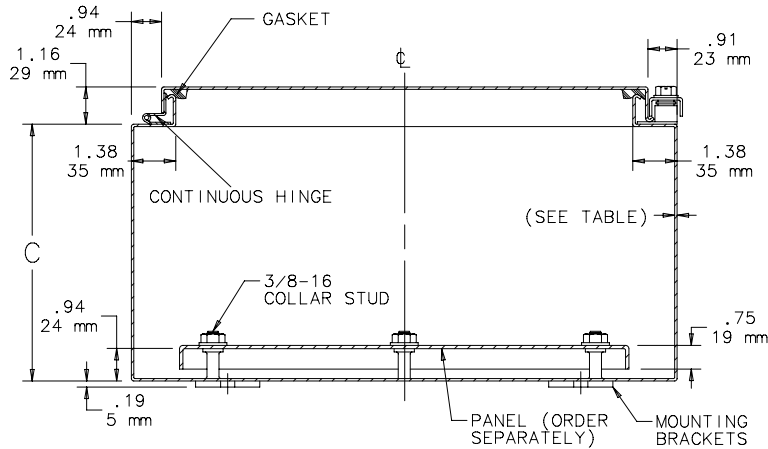

SECTION X-X

- NOTE:
1. Removable data pocket included (see table for size). Large data pocket 12.00 x 12.00 (305mm x 305mm); small data pocket 6.00 x 6.00 (152mm x 152mm).
  2. Maximum spacing between door clamps is 15.00 (382mm)