

HOLE PLUGS



Brass and Plastic Plugs for use in PG and Metric Threaded Holes

PG & Metric Metal Plugs



Technical Data:

	Materials:	Nickel-Plated Brass
	O-Ring:	NBR
	Seal:	IP 54 IP 68 with O-Ring
	Temperature:	-30°C to +100°C Metric With O-Ring: Metric Without O-Ring:

SKINDICHT® BL Hole Plugs/ BL Hole Plugs with O-Ring

BL Part Number	BL Part Number with O-Ring	Thread Type & Size	Standard Pack Size
52002680	54001610	PG-7	100
52003390	54000071	PG-9	100
52003400	54000040	PG-11	100
52003410	54001630	PG-13	100
52003420	54001640	PG-16	100
52003430	54001660	PG-21	50
52003440	54001620	PG-29	50
52003450	54001650	PG-36	25
52003460	54001670	PG-42	10
52002790	54001680	PG-48	10


SKINDICHT® BLM Hole Plugs/ BLM Hole Plugs with O-Ring

BLM Part Number	BLM Part Number with O-Ring	Thread Type & Size	Outer Diameter inches	Standard Pack Size
52103100	52103105	M-12X1.5	0.55	100
52103110	52103115	M-16X1.5	0.71	100
52103120	52103125	M-20X1.5	0.87	100
52103130	52103135	M-25X1.5	1.10	100
52103140	52103145	M-32X1.5	1.38	50
52103150	52103155	M-40X1.5	1.73	25
52103160	52103165	M-50X1.5	2.13	10
52103170	52103175	M-63X1.5	2.76	10

SKINDICHT® BLK & BLK-M PG & Metric Plastic Hole Plugs

Technical Data:

	Materials:	Polystyrene
	Color:	RAL 7035: Light Gray RAL 9005: Black
	Temperature:	-20°C to +70°C BLK-M: BLK-GL & BLK-GL-M:
	Seal:	IP 54 IP 54 BLK-GL-M with O-Ring: IP 68

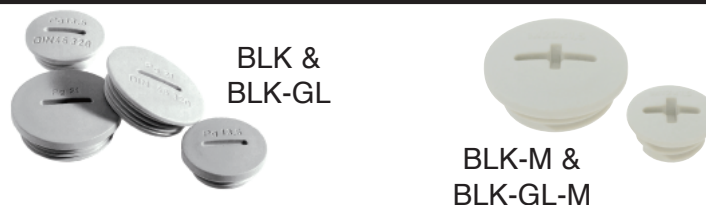

SKINDICHT® BLK/ BLK-GL Hole Plugs


Part Number Light Gray BLK	Part Number Light Gray BLK-GL	Thread Type & Size	Thread Length inches	Standard Pack Size
52005949	52024848	PG-7	0.24	100
52005950	52024849	PG-9	0.24	100
52005960	52024850	PG-11	0.24	100
52005970	52024851	PG-13	0.24	100
52005980	52024852	PG-16	0.24	100
52005990	52024853	PG-21	0.31	50
52006000	52024854	PG-29	0.31	50
52006010	52024855	PG-36	0.39	25
52006020	52024856	PG-42	0.39	25
52006030	52024857	PG-48	0.47	25

SKINDICHT® Hole Plugs

- BLK-M
- BLK-GL-M
- BLK-GL-M with O-ring

Part Number Light Gray BLK-M	Part Number Light Gray BLK-GL-M	Part Number Lt Gray / O-ring BLK-GL-M	Part Number Black BLK-GL-M	Part Number Black with O-Ring BLK-GL-M	Thread Type & Size	Thread Length inches	Standard Pack Size
52006600	52006100	52006107	52006103	52006106	M-12X1.5	.236	100
52006610	52006110	52006117	52006113	52006116	M-16X1.5	.236	100
52006620	52006120	52006127	52006123	52006126	M-20X1.5	.236	100
52006630	52006130	52006137	52006133	52006136	M-25X1.5	.315	100
52006640	52006140	52006147	52006143	52006146	M-32X1.5	.315	50
52006650	52006150	52006157	52006153	52006156	M-40X1.5	.315	25
52006660	52006160	52006167	52006163	52006166	M-50X1.5	.394	25
52006670	52006170	52006177	52006173	52006176	M-63X1.5	.472	25

SKINTOP® CLICK BLK

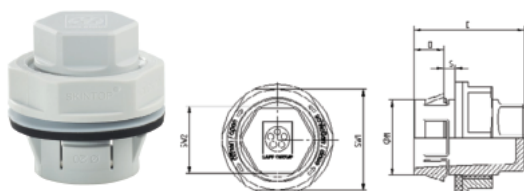

Technical Data:

	Materials:	Special Polyamide
	Body:	Special Elastomer
	Seal:	IP 68
	Temperature:	-20°C to +100°C

Part Number	Thread Type & Size	S Wall Thickness inches	SW 1 inches	SW 2 inches	C inches	D inches	Standard Pack Size
52109013	M-16	.04 - .16	.55	.04	1.12	.31	50
52109014	M-20	.04 - .16	.71	.04	1.16	.31	25
52109015	M-25	.04 - .16	.87	.04	1.20	.31	25