

IQeye Alliance-mini

H.264 Megapixel Dome IP Camera

Features

- > Resolutions up to HD1080p
- > H.264 Main Profile + MJPEG Compression
- > 60 fps @ SD480p, 30 fps @ HD1080p
- > Two-Way Audio with Built-in Microphone
- > 3-Axis Gimbal
- > Lightgrabber™ II Low-light Feature
- > Power Over Ethernet
- > Cast-Aluminum
- > Direct-to-Storage
- > ONVIF and PSIA Compliant
- > 5 Year Warranty

Supporting H.264 Main Profile, the Alliance-mini offers exceptional image quality in a tiny, versatile and attractive mini-dome package. It is available in standard interior vandal models from VGA to 1080p HD megapixel resolutions, making it one of the smallest professional surveillance dome cameras with the highest resolution available today. At only 2.78 inches in height the Alliance-mini camera is designed for discreet indoor use, ideal for retail, office and healthcare environments. These ultra lightweight cameras easily mount to ceilings or walls, and the true 3-axis gimbal, locking shroud and Power-over-Ethernet design saves time and money on installation and maintenance. The Alliance-mini also supports streaming audio, allowing 2-way communication between the camera and remote/ monitoring locations. ONVIF and PSIA compliant APIs provide the flexibility to ensure compatibility with most popular VMS platforms. Optional accessory kits include wall and pendant mount, wide and telephoto lenses.



IQ inVision 

33122 Valle Road
San Juan Capistrano, CA
92675-4853
USA

toll free within US 877.850.0805
phone +1.949.369.8100
fax +1.949.369.8105

www.iqeye.com



IQeye Alliance-mini

H.264 Megapixel Dome IP Camera



Specifications

Video

Compression	H.264 and MJPEG
H.264 Profile	Main
Sensor	1/3" CMOS
JPEG Compression Quality Settings	User Configurable
Shutter Speed	Auto/Programmable/Fixed
Image Settings	Saturation, Contrast, Brightness, Sharpness, Lightgrabber™ II
Exposure	User Configurable
White Balance	Auto/Programmable
Backlight Compensation	Auto

Features

Motion Detection	User Configurable Windows
Time Lapse Recording	User Configurable
Event Based Recording	User Configurable
Flip and Rotate	180, Horizontal, Vertical
Audio Support	Two-way G.711 PCM 8 kHz
On-Camera IQapps	IQaccess
System Integration	ONVIF, PSIA, IQfinder, IQmanager, IQsentry, IQevent, Direct-to-Storage

Network

Supported Protocols	TCP/IP, HTTP, HTTPS, DHCP, UDP, RTP, RTSP, DNS, ARP, ICMP, NTP, UPnP, ZeroConf, APIPA, UDP multicast, SNMP, FTP, SMTP, Telnet, CIFS
---------------------	---

Password Protection	Secure Multi-level
---------------------	--------------------

Input/Output

Input Power	Power over Ethernet 802.3af Class 1
-------------	-------------------------------------

Power Consumption	< 3.8W (typical)
-------------------	------------------

AC Lighting	50 Hz/60 Hz Selectable
-------------	------------------------

Network Interface	RJ45 10Base-T/100Base-TX
-------------------	--------------------------

Audio I/O	Built-in Microphone, Mic/Line in, Line out
-----------	--

Misc

Approvals	FCC, CE
-----------	---------

Temperature Range	32°F to 104°F, 0°C to 40°C
-------------------	----------------------------

Weight (grams)	253 g (SI), 298 g (SV)
----------------	------------------------

Warranty	5 years
----------	---------


Lens Options	F1 Wide Angle Lens 1/3" M12, 4.2 mm, F1.8 F2 Wide Angle Lens 1/3" M12, 2.8 mm, F2.6 F3 Telephoto Lens 1/3" M12, 8 mm, F1.8 F4 Wide Angle Lens 1/3" M12, 3.6 mm, F1.8
--------------	---

Accessories	IQD4-PB Pendant Mount Black IQD4-WB Wall Mount Black IQD-GBA Gang Box Adapter
-------------	---


Product Configurations

Part Number	Max Resolution	Max Framerate	Min Illumination	Compatible Lens
IQD30SV	SD480p - 720 x 480	60 fps	Color: 0.1 lux	F1, F2, F3
IQD31SV	HD720p - 1280 x 720	30 fps	Color: 0.1 lux	F1, F2, F3
IQD32SV	HD1080p - 1920 x 1080	30 fps	Color: 0.2 lux	F1, F3, F4

Dimensions

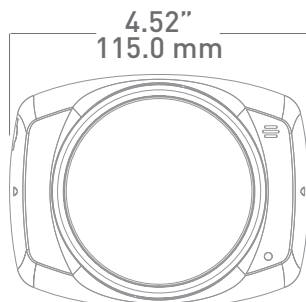

Top

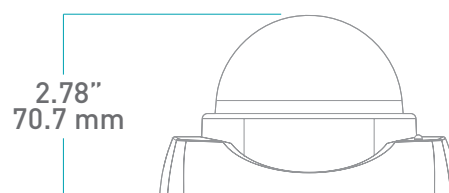

Side