

plantronics®

**LEARN
MORE**

**Voyager™ PRO+
Bluetooth® Headset**

TAKE A GOOD LOOK

CALL BUTTON


- **Take a call or end it** (1 tap)
- **Redial** (2 taps)
- **Initiate phone's voice-dialing** (2-second press until tone heard)
- **Reconnect lost connection** (1 tap)
- **Transfer audio to/from headset** (1-second press while on a call)
- **Dial Plantronics Vocalyst™ voice and text service** (3 taps) (Available in U.S. only)

POWER BUTTON

- **On or off** (2-second press)
- **Battery level voice alerts** (1 tap)
- **Activate pairing after initial set up** (press until LED flashes red/blue)

MICRO USB CHARGING PORT

- **With AC charger:**
90 minutes for full charge
- **Fully charge before first use**
- **Best performance when fully charged**

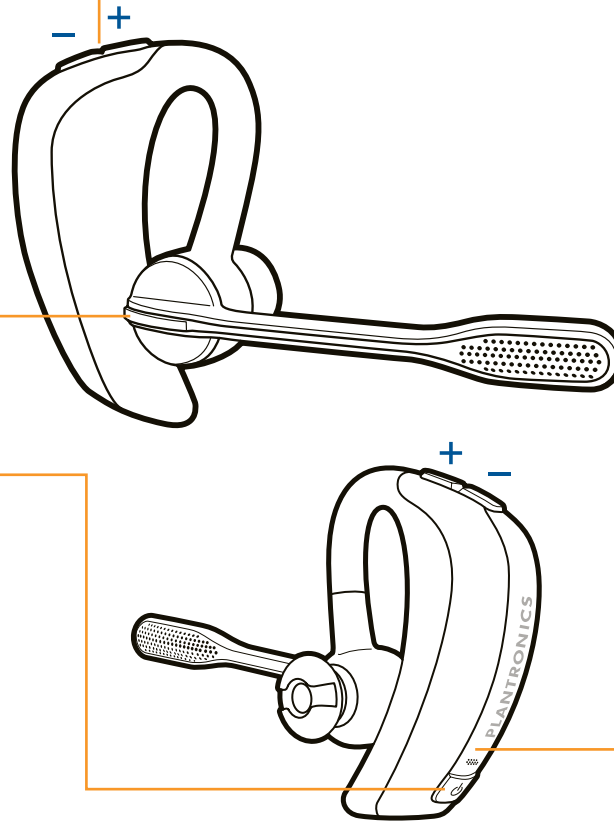

VOLUME/MUTE BUTTONS


- **Volume: up/down** (tap + or – buttons per level change)
- **Mute during a call: on/off** (1-second press of both + and – buttons)
- **Music or audio: pause/play** (1-second press of both + and – buttons)

LED

- **Charging** (solid red)
- **Battery status** (1-6 hrs left = 1 red flash, low = 2 red flashes, critically low = 3 red flashes)
- **Missed call** (3 purple flashes, repeats for 5 minutes or until canceled by tapping Call button)
- **Pairing mode** (repeating blue/red flashes)
- **Multipoint** (on = 2 blue flashes, off = 1 blue flash)

Be safe! Please read the safety guide before using your new headset.

CONNECT TO YOUR PHONE

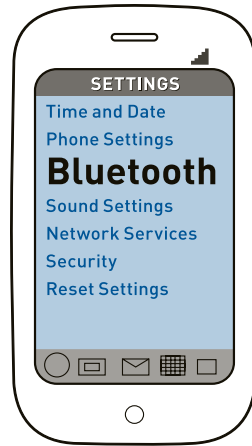

1. READY

Activate the Bluetooth feature on your phone, then use the phone's settings to add/search/discover new Bluetooth devices.

iPhone: Settings > General > Bluetooth > On
(starts the search for devices)

BlackBerry® smartphone:
Settings/options >
Bluetooth: On >
Search for devices

VIDEO TUTORIAL IN USA:
www.plantronics.com/pairing



2. SET

First Time:


With headset turned off, activate Bluetooth pairing mode by pressing the Power button. The LED flashes red/blue to indicate pairing mode.

Activate Multipoint:

While pressing the Call button, turn on the headset and keep pressing the Call button until LED flashes blue twice. (Repeat to deactivate.)

Pairing Second Phone/ Reconnecting Original:

Start in "OFF" mode. Press and hold the Power button until the LED flashes red/blue.

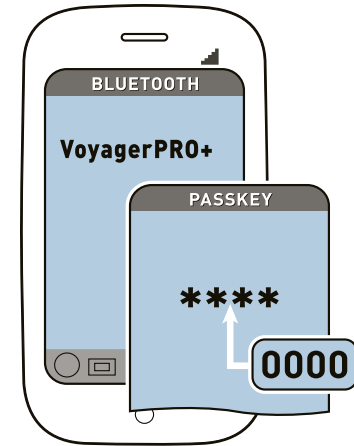

3. CONNECT

Select "VoyagerPRO+" from the list of Bluetooth devices shown on your phone.

If phone asks for a passcode, enter four zeros (0000). You may see **** on screen.

Some phones also ask to confirm headset connection after pairing.


Headset LED will stop flashing red/blue once your phone and headset are successfully paired/connected.

MIX AND MATCH FOR BEST FIT

The headset comes with the medium eartip installed, but you can replace it with the optional small or large eartip provided.

Removing the Eartip:


1. Grip the eartip and gently push it into the speaker housing then rotate it a quarter turn to the left to unlock.
2. Pull the eartip away from the headset.

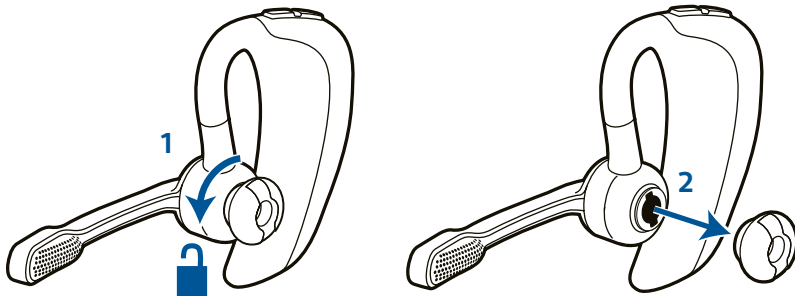

Attaching a New Eartip:

1. Align the tabs on the eartip with the slots on the speaker housing.
2. Gently push the eartip into housing while turning it a quarter turn to the right. The eartip will stop rotating when it is locked.

You may want to add the foam eartip covers for additional comfort.

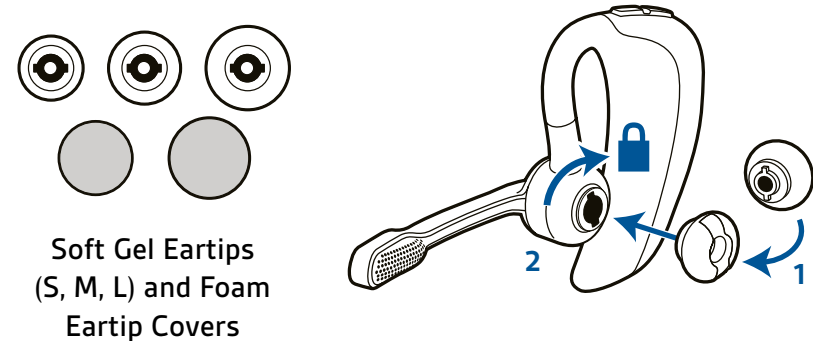


TRY IT ON

For the best sound clarity and comfort, make sure you have a secure fit.


The Over-and-In Technique:

1. Guide the earloop behind your ear and position the headset so that the speaker and eartip rest comfortably in your ear.
2. Pivot the boom up or down to point the microphones toward the corner of your mouth.

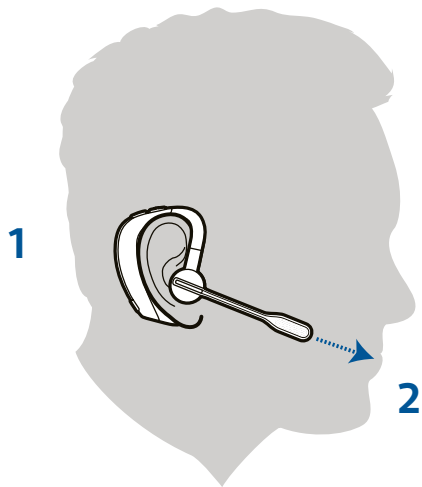

The Quick-Turn Adjustment:

1. Pivot the boom into an upright position.
2. Rotate the boom and speaker to the other side of the headset and lower it before fitting the headset on your other ear.

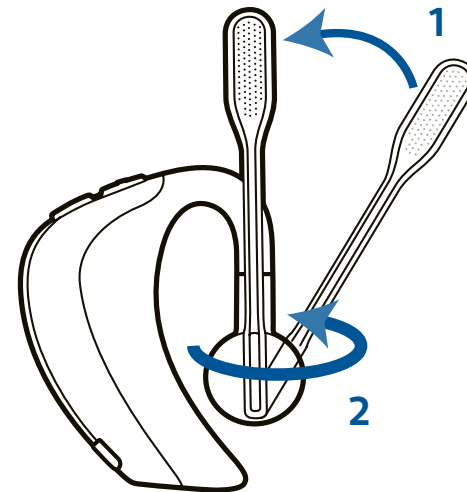

MORE ABOUT MULTIPOINT

Plantronics VoyagerPRO+ supports multipoint technology, which allows you to use one headset with two different Bluetooth mobile phones.

To pair your headset to a second phone, see "[Connect to Your Phone](#)".

How to Initiate a Call

When multipoint is on, the headset initiates or redials a call from the phone that last made an outgoing call.

To use the second paired phone instead, make the call using the controls on that phone. The second phone activates its link with the headset.

NOTE: The headset cannot place a current call on hold while answering a call from the second phone.

How to Answer a Call While Talking on the Other Paired Phone

To answer a second call on the other phone, the current call must be terminated or transferred back to the first phone. To transfer the call, see "[Take a Good Look](#)".

If you choose not to answer, the second call will go to voice mail.

Answering an incoming call from the second phone, while already on another call:

1. To answer the second call, end the first call by tapping the Call button.
2. Answer the second call by tapping the Call button again.

TIP: To avoid issues with multipoint, use the Call button on the headset rather than your phone controls.

LISTEN TO THE VOICE

This headset announces various status alerts when you power on/off, run low on talk time, or lose/reconnect the Bluetooth connection to your phone.

WHAT YOU'LL HEAR	WHEN YOU'LL HEAR IT
Power On	After pressing the Power button for 2 seconds
Power Off	After pressing the Power button for 2 seconds
Talk Time: ("6 hrs", "5 hrs", "4 hrs", "3 hrs", "less than 2 hrs")	After powering the headset "on"
Battery Low	When you have under 30 minutes left before the battery must be recharged
Recharge Headset	When you have approximately 10 minutes left before the battery must be recharged
Connected	After turning the headset on or reconnecting a dropped Bluetooth signal
Phone 1 Connected	After powering the headset to "on" or reconnecting a dropped Bluetooth connection
Phone 2 Connected	After pairing a second phone using multipoint feature
Pairing	While the headset and phone are trying to pair/connect
Pairing Successful	After the headset and phone are successfully paired/connected
Pairing Incomplete, Restart Headset	After the headset and phone tried to pair but failed
Mute On	After pressing the Volume + and - buttons simultaneously during a call
Mute Off	When on mute, after pressing the Volume + and - buttons simultaneously during a call
Lost Connection	When the phone loses the Bluetooth connection with the headset
Volume Maximum	When the highest volume level is reached after tapping Volume + button
Volume Minimum	When the lowest volume level is reached after tapping Volume - button

TIPS

Stream Music and More:

Once your phone is connected, music or audio files like GPS directions or podcasts can be streamed through the headset.

The headset supports A2DP when connected to a device capable of streaming A2DP audio.

PAUSE/PLAY: You can pause and play music and audio files using controls on the headset if your device also supports Bluetooth AVRCP. Simply press both volume +/- buttons simultaneously until you hear a beep.

Use Multipoint One Call at a Time:

You cannot place a current call on hold while answering a call from the second phone.

Tap the Call button to end the first call and tap it again to take the second call.

Check Headset Battery Level on an iPhone:

The battery level of your headset is shown on-screen beside the phone's battery level icon.

Check the Battery Level:

The battery alert announces remaining talk time after calls end.

In addition, you can tap the Power button to check battery level.

Know How to Reconnect:

Your headset tries to reconnect a lost connection. If it can't, then tap the Call button once or manually reconnect via the phone's Bluetooth device menu.

Stay Near Your Phone:

Bluetooth has a working "range" of up to 33 feet between the phone and headset before audio degrades and the connection is lost.

SPECIFICATIONS

Talk Time	Up to 6 hours talk time
Standby Time	Up to 5 days standby
Operating Distance (Range)	Up to 33 foot range
Headset Weight	17 grams
Charge Connector	Micro USB cable with micro USB connection and AC/DC 100–240V
Battery Type	Rechargeable, non-replaceable Lithum-ion polymer
Charge Time (Maximum)	1.5 hours
Power Requirements	5V DC - 180mA
Bluetooth Version	Version 2.1 + Enhanced Data Rate (EDR), eSCO data packet transfer, Secure Simple Pairing (SSP) if supported by phone
Bluetooth Profiles	Hands-free v1.5 (HFP), Headset v1.1 (HSP), Advanced Audio Distribution (A2DP) and Audio/Video Remote Control (AVRCP)
Operating, Storage and Charging Temperature	32°F - 104°F (0 - 40°C)

NEED MORE HELP?

Phone support in USA:

1-866-363-BLUE (2583)

1-year limited warranty details:

www.plantronics.com/warranty

© 2011 Plantronics, Inc. All Rights Reserved. Plantronics, Vocalyst and Voyager Pro+ are trademarks or registered trademarks of Plantronics, Inc. The Bluetooth word mark and logos are owned by the Bluetooth SIG, Inc. and any use of such marks by Plantronics, Inc. is under license. iPhone is a trademark of Apple Inc. registered in the U.S. and other countries. Blackberry is owned by Research In Motion Limited and is registered in the United States and may be pending or registered in other countries. Plantronics, Inc is not endorsed, sponsored, affiliated with or otherwise authorized by Research In Motion Limited. Patents US 5,210,791; D612,840; D612,834; D612,835; BR DI69022011; China ZL200930191189.7; EM 001142582-001; IN 223437; Taiwan D134706; Patents Pending. 84470-01 (03/11)



Z109
N10687