

## CONCEPT™ Wall-Mount Enclosures

### CONCEPT™, Type 4X



#### Industry Standards

Mounting brackets required to meet UL/CSA external mounting requirements.

UL 508A Listed; Type 3R, 4, 4X, 12; File No. E61997  
cUL Listed per CSA C22.2 No 94; Type 3R, 4, 4X, 12; File No. E61997

NEMA/EMAC Type 3R, 4, 4X, 12, 13  
CSA File No. 42186: Type 4, 4X, 12  
VDE IP66  
IEC 60529, IP66  
Meets NEMA Type 3RX requirements

#### Application

For indoor or outdoor applications that require corrosion protection from chemicals and water. CONCEPT™ Enclosures feature streamlined styling with an attractive stroked finish and flush quarter-turn latches for secure closure. Available in solid- and window-door models.

#### Specifications

- Manufactured from Type 304 or Type 316L stainless steel
- Minimum-width body flange provides maximum body opening
- External formed 90-degree body flange
- Panel mounting studs fit optional CONCEPT panels and other accessories
- Mounting holes in back of body for direct mounting or for optional external mounting brackets
- Type 316 stainless steel hidden hinges promote clean aesthetic appearance
- Corner formed doors are interchangeable and easily removed by pulling clip-style hinge pins
- Provision on door (except window-door style and when B = 12 in.) for thermoplastic data pocket
- Provision on door (except window-door style and when B = 12 in.) for optional doorstop kit
- Quarter-turn latches furnished with flush slotted insert
- Seamless foam-in-place gasket
- Self-grounding latch system with double seal
- Bonding provision on door; grounding stud on body
- Furnished hardware kit consists of panel-mounting nuts, panel-grounding hardware and sealing washers for wall-mounting holes
- Installation instructions
- Window doors have a clear polycarbonate window

#### Finish

Door and body have smooth #4 brushed finish.

#### Accessories

See also Accessories.

Type 316 Stainless Steel Door Stop Kit  
CONCEPT™ Panels

H2OMIT™ Vent Drains, Type 4X

H2OMIT™ Thermoelectric Dehumidifier

Handles

Lock Inserts

#### Modification and Customization

Hoffman excels at modifying and customizing products to your specifications. Contact your local Hoffman sales office or distributor for complete information.

Bulletin: CWS

#### Standard Product **One-Door**

| Catalog Number | AxBxC in.            | AxBxC mm        | Door Gauge | Body Gauge | Panel  | Conductive Panel | Panel Size D x E (in.) | Panel Size D x E (mm) | Mounting G x H (in.) | Mounting G x H (mm) | Latches Qty. | Style        | J (in.) | J (mm) |
|----------------|----------------------|-----------------|------------|------------|--------|------------------|------------------------|-----------------------|----------------------|---------------------|--------------|--------------|---------|--------|
| CSD12126SS     | 12.00 x 12.00 x 6.00 | 305 x 305 x 152 | 16         | 18         | CP1212 | CP1212G          | 10.20 x 10.20          | 259 x 259             | 10.50 x 10.50        | 267 x 267           | 1            | Quarter-turn | 6.00    | 152    |
| CSD12126SS6    | 12.00 x 12.00 x 6.00 | 305 x 305 x 152 | 16         | 18         | CP1212 | CP1212G          | 10.20 x 10.20          | 259 x 259             | 10.50 x 10.50        | 267 x 267           | 1            | Quarter-turn | 6.00    | 152    |
| CSD16126SS     | 16.00 x 12.00 x 6.00 | 406 x 305 x 152 | 16         | 18         | CP1612 | CP1612G          | 14.20 x 10.20          | 361 x 259             | 14.50 x 10.50        | 368 x 267           | 1            | Quarter-turn | 8.00    | 203    |
| CSD16126SS6    | 16.00 x 12.00 x 6.00 | 406 x 305 x 152 | 16         | 18         | CP1612 | CP1612G          | 14.20 x 10.20          | 361 x 259             | 14.50 x 10.50        | 368 x 267           | 1            | Quarter-turn | 8.00    | 203    |
| CSD16166SS     | 16.00 x 16.00 x 6.00 | 406 x 406 x 152 | 16         | 18         | CP1616 | CP1616G          | 14.20 x 14.20          | 361 x 361             | 14.50 x 14.50        | 368 x 368           | 1            | Quarter-turn | 8.00    | 203    |
| CSD16166SS6    | 16.00 x 16.00 x 6.00 | 406 x 406 x 152 | 16         | 18         | CP1616 | CP1616G          | 14.20 x 14.20          | 361 x 361             | 14.50 x 14.50        | 368 x 368           | 1            | Quarter-turn | 8.00    | 203    |
| CSD20166SS     | 20.00 x 16.00 x 6.00 | 508 x 406 x 152 | 16         | 18         | CP2016 | CP2016G          | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 1            | Quarter-turn | 10.00   | 254    |
| CSD20166SS6    | 20.00 x 16.00 x 6.00 | 508 x 406 x 152 | 16         | 18         | CP2016 | CP2016G          | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 1            | Quarter-turn | 10.00   | 254    |
| CSD20206SS     | 20.00 x 20.00 x 6.00 | 508 x 508 x 152 | 16         | 18         | CP2020 | CP2020G          | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 1            | Quarter-turn | 10.00   | 254    |
| CSD20206SS6    | 20.00 x 20.00 x 6.00 | 508 x 508 x 152 | 16         | 18         | CP2020 | CP2020G          | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 1            | Quarter-turn | 10.00   | 254    |
| CSD16128SS     | 16.00 x 12.00 x 8.00 | 406 x 305 x 203 | 16         | 18         | CP1612 | CP1612G          | 14.20 x 10.20          | 361 x 259             | 14.50 x 10.50        | 368 x 267           | 1            | Quarter-turn | 8.00    | 203    |
| CSD16128SS6    | 16.00 x 12.00 x 8.00 | 406 x 305 x 203 | 16         | 18         | CP1612 | CP1612G          | 14.20 x 10.20          | 361 x 259             | 14.50 x 10.50        | 368 x 267           | 1            | Quarter-turn | 8.00    | 203    |
| CSD16168SS     | 16.00 x 16.00 x 8.00 | 406 x 406 x 203 | 16         | 18         | CP1616 | CP1616G          | 14.20 x 14.20          | 361 x 361             | 14.50 x 14.50        | 368 x 368           | 1            | Quarter-turn | 8.00    | 203    |
| CSD16168SS6    | 16.00 x 16.00 x 8.00 | 406 x 406 x 203 | 16         | 18         | CP1616 | CP1616G          | 14.20 x 14.20          | 361 x 361             | 14.50 x 14.50        | 368 x 368           | 1            | Quarter-turn | 8.00    | 203    |
| CSD16208SS     | 16.00 x 20.00 x 8.00 | 406 x 508 x 203 | 16         | 18         | CP1620 | CP1620G          | 18.20 x 14.20          | 462 x 361             | 14.50 x 18.50        | 368 x 470           | 1            | Quarter-turn | 8.00    | 203    |
| CSD16208SS6    | 16.00 x 20.00 x 8.00 | 406 x 508 x 203 | 16         | 18         | CP1620 | CP1620G          | 18.20 x 14.20          | 462 x 361             | 14.50 x 18.50        | 368 x 470           | 1            | Quarter-turn | 8.00    | 203    |
| CSD20168SS     | 20.00 x 16.00 x 8.00 | 508 x 406 x 203 | 16         | 18         | CP2016 | CP2016G          | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 1            | Quarter-turn | 10.00   | 254    |
| CSD20168SS6    | 20.00 x 16.00 x 8.00 | 508 x 406 x 203 | 16         | 18         | CP2016 | CP2016G          | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 1            | Quarter-turn | 10.00   | 254    |
| CSD20208SS     | 20.00 x 20.00 x 8.00 | 508 x 508 x 203 | 16         | 18         | CP2020 | CP2020G          | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 1            | Quarter-turn | 10.00   | 254    |
| CSD20208SS6    | 20.00 x 20.00 x 8.00 | 508 x 508 x 203 | 16         | 18         | CP2020 | CP2020G          | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 1            | Quarter-turn | 10.00   | 254    |
| CSD24168SS     | 24.00 x 16.00 x 8.00 | 610 x 406 x 203 | 16         | 18         | CP2416 | CP2416G          | 22.20 x 14.20          | 564 x 361             | 22.50 x 14.50        | 572 x 368           | 1            | Quarter-turn | 12.00   | 305    |
| CSD24168SS6    | 24.00 x 16.00 x 8.00 | 610 x 406 x 203 | 16         | 18         | CP2416 | CP2416G          | 22.20 x 14.20          | 564 x 361             | 22.50 x 14.50        | 572 x 368           | 1            | Quarter-turn | 12.00   | 305    |
| CSD24208SS     | 24.00 x 20.00 x 8.00 | 610 x 508 x 203 | 16         | 18         | CP2420 | CP2420G          | 22.20 x 18.20          | 564 x 462             | 22.50 x 18.50        | 572 x 470           | 1            | Quarter-turn | 12.00   | 305    |
| CSD24208SS6    | 24.00 x 20.00 x 8.00 | 610 x 508 x 203 | 16         | 18         | CP2420 | CP2420G          | 22.20 x 18.20          | 564 x 462             | 22.50 x 18.50        | 572 x 470           | 1            | Quarter-turn | 12.00   | 305    |
| CSD24248SS     | 24.00 x 24.00 x 8.00 | 610 x 610 x 203 | 14         | 16         | CP2424 | CP2424           | 22.20 x 22.20          | 564 x 564             | 22.50 x 22.50        | 572 x 572           | 2            | Quarter-turn | 5.00    | 127    |



## CONCEPT™ Wall-Mount Enclosures

| Catalog Number | AxBxC in.             | AxBxC mm         | Door Gauge | Body Gauge | Panel  | Conductive Panel | Panel Size D x E (in.) | Panel Size D x E (mm) | Mounting G x H (in.) | Mounting G x H (mm) | Latches Qty. | Style        | J (in.) | J (mm) |
|----------------|-----------------------|------------------|------------|------------|--------|------------------|------------------------|-----------------------|----------------------|---------------------|--------------|--------------|---------|--------|
| CSD242485S6    | 24.00 x 24.00 x 8.00  | 610 x 610 x 203  | 14         | 16         | CP2424 | CP2424G          | 22.20 x 22.20          | 564 x 564             | 22.50 x 22.50        | 572 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD243085S     | 24.00 x 30.00 x 8.00  | 610 x 762 x 203  | 14         | 16         | CP3024 | CP30240G         | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD243085S6    | 24.00 x 30.00 x 8.00  | 610 x 762 x 203  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD302485S     | 30.00 x 24.00 x 8.00  | 762 x 610 x 203  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD302485S6    | 30.00 x 24.00 x 8.00  | 762 x 610 x 203  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD303085S     | 30.00 x 30.00 x 8.00  | 762 x 762 x 203  | 14         | 16         | CP3030 | CP3030G          | 28.20 x 28.20          | 716 x 716             | 28.50 x 28.50        | 724 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD303085S6    | 30.00 x 30.00 x 8.00  | 762 x 762 x 203  | 14         | 16         | CP3030 | CP3030G          | 28.20 x 28.20          | 716 x 716             | 28.50 x 28.50        | 724 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD362485S     | 36.00 x 24.00 x 8.00  | 914 x 610 x 203  | 14         | 16         | CP3624 | CP3624G          | 34.20 x 22.20          | 869 x 564             | 34.50 x 22.50        | 876 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD362485S6    | 36.00 x 24.00 x 8.00  | 914 x 610 x 203  | 14         | 16         | CP3624 | CP3624G          | 34.20 x 22.20          | 869 x 564             | 34.50 x 22.50        | 876 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD363085S     | 36.00 x 30.00 x 8.00  | 914 x 762 x 203  | 14         | 16         | CP3630 | CP3630G          | 34.20 x 28.20          | 869 x 716             | 34.50 x 28.50        | 876 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD363085S6    | 36.00 x 30.00 x 8.00  | 914 x 762 x 203  | 14         | 16         | CP3630 | CP3630G          | 34.20 x 28.20          | 869 x 716             | 34.50 x 28.50        | 876 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD161210S5    | 16.00 x 12.00 x 10.00 | 406 x 305 x 254  | 16         | 18         | CP1612 | CP1612G          | 14.20 x 10.20          | 361 x 259             | 14.50 x 10.50        | 368 x 267           | 1            | Quarter-turn | 8.00    | 203    |
| CSD161210S56   | 16.00 x 12.00 x 10.00 | 406 x 305 x 254  | 16         | 18         | CP1612 | CP1612G          | 14.20 x 10.20          | 361 x 259             | 14.50 x 10.50        | 368 x 267           | 1            | Quarter-turn | 8.00    | 203    |
| CSD161610S5    | 16.00 x 16.00 x 10.00 | 406 x 406 x 254  | 16         | 18         | CP1616 | CP1616G          | 14.20 x 14.20          | 361 x 361             | 14.50 x 14.50        | 368 x 368           | 1            | Quarter-turn | 8.00    | 203    |
| CSD161610S56   | 16.00 x 16.00 x 10.00 | 406 x 406 x 254  | 16         | 18         | CP1616 | CP1616G          | 14.20 x 14.20          | 361 x 361             | 14.50 x 14.50        | 368 x 368           | 1            | Quarter-turn | 8.00    | 203    |
| CSD162010S5    | 16.00 x 20.00 x 10.00 | 406 x 508 x 254  | 16         | 18         | CP2016 | CP2016G          | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 1            | Quarter-turn | 10.00   | 254    |
| CSD162010S56   | 16.00 x 20.00 x 10.00 | 406 x 508 x 254  | 16         | 18         | CP2016 | CP2016G          | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 1            | Quarter-turn | 10.00   | 254    |
| CSD201610S5    | 20.00 x 16.00 x 10.00 | 508 x 406 x 254  | 16         | 18         | CP2016 | CP2016G          | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 1            | Quarter-turn | 10.00   | 254    |
| CSD201610S56   | 20.00 x 16.00 x 10.00 | 508 x 406 x 254  | 16         | 18         | CP2016 | CP2016G          | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 1            | Quarter-turn | 10.00   | 254    |
| CSD202010S5    | 20.00 x 20.00 x 10.00 | 508 x 508 x 254  | 16         | 18         | CP2020 | CP2020G          | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 1            | Quarter-turn | 10.00   | 254    |
| CSD202010S56   | 20.00 x 20.00 x 10.00 | 508 x 508 x 254  | 16         | 18         | CP2020 | CP2020G          | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 1            | Quarter-turn | 10.00   | 254    |
| CSD202410S5    | 20.00 x 24.00 x 10.00 | 508 x 610 x 254  | 16         | 18         | CP2420 | CP2420G          | 22.20 x 18.20          | 564 x 462             | 22.50 x 18.50        | 572 x 470           | 1            | Quarter-turn | 12.00   | 305    |
| CSD202410S56   | 20.00 x 24.00 x 10.00 | 508 x 610 x 254  | 16         | 18         | CP2420 | CP2420G          | 22.20 x 18.20          | 564 x 462             | 22.50 x 18.50        | 572 x 470           | 1            | Quarter-turn | 12.00   | 305    |
| CSD241610S5    | 24.00 x 16.00 x 10.00 | 610 x 406 x 254  | 16         | 18         | CP2416 | CP2416G          | 22.20 x 14.20          | 564 x 361             | 22.50 x 14.50        | 572 x 368           | 1            | Quarter-turn | 12.00   | 305    |
| CSD241610S56   | 24.00 x 16.00 x 10.00 | 610 x 406 x 254  | 16         | 18         | CP2416 | CP2416G          | 22.20 x 14.20          | 564 x 361             | 22.50 x 14.50        | 572 x 368           | 1            | Quarter-turn | 12.00   | 305    |
| CSD242010S5    | 24.00 x 20.00 x 10.00 | 610 x 508 x 254  | 16         | 18         | CP2420 | CP2420G          | 22.20 x 18.20          | 564 x 462             | 22.50 x 18.50        | 572 x 470           | 1            | Quarter-turn | 12.00   | 305    |
| CSD242010S56   | 24.00 x 20.00 x 10.00 | 610 x 508 x 254  | 16         | 18         | CP2420 | CP2420G          | 22.20 x 18.20          | 564 x 462             | 22.50 x 18.50        | 572 x 470           | 1            | Quarter-turn | 12.00   | 305    |
| CSD242410S5    | 24.00 x 24.00 x 10.00 | 610 x 610 x 254  | 14         | 16         | CP2424 | CP2424G          | 22.20 x 22.20          | 564 x 564             | 22.50 x 22.50        | 572 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD242410S56   | 24.00 x 24.00 x 10.00 | 610 x 610 x 254  | 14         | 16         | CP2424 | CP2424G          | 22.20 x 22.20          | 564 x 564             | 22.50 x 22.50        | 572 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD243010S5    | 24.00 x 30.00 x 10.00 | 610 x 762 x 254  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 22.50 x 28.50        | 572 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD243010S56   | 24.00 x 30.00 x 10.00 | 610 x 762 x 254  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 22.50 x 28.50        | 572 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD302010S5    | 30.00 x 20.00 x 10.00 | 762 x 508 x 254  | 14         | 16         | CP3020 | CP3020G          | 28.20 x 18.20          | 716 x 462             | 28.50 x 18.50        | 724 x 470           | 2            | Quarter-turn | 5.00    | 127    |
| CSD302010S56   | 30.00 x 20.00 x 10.00 | 762 x 508 x 254  | 14         | 16         | CP3020 | CP3020G          | 28.20 x 18.20          | 716 x 462             | 28.50 x 18.50        | 724 x 470           | 2            | Quarter-turn | 5.00    | 127    |
| CSD302410S5    | 30.00 x 24.00 x 10.00 | 762 x 610 x 254  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD302410S56   | 30.00 x 24.00 x 10.00 | 762 x 610 x 254  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD303010S5    | 30.00 x 30.00 x 10.00 | 762 x 762 x 254  | 14         | 16         | CP3030 | CP3030G          | 28.20 x 28.20          | 716 x 716             | 28.50 x 28.50        | 724 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD303010S56   | 30.00 x 30.00 x 10.00 | 762 x 762 x 254  | 14         | 16         | CP3030 | CP3030G          | 28.20 x 28.20          | 716 x 716             | 28.50 x 28.50        | 724 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD362410S5    | 36.00 x 24.00 x 10.00 | 914 x 610 x 254  | 14         | 16         | CP3624 | CP3624G          | 34.20 x 22.20          | 869 x 564             | 34.50 x 22.50        | 876 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD362410S56   | 36.00 x 24.00 x 10.00 | 914 x 610 x 254  | 14         | 16         | CP3624 | CP3624G          | 34.20 x 22.20          | 869 x 564             | 34.50 x 22.50        | 876 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD363010S5    | 36.00 x 30.00 x 10.00 | 914 x 762 x 254  | 14         | 16         | CP3630 | CP3630G          | 34.20 x 28.20          | 869 x 716             | 34.50 x 28.50        | 876 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD363010S56   | 36.00 x 30.00 x 10.00 | 914 x 762 x 254  | 14         | 16         | CP3630 | CP3630G          | 34.20 x 28.20          | 869 x 716             | 34.50 x 28.50        | 876 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD482410S5    | 48.00 x 24.00 x 10.00 | 1220 x 610 x 254 | 14         | 14         | CP4824 | CP4824G          | 46.20 x 22.20          | 1173 x 564            | 46.50 x 22.50        | 1181 x 572          | 1            | 3-point      | 24.00   | 610    |
| CSD482410S56   | 48.00 x 24.00 x 10.00 | 1220 x 610 x 254 | 14         | 14         | CP4824 | CP4824G          | 46.20 x 22.20          | 1173 x 564            | 46.50 x 22.50        | 1181 x 572          | 1            | 3-point      | 24.00   | 610    |
| CSD202012S5    | 20.00 x 20.00 x 12.00 | 508 x 508 x 305  | 14         | 16         | CP2020 | CP2020G          | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 1            | Quarter-turn | 10.00   | 254    |
| CSD202012S56   | 20.00 x 20.00 x 12.00 | 508 x 508 x 305  | 14         | 16         | CP2020 | CP2020G          | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 1            | Quarter-turn | 10.00   | 254    |
| CSD242412S5    | 24.00 x 24.00 x 12.00 | 610 x 610 x 305  | 14         | 16         | CP2424 | CP2424G          | 22.20 x 22.20          | 564 x 564             | 22.50 x 22.50        | 572 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD242412S56   | 24.00 x 24.00 x 12.00 | 610 x 610 x 305  | 14         | 16         | CP2424 | CP2424G          | 22.20 x 22.20          | 564 x 564             | 22.50 x 22.50        | 572 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD302412S5    | 30.00 x 24.00 x 12.00 | 762 x 610 x 305  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD302412S56   | 30.00 x 24.00 x 12.00 | 762 x 610 x 305  | 14         | 16         | CP3024 | CP3024G          | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD303012S5    | 30.00 x 30.00 x 12.00 | 762 x 762 x 305  | 14         | 16         | CP3030 | CP3030G          | 28.20 x 28.20          | 716 x 716             | 28.50 x 28.50        | 724 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD303012S56   | 30.00 x 30.00 x 12.00 | 762 x 762 x 305  | 14         | 16         | CP3030 | CP3030G          | 28.20 x 28.20          | 716 x 716             | 28.50 x 28.50        | 724 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD362412S5    | 36.00 x 24.00 x 12.00 | 914 x 610 x 305  | 14         | 16         | CP3624 | CP3624G          | 34.20 x 22.20          | 869 x 564             | 34.50 x 22.50        | 876 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD362412S56   | 36.00 x 24.00 x 12.00 | 914 x 610 x 305  | 14         | 16         | CP3624 | CP3624G          | 34.20 x 22.20          | 869 x 564             | 34.50 x 22.50        | 876 x 572           | 2            | Quarter-turn | 5.00    | 127    |
| CSD363012S5    | 36.00 x 30.00 x 12.00 | 914 x 762 x 305  | 14         | 14         | CP3630 | CP3630G          | 34.20 x 28.20          | 869 x 716             | 34.50 x 28.50        | 876 x 724           | 2            | Quarter-turn | 5.00    | 127    |
| CSD363012S56   | 36.00 x 30.00 x 12.00 | 914 x 762 x 305  | 14         | 14         | CP3630 | CP3630G          | 34.20 x 28.20          | 869 x 716             | 34.50 x 28.50        | 876 x 724           | 2            | Quarter-turn | 5.00    | 127    |




Catalog numbers ending in 6 are Type 316L stainless steel.

Purchase panels separately. Optional stainless steel, composite and aluminum panels are also available for most sizes.

Optional NEMA style steel and stainless steel panels require conversion kit catalog number CCPM4.



# CONCEPT™ Wall-Mount Enclosures

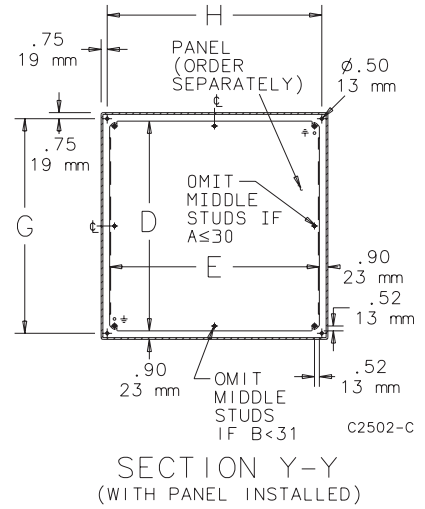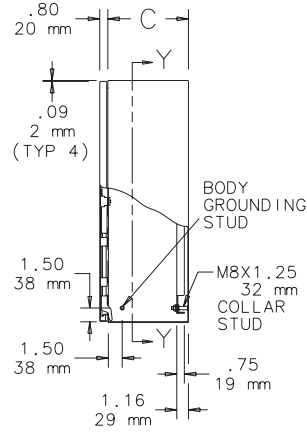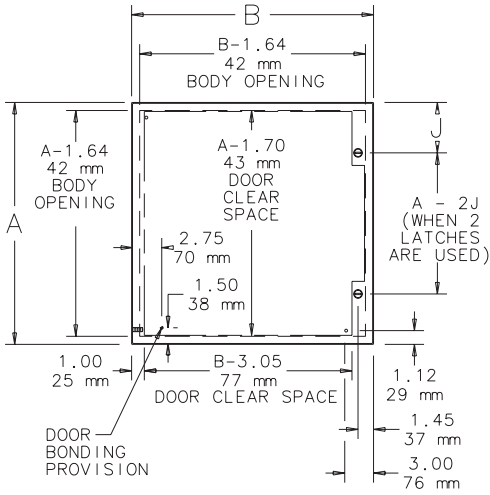

## CONCEPT™ Wall-Mount Enclosures

### Standard Product **One-Door with Window**

| Catalog Number | AxBxC in.             | AxBxC mm        | Door Ga. | Body Ga. | Panel  | Panel Size D x E (in.) | Panel Size D x E (mm) | Mounting G x H (in.) | Mounting G x H (mm) | Window Size M x N (in.) | Window Size M x N (mm) | Latch Qty. | Style        | J (in.) | J (mm) |
|----------------|-----------------------|-----------------|----------|----------|--------|------------------------|-----------------------|----------------------|---------------------|-------------------------|------------------------|------------|--------------|---------|--------|
| CSD12126WSS    | 12.00 x 12.00 x 6.00  | 305 x 305 x 152 | 16       | 18       | CP1212 | 10.20 x 10.20          | 259 x 259             | 10.50 x 10.50        | 267 x 267           | 8.74 x 7.10             | 222 x 180              | 1          | Quarter-turn | 6.00    | 152    |
| CSD16126WSS    | 16.00 x 12.00 x 6.00  | 406 x 305 x 152 | 16       | 18       | CP1612 | 14.20 x 10.20          | 361 x 259             | 14.50 x 10.50        | 368 x 267           | 12.74 x 7.10            | 324 x 180              | 1          | Quarter-turn | 8.00    | 203    |
| CSD20166WSS    | 20.00 x 16.00 x 6.00  | 508 x 406 x 152 | 16       | 18       | CP2016 | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 16.74 x 11.10           | 425 x 282              | 1          | Quarter-turn | 10.00   | 254    |
| CSD20206WSS    | 20.00 x 20.00 x 6.00  | 508 x 508 x 152 | 16       | 18       | CP2020 | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 16.74 x 15.10           | 425 x 384              | 1          | Quarter-turn | 10.00   | 254    |
| CSD20168WSS    | 20.00 x 16.00 x 8.00  | 508 x 406 x 203 | 16       | 18       | CP2016 | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 16.74 x 11.10           | 425 x 282              | 1          | Quarter-turn | 10.00   | 254    |
| CSD20208WSS    | 20.00 x 20.00 x 8.00  | 508 x 508 x 203 | 16       | 18       | CP2020 | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 16.74 x 15.10           | 425 x 384              | 1          | Quarter-turn | 10.00   | 254    |
| CSD24208WSS    | 24.00 x 20.00 x 8.00  | 610 x 508 x 203 | 16       | 18       | CP2420 | 22.20 x 18.20          | 564 x 462             | 22.50 x 18.50        | 572 x 470           | 20.74 x 15.10           | 527 x 384              | 1          | Quarter-turn | 12.00   | 305    |
| CSD24248WSS    | 24.00 x 24.00 x 8.00  | 610 x 610 x 203 | 14       | 16       | CP2424 | 22.20 x 22.20          | 564 x 564             | 22.50 x 22.50        | 572 x 572           | 20.74 x 17.68           | 527 x 449              | 2          | Quarter-turn | 5.00    | 127    |
| CSD30248WSS    | 30.00 x 24.00 x 8.00  | 762 x 610 x 203 | 14       | 16       | CP3024 | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 26.74 x 17.68           | 679 x 449              | 2          | Quarter-turn | 5.00    | 127    |
| CSD161210WSS   | 16.00 x 12.00 x 10.00 | 406 x 305 x 254 | 16       | 18       | CP1612 | 14.20 x 10.20          | 361 x 259             | 14.50 x 10.50        | 368 x 267           | 12.74 x 7.10            | 324 x 180              | 1          | Quarter-turn | 8.00    | 203    |
| CSD201610WSS   | 20.00 x 16.00 x 10.00 | 508 x 406 x 254 | 16       | 18       | CP2016 | 18.20 x 14.20          | 462 x 361             | 18.50 x 14.50        | 470 x 368           | 16.74 x 11.10           | 425 x 282              | 1          | Quarter-turn | 10.00   | 254    |
| CSD202010WSS   | 20.00 x 20.00 x 10.00 | 508 x 508 x 254 | 16       | 18       | CP2020 | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 16.74 x 15.10           | 425 x 384              | 1          | Quarter-turn | 10.00   | 254    |
| CSD242010WSS   | 24.00 x 20.00 x 10.00 | 610 x 508 x 254 | 16       | 18       | CP2420 | 22.20 x 18.20          | 564 x 462             | 22.50 x 18.50        | 572 x 470           | 20.74 x 15.10           | 527 x 384              | 1          | Quarter-turn | 12.00   | 305    |
| CSD242410WSS   | 24.00 x 24.00 x 10.00 | 610 x 610 x 254 | 14       | 16       | CP2424 | 22.20 x 22.20          | 564 x 564             | 22.50 x 22.50        | 572 x 572           | 20.74 x 17.68           | 527 x 449              | 2          | Quarter-turn | 5.00    | 127    |
| CSD302410WSS   | 30.00 x 24.00 x 10.00 | 762 x 610 x 254 | 14       | 16       | CP3024 | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 26.74 x 17.68           | 679 x 449              | 2          | Quarter-turn | 5.00    | 127    |
| CSD202012WSS   | 20.00 x 20.00 x 12.00 | 508 x 508 x 305 | 14       | 16       | CP2020 | 18.20 x 18.20          | 462 x 462             | 18.50 x 18.50        | 470 x 470           | 16.74 x 15.10           | 425 x 384              | 1          | Quarter-turn | 10.00   | 254    |
| CSD302412WSS   | 30.00 x 24.00 x 12.00 | 762 x 610 x 305 | 14       | 16       | CP3024 | 28.20 x 22.20          | 716 x 564             | 28.50 x 22.50        | 724 x 572           | 26.74 x 17.68           | 679 x 449              | 2          | Quarter-turn | 5.00    | 127    |

Purchase panels separately.

Optional NEMA style steel and stainless steel panels require conversion kit catalog number CCPM4.

Material is stainless steel Type 304.

For Conductive Panels, add a "G" to the panel catalog number.

### CONCEPT Single-Door Wall-Mounted Enclosures with Windows

