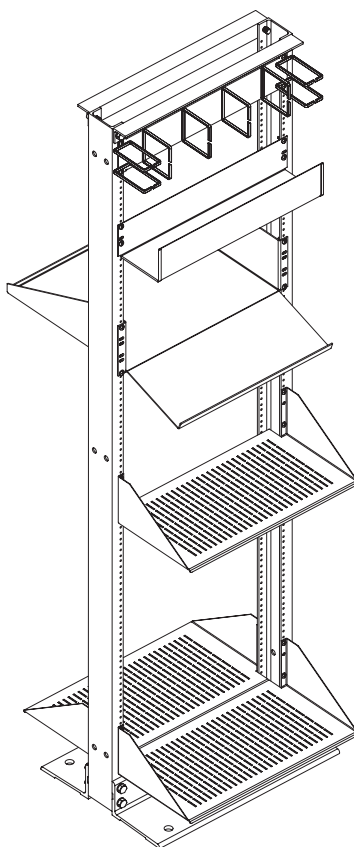


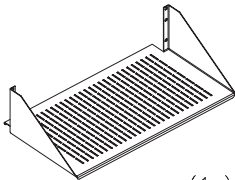
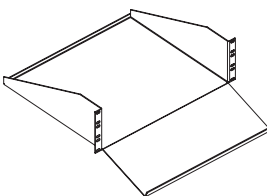
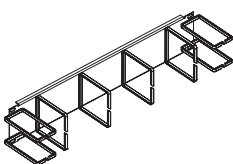
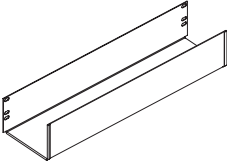
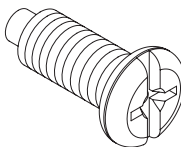
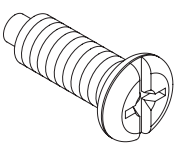
Open Frame Rack Accessories

Shelf, Keyboard Shelf, Cord Trough, Cord Keeper

Étagère Étagère de clavier Cuvette de corde Garde de corde

Estante Estante del teclado Canal de la cuerda Encargado de la cuerda

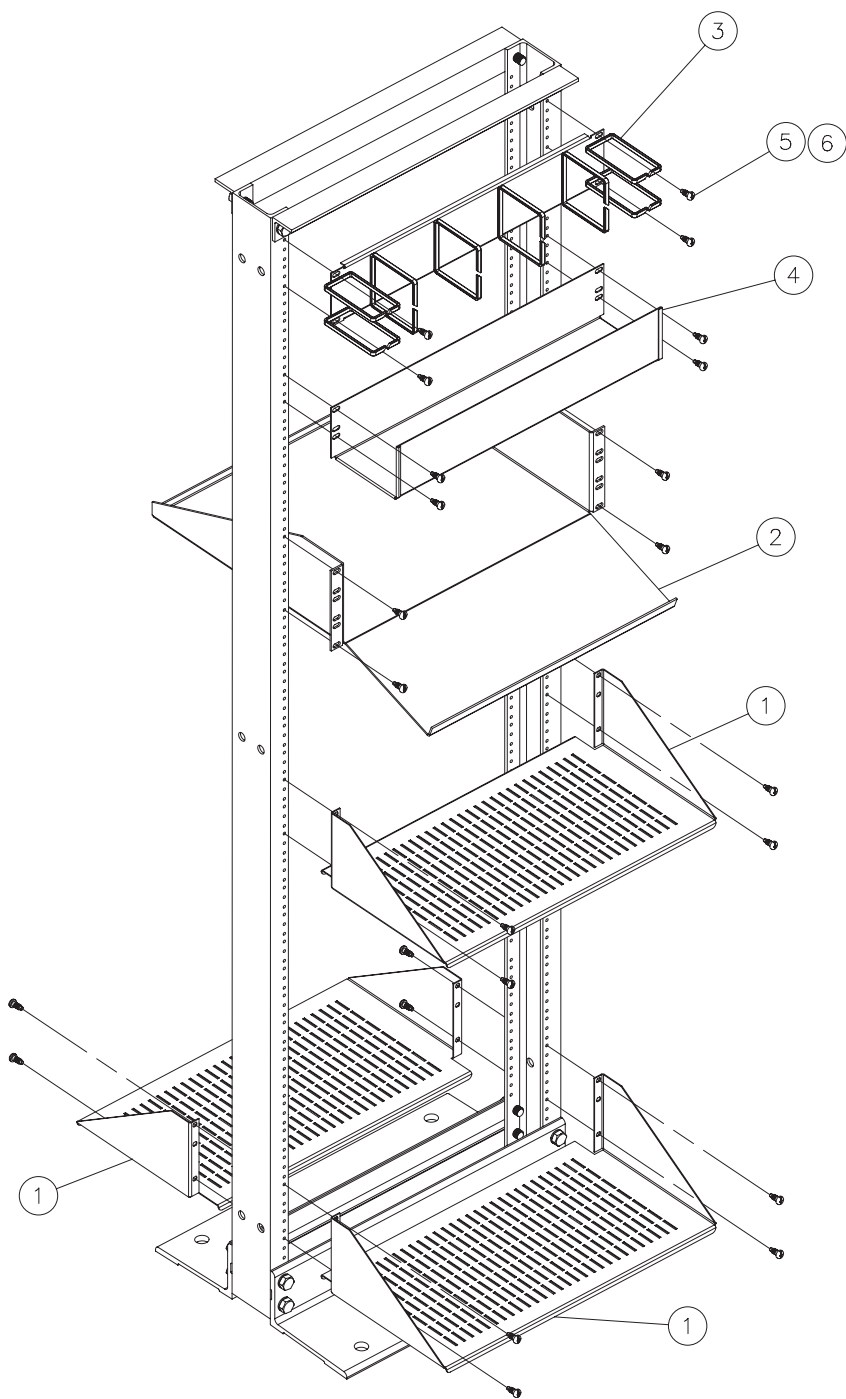


1  { 1x } { 2x }	2  (1x)	3  (1x)
4  (1x)	5 12-24 x .63  (4x)	6 10-32 x .63  (4x)

Note: Select screws to match rack angle thread pattern, typically 12-24 screws for open frame rack mounting or 10-32 screws for cabinet mounting. Only one type of screw may be supplied.

Note: Les vis choisies pour assortir le modèle de fil d'angle de support, en général 12-24 baïse pour le support de chassis ouvert d'armature ou 10-32 vis pour le support de coffret. Seulement un type de vis peut être assuré.

Nota: Los tornillos selectos para emparejar el patrón del hilo de rosca del ángulo del estante, típicamente 12-24 atornillos para el montaje de estante abierto del marco o 10-32 tornillos para el montaje del gabinete. Solamente un tipo de tornillo puede ser provisto.



HOFFMAN (World Headquarters)
2100 Hoffman Way
Anoka, MN 55303-1745 USA
(763) 421-2240 Fax: (763) 422-2178
Customer Service: (763) 422-2211
www.hoffmanonline.com

Canada
HOFFMAN
111 Grangeway Avenue
Suite 504
Scarborough, Ontario M1H 3E9
(416) 289-2770 Fax: (416) 289-2883
1-800-668-2500 (Canada only)

Mexico
HOFFMAN MEXICO, S de RL de CV
Arquímedes No. 33
Piso 1
Col. Palmas Polanco
México, DF
CP 11560
P: (55) 5280-1596
F: (55) 5280-8827 / 5280-8167