


## Open-Frame Rack Cable Managers

### CABLETEK™-EC Vertical Cable Manager

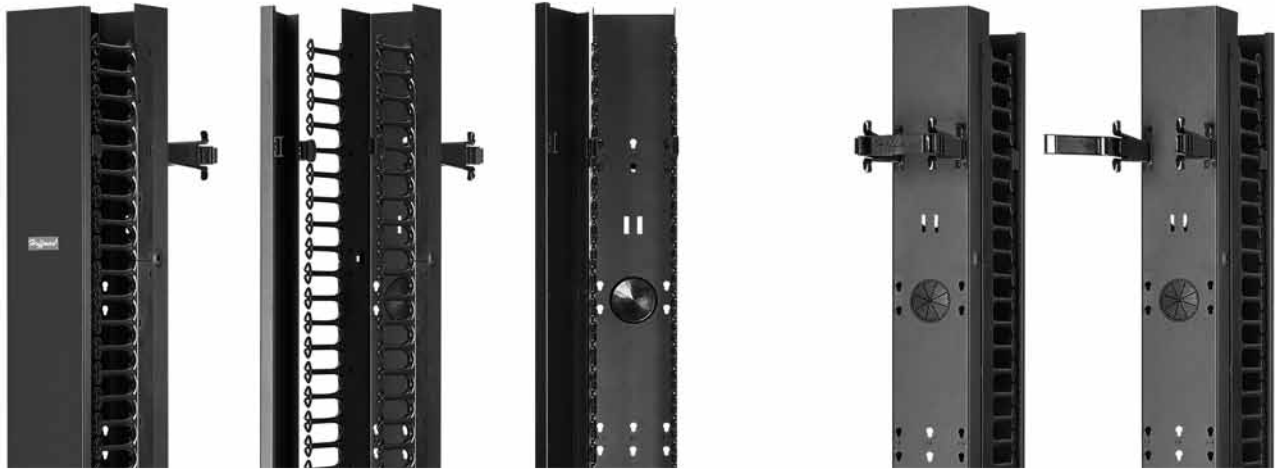

#### Application

Attach CABLETEK™ -EC Vertical Cable Managers to the sides and/or in between open-frame racks to economically provide support, easy access and proper cable management with easy cable installation for Network rack-mount equipment. The front side provides support, management and high cable capacity for patch cords with easy-to-remove front covers standard. The rear of the manager provides the same support for horizontal cabling (Cat 5e, 6, 6A and fiber). CABLETEK-EC Vertical Cable Managers are available in single- and double-sided versions.

#### Features

- Universal mounting pattern for 2- and 4-post open-frame racks
- Easy-to-install with self-aligning, self-captivating carriage bolts for single-sided attachment
- Arrowhead supporting fingers provide easy insertion, removal and alignment of Cat 5e, 6, 6A and other cable types
- Deep cable depth provides smooth transition of cables from vertical to horizontal positions
- Large feed-through holes and pre-scored grommets provide cable feed from front to back of cable manager
- Unobstructed cable access for all rack unit locations
- Extra deep cable channel for maximum cable density has multiple cable tie-down points
- Standard front cover, with field installed snap hinges, provides cable access from right, left or neutral

- Double-sided cable manager has three sets of posts and gates which can be positioned as needed to support and contain cables
- Gates can be opened from the left or right and swing open more than 280 degrees
- Additional posts and gates can be added (order separately)
- The single-sided cable manager can be upgraded with CABLETEK Posts and Gates Kits
- CABLETEK Rear Cover accessory is sold separately and is fully field installable; no tools needed

#### Specifications

- Easy-to-remove front cover is multi-formed, light-weight aluminum with high-strength, black composite snap-on hinge points and hinges right, left or neutral
- Cable channel constructed of multi-formed 14 gauge steel
- Arrowhead supporting fingers are high-strength, black composite with all edges rounded
- Rear posts and gates on double-sided models are high-strength, black composite with all edges rounded

#### Finish


All aluminum and steel components have a black, low-gloss, light-textured RAL 9005 powder-coated finish. All composite parts are provided in matching black.

**Bulletin: DOFRY**

#### Standard Product

Catalog Number	AxBxC in./mm	Description	Width	Height	RU
EC3S7	84.00 x 3.50 x 11.50	Single Sided	3.5 in.	7 ft.	45
	2134 x 89 x 292				
EC3D7	84.00 x 3.50 x 18.00	Double Sided	3.5 in.	7 ft.	45
	2134 x 89 x 457				
EC6S7	84.00 x 6.00 x 11.50	Single Sided	6 in.	7 ft.	45
	2134 x 152 x 292				
EC6D7	84.00 x 6.00 x 18.00	Double Sided	6 in.	7 ft.	45
	2134 x 152 x 457				


# Open-Frame Rack Cable Managers

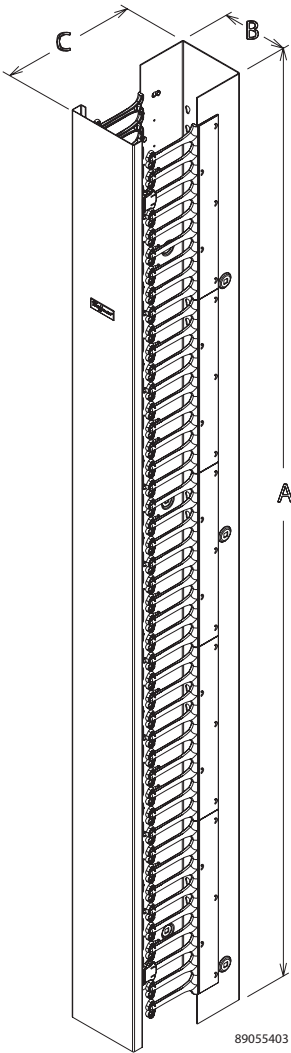

89055403


Cable Fill Chart

Catalog Numbers	Front Capacity @ 60 %	Front Capacity @ 60 %	Front Capacity @ 60 %	Rear Capacity @ 60 %	Rear Capacity @ 60 %	Rear Capacity @ 60 %
Cable Category	5e	6	5A	5e	6B	6A
EC3S7	534	414	287	—	—	—
EC3D7	534	414	287	195	151	105
EC6S7	917	710	493	—	—	—
EC6D7	917	710	493	414	341	236
Arrowhead	85	66	66	—	—	—

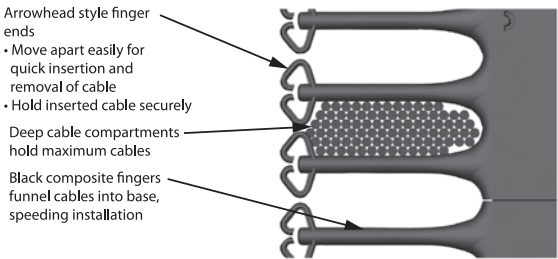

## Open-Frame Rack Cable Managers

### CABLETEK™ Post and Gate Kits

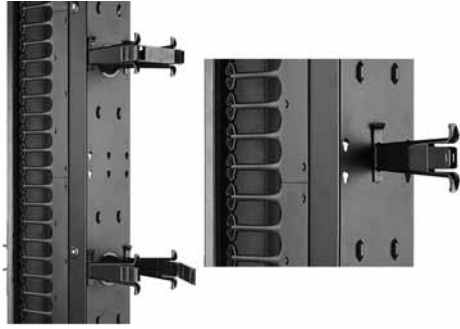


Post and Gate Kits snap together quickly without tools. Each set consists of two posts and one gate. Posts snap into prepunched holes on the backs of all CABLETEK™ Vertical Cable Managers and are easily repositionable without tools. Gates swivel open 280 degrees left or right to allow convenient cable access. When closed, post and gates contain, support and secure large volumes of cables and cable bundles. Molded from black composite material with large radius, these Post and Gates smoothly transition cables from vertical to horizontal positions. Order additional Posts and Gate Kits to add to single- and double-sided cable managers.


Single posts can be used alone as slack spools on the front side of the cable manager.

**Bulletin: DOFRY**

Catalog Number	Description	B (in.)	B (mm)	Pkg. Qty.
DGP3	Post and Gates	3.00	76	10 sets
DGP6	Post and Gates	6.00	152	10 sets
DGP10	Post and Gates	10.00	254	10 sets
DGP12	Post and Gates	12.00	305	10 sets

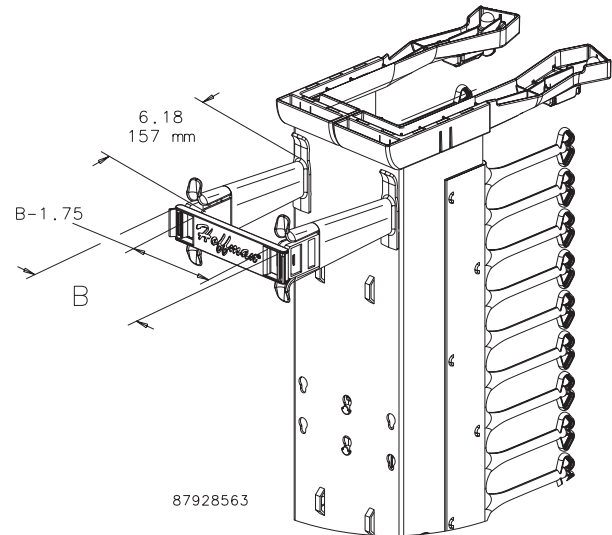

### Rear Cover

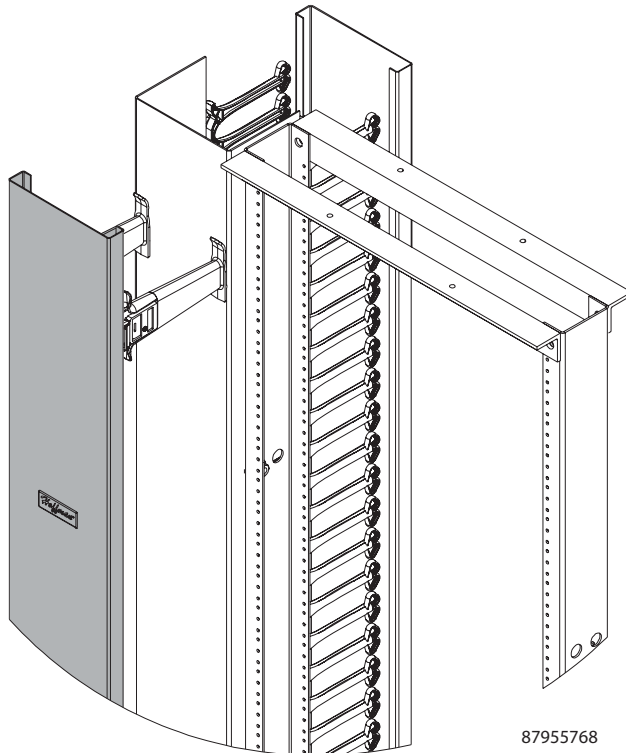

Rear cover is an accessory for all CABLETEK™ Vertical Cable Managers. For double-sided managers, covers attach to provided post and gates. For single-sided managers, appropriate Post and Gates Kit needs to be ordered.

**Bulletin: DOFRY**

Catalog Number	AxBxC in./mm	Fits
EC3C7	84.00 x 3.50 x 1.00 2134 x 89 x 25	3.50 x 7.00 in.
EC6C7	84.00 x 6.00 x 1.00 2134 x 152 x 25	6.00 x 7.00 in.
EC10C7	84.00 x 10.00 x 1.00 2134 x 254 x 25	10.00 x 7.00 in.
EC12C7	84.00 x 12.00 x 1.00 2134 x 305 x 25	12.00 x 7.00 in.

Posts and Gates are required for assembly and to support the rear cover. For single-sided cable managers, order the appropriate Post and Gate accessory kit.



## Open-Frame Rack Cable Managers

### Notes