



CADDY® Fasteners for Stud Wall Applications



ERICO®

New CADDY® Fasteners for Stud Wall Applications are a Snap to Install

The CADDYMAN™ has been hard at work developing new products to save you time and money in the field. If you're looking for ways to speed installation time and lower installation costs – we've got 'em.

We know that efficient installations are what you're looking for. No more searching for scraps for field fabrications. CADDY Fasteners for Stud Wall applications install quickly and many of them will help you comply with the Code!

With innovative installation techniques and code compliant designs, our versatile Stud Wall fasteners will keep you ahead of the game for wood or metal stud applications.

ERICO's CADDY line is the most comprehensive line of UL listed electrical fasteners. Don't fall for non-listed imitations and substitutions. For a complete list of CADDY UL listed fasteners, contact the factory.




For more information about the entire line of CADDY time-saving fasteners, contact ERICO for a copy of the CADDY Field Catalog...or log on to www.caddyman.com to reference the CFC online.



TSGB

One-Piece, Break-Apart Design Makes Our Best Even Better


The TSGB Telescopic Screw Gun Bracket makes mounting electrical boxes between wall studs easy. The unique, one-piece, break-apart design of the TSGB is a CADDY innovation and an industry first - improved design also includes inch marks for pre-assembly. It accommodates various box sizes (4" sq. or 4-11/16" sq.; 1-1/2" or 2-1/8" deep). Interlocking tabs to prevent bar "halves" from accidental disassembly.

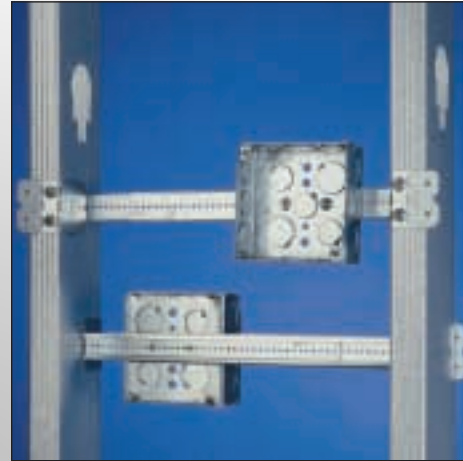

459

Eliminates "Rattlers"; Protects Cable from Nails or Screws

The CADDY 459 is a one-piece, spring steel clip designed to support MC/AC cable to metal stud. This anti-rattle support protects the MC/AC cable from being penetrated by nails or screws and meets NEC 300-4(d). This time- and labor-saving innovation is an industry first, it snaps onto metal stud without any tools and the MC/AC snaps securely into the clip.

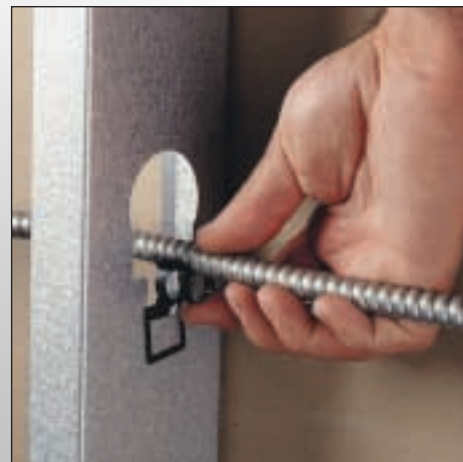

HS3

Attaches Switch Box To Bracket Without Screws

The HS3 Quick Mount Switch Box Support bracket now allows the attachment of a switch box to the bracket with easy-to-bend attachment fingers - without screws. It comes ready for the most common 3-1/2" stud depths but can be easily modified for 2-1/2" wall applications. A far side support leg provides "wobble-free" support and a "v"-notch provides easy alignment, exact positioning and eliminates multiple measuring.



DBM2

A Cost Effective Way To Attach Two Electrical Boxes To Stud

The DBM2 Double Box Mount Support easily supports two electrical boxes, one on each side, of either metal or wood stud - eliminating the need for multiple bracketed assemblies. Made of spring steel, the DBM2 allows you to "press" the assembly in place. Only a screw gun is required for final attachment to metal stud.




J1A35

Far Side Box Support - Back By Popular "Reprimand"

The redesign and reintroduction of the J1A35 Far Side Box Support is a result of customer demands. This wobble-free support bracket allows contractors to easily attach a secure, far side support to the box with a quick tap of a hammer. A bendable leg made of mild steel is ready for 3-1/2" stud depths and a new feature includes a score mark for 2-1/2" stud walls - eliminating the need to stock two different sizes.



For 2-1/2" walls,
bend at the score.

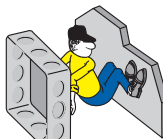


The Best is Back!

CS812

Eliminate Offset Bending of Conduit for All Box Knockouts

The CS812 screw-on conduit support clip accommodates 1/2" and 3/4" EMT conduit and MC/AC cable and eliminates offset bending of conduit. An alignment tab positively locates the fastener on the stud, keeping conduit in line with box knock outs. The CS812 can be used with wood or metal stud. Complies with NEC 348-12. (Also shown is the CADDY H23 Quick Mount Box Hanger.)

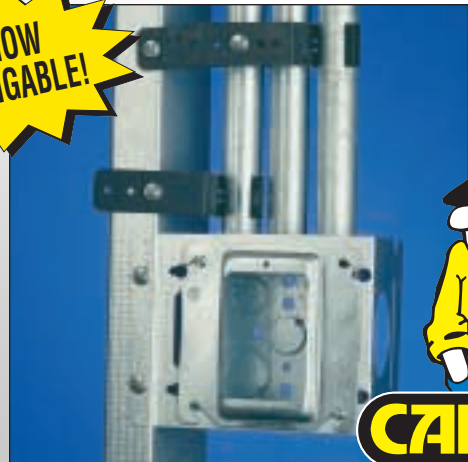


Contact Your Favorite CADDY Distributor for These New and Improved Stud Wall Products



TSGB

UPC #	Catalog #	Description	Qty per Box	Weight per Box
782586		Telescopic Screw Gun Bracket -		
47616	TSGB16	11" - 18"	50	20.44# (9.29 Kg)
47624	TSGB24	17" - 26"	50	31.40# (14.3 Kg)
30470		Low profile, self-tapping screws	1000	4.8# (2.2 Kg)

Assemblies available - contact factory

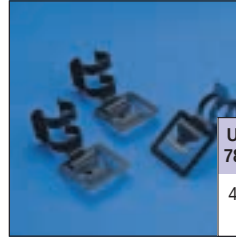

459

UPC #	Catalog #	Description	Qty per Box/Case	Weight per Box
782586				
43676	459	MC/AC through metal stud	100/1000	1.5# (.6 Kg)



J1A35

UPC #	Catalog #	Description	Qty per Box/Case	Weight per Box
782586				
21674	J1A35	Hammer-on Far Side Box Support - for 3-1/2" & 2-1/2" studs	100/1000	4.5# (2.1 Kg)



HS3

UPC #	Catalog #	Description	Qty per Box/Case	Weight per Box
782586				
49045	HS3	Quick Mount Switch Box Support Bracket	100/500	12.60# (5.73 Kg)
30470		Low profile, self-tapping screws	1000	4.8# (2.18 Kg)




CS812

UPC #	Catalog #	Description	Qty per Box
782586			
49045	CS812	Attaches 1/2" and 3/4" EMT conduit, MC/AC to metal or wood stud. For 1-1/2" deep box.	100
30470	CS812D	Attaches 1/2" and 3/4" EMT conduit, MC/AC to metal or wood stud. For 2-1/8" deep box.	100



DBM2

UPC #	Catalog #	Description	Qty per Box/Case	Weight per Box
782586				
43927	DBM2	Double Box Mount Support Bracket	50/300	12# (5.5 Kg)
30470		Low profile, self-tapping screws	1000	4.8# (2.2 Kg)

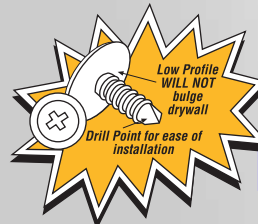

SMS8

Catalog #	Description	Qty per Box	Weight per Box
SMS8	Low profile, self-tapping screws #8 x 1/2" long	1000	4.8# (2.2 Kg)

ERICO[®]

www.erico.com

FASTENING PRODUCTS

Electrical Division Customer Service
Phone: 800-853-0878
Fax: 800-462-4797

Mechanical Division Customer Service
Phone: 800-333-0852
Fax: 800-677-5403

F262B

F364LT00

00860M0

©2000 ERICO, Inc.

Printed in U.S.A.