

CADDY®

CADDY® SPEED LINK

Universal Support System

**FIRE
RATED**



ERICO®

CADDY® SPEED LINK Universal Support Systems

- Are cost-effective alternatives to jack chain, threaded rod and associated hardware
- Reduce installation time, inventory and shipping costs
- Have a small, lightweight design
- Function as stand-alone systems or with an assortment of CADDY® Fasteners
- Include a strong, yet flexible, wire rope with a specially engineered hook or toggle at one end which serves as the means of support
- Consist of all-steel construction
- Carry a DIN 4102-2 fire rating of 30 minutes at 30% of rated load
- Install without drilling and allow objects to be hung at a variety of angles – even from sloped ceilings
- Are shipped in a convenient plastic sleeve that keeps the wire rope looped up until the contractor is ready to install
- Can be installed from the ground using an optional extension tool



Many ERICO® products are UL Listed.
Please contact your ERICO representative for approval information.

CADDY SPEED LINK Applications



Cable Ladder



Signage



Attachment to Beams



Attachment to Strut



Lighting in T-Grids



Cable Tray



High Bay Lighting



CADDY® SPEED LINK LD (1.5 mm)



Benefits:

The CADDY SPEED LINK LD system utilizes a 1.5 mm (0.059 in.) diameter wire rope and holds working loads of up to 20 kg (44 lbs) with a 5:1 safety factor. It is ideal for hanging lighting fixtures, ductwork, speakers, alarm sensors, signage and pipes, among other things.

A universal toggle and Y-toggle for CADDY SPEED LINK LD makes lighting and overhead decking installation even easier. For overhead decking applications, a universal toggle/wire rope assembly is available in 1 m (3.3 ft), 2 m (6.6 ft), 3 m (9.9 ft), 5 m (16.4 ft), 7 m (22.9 ft) and 10 m (32.8 ft) lengths. The universal toggle is identical to standard CADDY SPEED LINK LD, except the hook is replaced with a toggle. An optional Y-toggle

easily hangs lights. It consists of 200 mm (7.8 in.), 300 mm (11.8 in.), 500 mm (19.6 in.) or 800 mm (31.4 in.) length of wire rope with a toggle on each end. The center of the wire rope is looped and crimped. It is ideal as a support or safety wire for lighting fixtures.

A small, aesthetically pleasing locking device completes the CADDY SPEED LINK LD assembly. This low-profile stainless-steel locking device helps ensure stability and allows for additional adjustment after wire insertion. The lock can be released with the included release tool or with a small screwdriver.

Features:

- Is also available with universal toggles and Y-toggles for lighting and overhead decking applications
- Holds working loads of 20 kg (44 lbs) with a 5:1 safety factor
- Comes with a sleek, low-profile locking device that minimizes visual impact
- Allows for easy adjustments of supported objects both during and after installation
- Is available with stainless steel wire rope for applications where a higher level of corrosion resistance is required
- Works with a variety of CADDY Fasteners including beam clamps and purlin clips

CADDY® SPEED LINK (2 mm / 3 mm)



Benefits:

CADDY® SPEED LINK is available in 2 mm and 3 mm wire rope. The 2 mm (0.079 in.) wire rope supports static loads up to 45 kg (100 lbs). The 3 mm (0.118 in.) wire rope handles static loads up to 90 kg (200 lbs). Both systems have a 5-to-1 safety factor.

The unique steel locking device on CADDY SPEED LINK accommodates both 2 mm and 3 mm wire rope. The lock can be released with the included release tool or with a small screwdriver.

The CADDY SPEED LINK system is available in 1 m (3.3 ft), 2 m (6.6 ft), 3 m (9.9 ft), 5 m (16.4 ft), 7 m (22.9 ft) and 10 m (32.8 ft) lengths. It supports a wide-range of applications including cable tray, lighting, ductwork, pipe and tube, conduit, strut profiles and signage from overhead structural building members.

Greater lengths can be achieved by stringing two or more systems together with the use of locking devices.

Features:

- Reduces installation time and inventory
- Works with a variety of CADDY® Fasteners or as a stand-alone system without drilling into the building structure
- Increases installation versatility by allowing objects to be hung at an angle
- Allows for easy adjustments of supported objects both during and after installation
- Minimizes vibration and system wear and tear with a strong, yet flexible wire rope
- Holds working loads of up to 90 kg (200 lbs) with a 5:1 safety factor

CADDY® SPEED LINK LD 1.5 mm (.059 in.) Diameter*

	Part Number	Wire Rope Length	Quantity per Box/Bag	Working Load (LBS.) (KG.)	
HOOK					
	SLD15L1	1 m (3.3 ft)	100	44	20
	SLD15L2	2 m (6.6 ft)	100	44	20
	SLD15L3	3 m (9.9 ft)	100	44	20
	SLD15L5	5 m (16.4 ft)	100	44	20
	SLD15L7	7 m (22.9 ft)	100	44	20
	SLD15L10	10 m (32.8 ft)	100	44	20
	2-PACKS - HOOK – ALL STAINLESS STEEL				
	SLD15L2S	2 m (6.6 ft)	2	44	20
	SLD15L5S	5 m (16.4 ft)	2	44	20
	SLD15L10S	10 m (32.8 ft)	2	44	20
	2-PACKS – HOOK				
	SLD15L1TP	1 m (3.3 ft)	2	44	20
	SLD15L2TP	2 m (6.6 ft)	2	44	20
	SLD15L3TP	3 m (9.9 ft)	2	44	20
	SLD15L5TP	5 m (16.4 ft)	2	44	20


CADDY® SPEED LINK LD Toggles 1.5 mm (.059 in.) Diameter*

	Part Number	Wire Rope Length	Quantity per Box/Bag	Working Load (LBS.) (KG.)	
TOGGLE					
	SLD15L1T	1 m (3.3 ft)	20	44	20
	SLD15L2T	2 m (6.6 ft)	20	44	20
	SLD15L3T	3 m (9.9 ft)	20	44	20
	SLD15L5T	5 m (16.4 ft)	20	44	20
	SLD15L7T	7 m (22.9 ft)	20	44	20
	SLD15L10T	10 m (32.8 ft)	20	44	20
	2-PACKS – TOGGLE				
	SLD15L1TTP	1 m (3.3 ft)	2	44	20
	SLD15L2TTP	2 m (6.6 ft)	2	44	20
	SLD15L3TTP	3 m (9.9 ft)	2	44	20
	SLD15L5TTP	5 m (16.4 ft)	2	44	20
	SLD15L10TTP	10 m (32.8 ft)	2	44	20
Y-TOGGLE					
	SLD15Y200	200 mm (7.8 in)	20	44	20
	SLD15Y300	300 mm (11.8 in)	20	44	20
	SLD15Y500	500 mm (19.6 in)	20	44	20
	SLD15Y800	800 mm (31.4 in)	20	44	20
	2-PACKS – Y-TOGGLE				
	SLD15Y500TP	500 mm (19.6 in)	2	44	20
	SLD15Y800TP	800 mm (31.4 in)	2	44	20
QUAD TOGGLE					
	SLD15QT250	250 mm (9.8 in)	20	44	20
INTEGRAL Y-TOGGLE					
	SLD15Y300L3	300 mm (11.8 in) / 3 m (9.9 ft)	20	44	20



*Galvanized steel wire rope unless denoted otherwise.

CADDY® SPEED LINK 2 mm (.079 in.) Diameter*

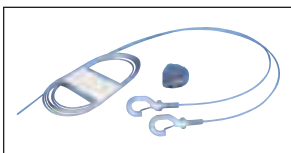	Part Number	Wire Rope Length	Quantity per Box/Bag	Working Load (LBS.) (KG.)	
HOOK					
	SLD2L1	1 m (3.3 ft)	100	100	45
	SLD2L2	2 m (6.6 ft)	100	100	45
	SLD2L3	3 m (9.9 ft)	100	100	45
	SLD2L5	5 m (16.4 ft)	50	100	45
	SLD2L7	7 m (22.9 ft)	25	100	45
	SLD2L10	10 m (32.8 ft)	25	100	45
	INDIVIDUALLY PACKAGED				
	SLD2L1BP	1 m (3.3 ft)	1	100	45
	SLD2L2BP	2 m (6.6 ft)	1	100	45
	SLD2L3BP	3 m (9.9 ft)	1	100	45
SLD2L5BP	5 m (16.4 ft)	1	100	45	
SLD2L10BP	10 m (32.8 ft)	1	100	45	
Y-TOGGLE					
	SLD2Y300	300 mm (11.8 in)	100	100	45
CADDY SPEED LINK - 2 mm DIAMETER INTEGRAL Y-TOGGLES					
	SLD2Y300L2	300 mm (11.8 in) / 2 m (6.5 ft)	20	100	45
	SLD2Y300L3	300 mm (11.8 in) / 3 m (9.8 ft)	20	100	45
	SLD2Y300L5	300 mm (11.8 in) / 5 m (16.4 ft)	20	100	45
	SLD2Y300L7	300 mm (11.8 in) / 7 m (22.9 ft)	20	100	45
	SLD2Y300L10	300 mm (11.8 in) / 10 m (32.8 ft)	10	100	45
CADDY SPEED LINK - 2 mm DIAMETER Y-HOOKS					
	SLD2YH500	500 mm (19.6 in)	10	100	45
	SLD2YH800	800 mm (31.4 in)	10	100	45
INTEGRAL Y-HOOKS					
	SLD2YH500L2	500 mm (19.6 in) / 2 m (6.5 ft)	20	100	45
	SLD2YH500L3	500 mm (19.6 in) / 3 m (9.8 ft)	20	100	45
	SLD2YH500L7	500 mm (19.6 in) / 7 m (22.9 ft)	20	100	45
	2-PACKS - INTEGRAL Y-HOOKS				
	SLD2YH500L2TP	500 mm (19.6 in) / 2 m (6.5 ft)	2	100	45
	SLD2YH500L3TP	500 mm (19.6 in) / 3 m (9.8 ft)	2	100	45
	SLD2YH500L7TP	500 mm (19.6 in) / 7 m (22.9 ft)	2	100	45

CADDY® SPEED LINK 3 mm (.118 in.) Diameter*

	Part Number	Wire Rope Length	Quantity per Box/Bag	Working Load (LBS.)	(KG.)	
	HOOK					
	SLD3L1	1 m (3.3 ft)	100	200	90	
	SLD3L2	2 m (6.6 ft)	100	200	90	
	SLD3L3	3 m (9.9 ft)	50	200	90	
	SLD3L5	5 m (16.4 ft)	50	200	90	
	SLD3L7	7 m (22.9 ft)	25	200	90	
	SLD3L10	10 m (32.8 ft)	25	200	90	
	INDIVIDUALLY PACKAGED					
	SLD3L1BP	1 m (3.3 ft)	1	200	90	
	SLD3L2BP	2 m (6.6 ft)	1	200	90	
	SLD3L3BP	3 m (9.9 ft)	1	200	90	
	SLD3L5BP	5 m (16.4 ft)	1	200	90	
	SLD3L10BP	10 m (32.8 ft)	1	200	90	
	STAINLESS STEEL WIRE ROPE					
	SLD3L2SS	2 m (6.6 ft)	100	200	90	
	SLD3L3SS	3 m (9.9 ft)	50	200	90	
	CADDY SPEED LINK - 3 mm DIAMETER Y-HOOKS					
		SLD3YH500	500 mm (19.6 in)	10	200	90
	SLD3YH800	800 mm (31.4 in)	20	200	90	

*Galvanized steel wire rope unless denoted otherwise.

CADDY® SPEED LINK Tools & Accessories

	Part Number	Description	Quantity per Box
	SLWC	CADDY® SPEED LINK Wire Cutter	1
	SLADCP	CADDY SPEED LINK Air Duct Corner Protector	10
	SLADS	CADDY SPEED LINK Air Duct Support Attachment	100
	SLEBM6	Eye Bolt M6; 30 mm long	100
	SLEBM8	Eye Bolt M8; 40 mm long	100
	SLEB250	Eye Bolt 1/4-20 Thread	100
	SLEB375	Eye Bolt 3/8-16 Thread	100
	SLEBWS	Wood Screw Eye Bolt	100
	CFEB05	Concrete Fixing Eyebolt Screw	100
	SLWPT	CADDY SPEED LINK Wire Insulation Protection Tube	82 ft. (25 m)
	SL1214	CADDY SPEED LINK Clip .468 - .562 MC/AC Cable	100
	SL1518	MC/AC Clip 0.500" – 0.718"	100
	SLLC250†	CADDY SPEED LINK Lighting Clip, 1/4"	200
	VAFT	Installation Tool for VF & AF Assemblies	1




† 50 pound (22 Kg) ultimate static load limit. Not to be used as a lifting device.

CADDY® SPEED LINK Fire Rating Information

CADDY SPEED LINK meets the requirements of DIN 4102-2 for 30 minutes at 30 percent of rated load.



Standardized Temperature Curve (ETK) in DIN 4102-2

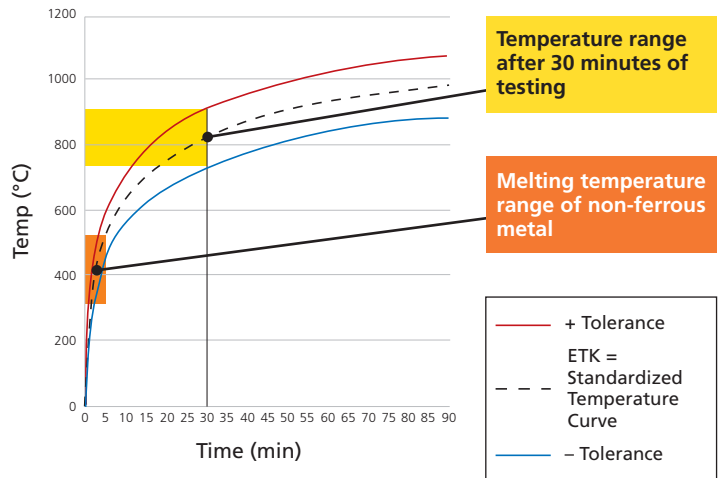

WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

WARRANTY

ERICO products are warranted to be free from defects in material and workmanship at the time of shipment. NO OTHER WARRANTY, WHETHER EXPRESS OR IMPLIED (INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE), SHALL EXIST IN CONNECTION WITH THE SALE OR USE OF ANY ERICO PRODUCTS. Claims for errors, shortages, defects or nonconformities ascertainable upon inspection must be made in writing within 5 days after Buyer's receipt of products. All other claims must be made in writing to ERICO within 6 months from the date of shipment or transport. Products claimed to be nonconforming or defective must, upon ERICO's prior written approval in accordance with its standard terms and procedures governing returns, promptly be returned to ERICO for inspection. Claims not made as provided above and within the applicable time period will be barred. ERICO shall in no event be responsible if the products have not been stored or used in accordance with its specifications and recommended procedures. ERICO will, at its option, either repair or replace nonconforming or defective products for which it is responsible or return the purchase price to the Buyer. THE FOREGOING STATES BUYER'S EXCLUSIVE REMEDY FOR ANY BREACH OF ERICO WARRANTY AND FOR ANY CLAIM, WHETHER SOUNDING IN CONTRACT, TORT OR NEGLIGENCE, FOR LOSS OR INJURY CAUSED BY THE SALE OR USE OF ANY PRODUCT.

LIMITATION OF LIABILITY

ERICO excludes all liability except such liability that is directly attributable to the willful or gross negligence of ERICO's employees. Should ERICO be held liable its liability shall in no event exceed the total purchase price under the contract. ERICO SHALL IN NO EVENT BE RESPONSIBLE FOR ANY LOSS OF BUSINESS OR PROFITS, DOWNTIME OR DELAY, LABOR, REPAIR OR MATERIAL COSTS OR ANY SIMILAR OR DISSIMILAR CONSEQUENTIAL LOSS OR DAMAGE INCURRED BY BUYER.

cULus is a registered trademark of Underwriters Laboratories, Inc.

 


www.erico.com



AUSTRALIA

Phone +61-2-9751-8500
Fax +61-2-9475-5334



CHINA

Phone +86-21-3430-4878
Fax +86-21-5831-8177



HUNGARY

Phone +068-00-165-38
Fax +31-13-583-5499



NORWAY

Phone +800-100-73
Fax +800-100-66



SWITZERLAND

Phone +0800-558-697
Fax +0800-559-615



BELGIUM

Phone +0800-757-48
Fax +0800-757-60



DENMARK

Phone +808-89-373
Fax +808-89-372



INDONESIA

Phone +62-21-575-0941
Fax +62-21-575-0942



POLAND

Phone +48-71-374-4022
Fax +48-71-374-4043



THAILAND

Phone +66-2-267-5776
Fax +66-2-636-6988



BRAZIL

Phone +55-11-3623-4333
Fax +55-11-3621-4066



FRANCE

Phone +33-4-77-365-656
Fax +33-4-77-553-789



ITALY

Phone +39-02-8474-2250
Fax +39-02-8474-2251



SINGAPORE

Phone +65-6-268-3433
Fax +65-6-268-1389



**UNITED ARAB
EMIRATES**

Phone +971-4-881-7250
Fax +971-4-881-7270



CANADA

Phone +1-800-677-9089
Fax +1-800-677-8131



GERMANY

Phone +0-800-189-0272
Fax +0-800-189-0274



MEXICO

Phone +52-55-5260-5991
Fax +52-55-5260-3310



SPAIN

Phone +34-93-467-7726
Fax +34-93-467-7725



UNITED KINGDOM

Phone +0808-2344-670
Fax +0808-2344-676



CHILE

Phone +56-2-370-2908
Fax +56-2-370-2914



HONG KONG

Phone +852-2764-8808
Fax +852-2764-4486



NETHERLANDS

Phone +31-13-583-5400
Fax +31-13-583-5499



SWEDEN

Phone +0207-909-08
Fax +0207-989-64



UNITED STATES

Phone +1-440-248-0100
Fax +1-440-248-0723