

pcmcia fiber adapters


PCM32-FX-SC-01

Fast Ethernet PCMCIA Fiber Adapter Cards: Fast Ethernet 100BASE-FX



Fast Ethernet PCMCIA cards provide a 100BASE-FX fiber port to deliver fiber optic connectivity to the laptop in high-security, fiber rich LAN environments. Offered in a high-performance 32-bit CardBus version to match virtually any laptop PC and help save money by eliminating the need for a docking station and a fixed, fiber NIC.

Applications

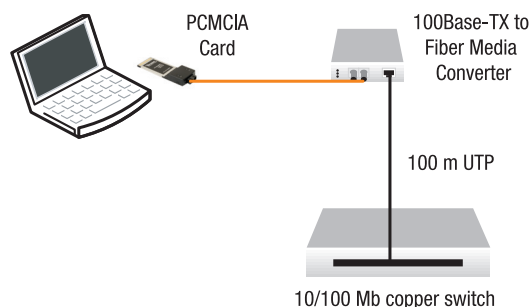

Ordering Information

PCM32-FX-SC-01
100BASE-FX 1300nm multimode (SC)
[2 km/1.2 mi.] Link Budget: 12.0 dB

Specifications

Standards	IEEE Std. 802.3 PCMCIA Type II Car dBus PCMCIA Release 2.x JEIDA 4.x
Card Slot	PC Card 68-pin connector to PC
Status LEDs	PCM32-FX-xx-01: LINK/ACT: ON = communication link; Flashing = activity on link FDX/COL: ON = full duplex link; Flashing = collisions occurring
LAN Drivers	PCM32-FX-xx-01: NetWare 3.x, 4.0, NetWare DOS Client ODI Windows 95, 98, ME, 2000, XP, NT 3.51, NT 4.0 Windows for Workgroup 3.1/3.11, Linux
Dimensions	Width: 2.1" [54 mm] Depth: 4.7" [120 mm] Height: 0.6" [16 mm]
Power	0.7A @ +5V max.
Environment	0° – 50°C; 5% – 95% humidity non-condensing; 0 – 10,000 ft. altitude
Shipping Weight	1 lb. [0.45 kg]
Compliance	FCC Class A Part 15, CE Mark
Warranty	Lifetime