

QuickPort® BNC Bulkhead Modules & Blank Modules

APPLICATION

Nickel or gold-plated female-to-female connector with twist-on front and rear connections. Pass through design applications; high-end video, home theater, CCTV and LAN. Cable: shielded video and data cable, 75-Ohm. Fill unused QuickPort openings with QuickPort blank modules.



SPECIFICATION

Modules for coaxial cable shall be individual snap-in style female-to-female bulkhead adapters, and shall fit all other installed Leviton telecommunications wall-plates, outlets and field-configurable patch panels and patch blocks. Bulkhead modules shall be available in six colors (ivory, white, almond, light almond, grey, and black) to match the housings or provide unique color-coding for port I.D. Modules shall be UL listed. All plastics used in construction of the module bodies shall be fire-retardant with a UL flammability rating of 94V-0.

FEATURES

- Female-female BNC bulkhead adapters
- Twist-on front and rear BNC plugs for easy termination
- Available in nickel and gold-plated finishes

PHYSICAL SPECIFICATIONS

Dimensions

BNC Bulkhead: .650"H x .600"W x 1.40"D
Blank Module: .650"H x .600"W x .90"D

Materials

Snap-in module bodies are high-impact, fire-retardant plastic rated UL 94V-0.

DESIGN CONSIDERATIONS

- QuickPort BNC bulkhead and blank modules snap into any housing with the QuickPort name: flush and surface mount outlets; Multimedia Outlet System (with adapter); patch panels; and patch blocks.
- Check clearance behind proposed location of bulkhead BNC module, to ensure space for proper bend-radius.
- Bulkhead BNC and blank modules are available in six colors (ivory, white, almond, light almond, grey, and black) to match the housings or provide unique color-coding for port I.D.
- BNC bulkhead module is for cables that have male connectors already installed on cables.

STANDARDS COMPLIANCE


cULus Listed

WARRANTY INFORMATION


For a copy of Leviton product warranties, visit www.leviton.com.

ELECTRONIC FILES

For CAD files, Typical specs, or Dimensional Line Art. (.DXF, .DWG, MS-DOS.eps or .TXT), visit www.leviton.com.

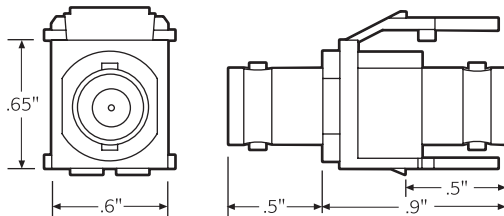

41084-BxF 40832-0Bx

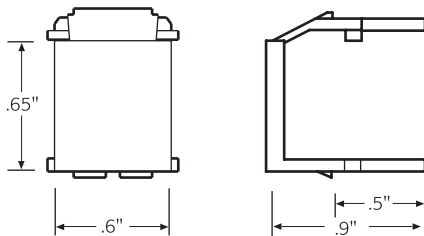

41084-BxB

41084-Bxx 40832-0Bx

PART NUMBERS

Description	Part No.
BNC Bulkhead Module, Nickel Plated	41084-BxF
BNC Bulkhead Module, Gold Plated	40832-0Bx
Blank Module	41084-BxB

x = Colors: Ivory (I), White (W), Grey (G), Black (E), Almond (A), Light Almond (T)

