




## GE Magnetic Contacts

### R1075 Series

*<sup>3</sup>/<sub>8</sub>" Diameter Press Fit with Wire Leads*

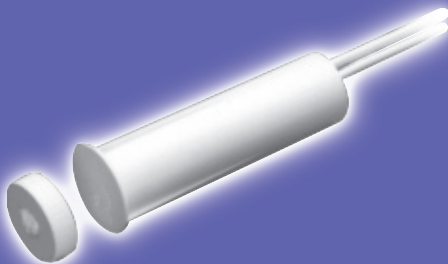

<i>Gap Distance</i>	<i>Closed Loop</i>
<i><sup>1</sup>/<sub>2</sub>"</i>	<i>R1075</i>
<i>Color</i>	<i>White</i>
<i>Quantity</i>	<i>10</i>

100% **TESTED**



604S  
Connectors and Switches

R1075-N



0 46188 06998 9

# R1075 Mini-Max Magnetic Contacts

3/8" Diameter Press Fit with Wire Leads

## Installation Instructions

### Switch

- 1: Drill 3/8" dia. hole 1 1/8" deep for the contact.
- 2: Connect contact leads to security system loop and test for continuity.
- 3: Lightly coat the contact RTV mounting compound (Sentrol part number 1905) and insert into hole.

### Magnet


- 1: Mount magnet to double-sided tape (included) and affix to window frame.
- 2: Or, if using stainless steel screw (included), drill 1/16" dia. (using magnet center hole as a guide) and mount using #4 x 1/2" stainless steel screw (included). Use caution if using screw other than the one provided, as it will effect the gap performance.
- 3: Care should be taken not to over tighten screw to avoid damaging magnet or stripping hole.

### Recess/Flush Mount Magnet

- 1: Drill 7/16" dia. by approximately 1/8" deep .
- 2: Coat magnet with RTV silicon adhesive and mount into hole.

NOTE: When surface mounting magnet be sure there is enough clearance to prevent the magnet from becoming damaged when closing the window or door.

### Standard Gap

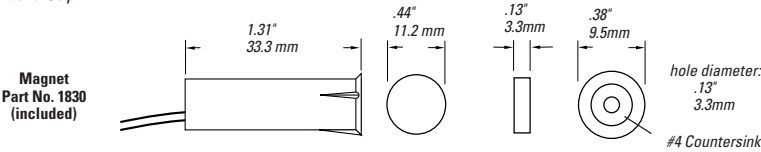

## C-UL-US Specifications

Part Number	Loop Type	Electrical Configuration	Gap Distance
R1075	Closed	N/O	1/2"

\*\* European Union Specifications: 48 VAC/DC Max., 0.5 Amp

### FORM A (R1075)

Voltage: 100 VAC/DC Max

Current: 0.5 A Max

Power: 7.5 W Max

WARNING: Each electrical rating is an individual maximum and cannot be exceeded!

## ULC Specifications

All Contacts: 30 VDC, 50 mA max

Gap Specifications:\*



GE Interlogix

www.GE-Interlogix.com

12345 SW Leveton Drive  
Tualatin, OR 97062  
Phone: 503-692-4052  
USA & Canada: 800-547-2556  
Technical Service: 800-648-7424  
Faxback: 800-483-2495

2266 Second Street North  
North St. Paul, MN 55109  
Phone: 651-777-2690  
USA & Canada: 800-777-5484  
Technical Service: 800-777-2624

Made in Taiwan