



SENTROL

1035 Series

Minature Surface Mount Self-Adhesive
Magnetic Contacts

Gap distance	Closed loop	SPDT
5/8"	1035	
1"	1035W	1037W

Color	White	Mahogany brown	Grey
Quantity	10		



1035-N



100% TESTED




0 46188 01169 8

1035 Series Miniature Surface Mount Self-Adhesive Magnetic Contacts

Installation Instructions

1035, 1035W, 1037W

Determine the positions of contact and magnet. Clean surface with alcohol before attaching contact and magnet (this will improve the adhesion of the urethane foam to the surface). Remove protective backing from foam strip, press contact and magnet firmly to surface.

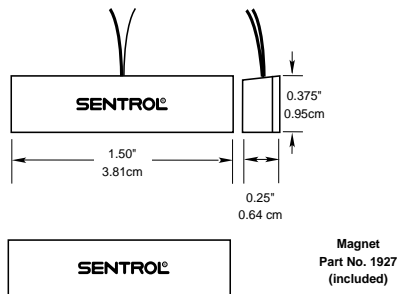

UL Specifications

** European Union Specifications: 48 VAC/DC Max., 0.5 Amp

Part Number	Loop Type	Electrical Configuration	Gap Distance*
1035	Closed	N/O	5/8"
1035W	Closed	N/O	1"
1037W	Open or Closed	SPDT	1"

**** FORM A (1035, 1035W)**
Voltage: 100 VAC/DC Max
Current: 0.5 A Max
Power: 7.5 W Max

FORM C (1037W)
Voltage: 30 V Max
Current: 0.25 A Max
Power: 3.0 W Max

* Gap Specifications are nominal and may vary $\pm 20\%$. Gap Specifications are for switch to make. Break distance is approximately 1.1 to 1.5 times make.

ULC Specifications

All Contacts: 30 V DC, 50 ma max.

Gap Specifications:
See UL Gap Specifications



PH 503.692.4052

USA & Canada: 800.547.2556

Technical Service: 800.648.7424 FaxBack: 800.483.2495

www.sentrol.com www.interlogixsecurity.com

©2001 Interlogix, Inc.

Interlogix, Caddx, ESL, ITI and Sentrol are trademarks of Interlogix, Inc.

PK-0989 Rev F 10/01