



GE Magnetic Contacts

R1125T Series

$\frac{3}{8}$ " Diameter Press Fit with Mini-Max Magnets



<i>Gap Distance</i>	<i>Closed Loop</i>
<i>Regular $\frac{1}{2}$"</i>	<i>R1125T</i>
<i>Wide $\frac{7}{8}$"</i>	<i>R1125TW</i>

<i>Color</i>	<i>White</i>
<i>Quantity</i>	<i>10</i>

100% TESTED



604S

Connectors and Switches

R1125T-N



0 46188 06993 4

R1125T Series

3/8" Diameter Press Fit with Mini-Max Magnets

Installation Instructions

Switch

- 1: Drill 3/8" dia. hole 1 1/8" deep for the contact.
- 2: Strip wire from security system loop, insert into terminal block and tighten. Test for continuity.
- 3: Lightly coat the contact RTV mounting compound (GE part number 1905) and insert into respective hole.

Magnet


- 1: Mount magnet to double-sided tape (included) and affix to window frame.
- 2: Or, if using stainless steel screw (included), drill 1/16" dia. (using magnet center hole as a guide) and mount using #4 x 1/2" stainless steel screw (included). Use caution if using screw other than the one provided, as it will effect the gap performance.
- 3: Care should be taken not to over tighten screw to avoid damage to magnet or stripping hole.

Recess/Flush Mount Magnet

- 1: Drill 7/16" dia. hole (standard gap) or 5/8" dia. hole (wide gap) by approximately 1/8" deep .
- 2: Coat magnet with RTV silicon adhesive and mount into hole.

NOTE: When surface mounting magnet be sure there is enough clearance to prevent the magnet from becoming damaged when closing the window or door.

Standard Gap

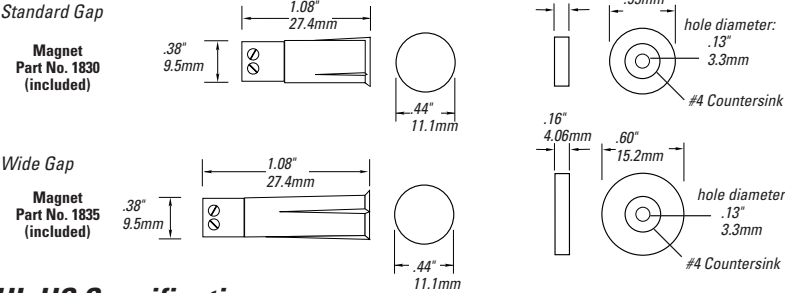

C-UL-US Specifications

Part Number	Loop Type	Electrical Configuration	Gap Distance
R1125T	Closed	N.O.	1/2"
R1125TW	Closed	N.O.	7/8"

** European Union Specifications: 48 V AC/DC max, 0.5 Amp

FORM A (R1125T, R1125TW)

Voltage: 100 V AC/DC max

Current: 0.5 A max

Power: 7.5 W max

WARNING: Each electrical rating is an individual maximum and cannot be exceeded!

C-UL Specifications



GE Interlogix

www.GE-Interlogix.com

12345 SW Leveton Drive
Tualatin, OR 97062
Phone: 503-692-4052
USA & Canada: 800-547-2556
Technical Service: 800-648-7424
Faxback: 800-483-2495

2266 Second Street North
North St. Paul, MN 55109
Phone: 651-777-2690
USA & Canada: 800-777-5484
Technical Service: 800-777-2624

Made in Taiwan