



SENTROL

1082 Series

Screw Mount with Leads

Magnetic Contacts

| Gap distance | Closed loop | Open loop | SPDT |
|--------------|-------------|-----------|------------|
| 1" | 1082 | | |
| 2" | | 1083W | 1084W |
| 3/4" | | | 1084D DPDT |

| Color | Natural | Mahogany brown | Grey |
|----------|---------|----------------|------|
| Quantity | 10 | | |



1082-N



0 4618801611 2

100% TESTED



1082 Series Screw Mount with Leads Magnetic Contacts


Installation Instructions

1082, 1083W, 1084D, 1084W

Select desired mounting positions for switch and magnet. For wide gap switches align labels on switch and magnet so labels read in the same direction (switches are polarity sensitive). Attach with mounting screws included.

Lead Colors on SPDT

Black: Common
White: Closed Loop
Red: Open Loop

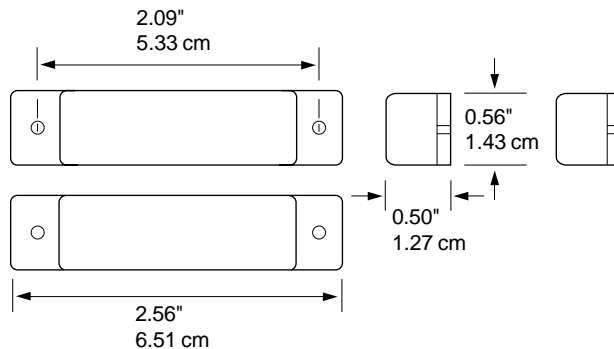

**Magnet
Part No. 1080-T
(included)**

UL Specifications

**European Union Specifications: 48 VAC/DC Max., 0.5 Amp

| Part Number | Loop Type | Electrical Configuration | Gap Distance |
|-------------|----------------|--------------------------|--------------|
| 1082 | Closed | N.O. | 1" |
| 1083W | Open | N.C. | 2" |
| 1084D | Open or Closed | DPDT | 3/4" |
| 1084W | Open or Closed | SPDT | 2" |

**FORM A (1082)

Voltage: 100 VAC/DC Max
Current: 0.5 A Max
Power: 7.5 W Max

FORM B (1083W)

Voltage: 30 VAC/DC Max
Current: 0.25 A Max
Power: 3.0 W Max

FORM C (1084D, 1084W)

Voltage: 30 VAC/DC Max
Current: 0.25 A Max
Power: 3.0 W Max

ULC Specifications

All Contacts: 30 VDC, 50 ma max. Gap Specifications:
See UL Gap Specifications



PH 503.692.4052

USA & Canada: 800.547.2556

Technical Service: 800.648.7424 FaxBack: 800.483.2495

www.sentrol.com www.interlogixsecurity.com

©2001 Interlogix, Inc.

Interlogix, Caddx, ESL, ITI and Sentrol are
trademarks of Interlogix, Inc.