



# SENTROL

## 1085 Series

Surface Mount with Wire Leads

Magnetic Contacts

Gap distance	Closed loop	SPDT
5/8"	1085	1087
1 1/2"	1085W	
3/8"		1087D DPDT

Color	Natural	Mahogany brown	Grey
Quantity	10		



1085-N

100% TESTED



## 1085 Series Surface Mount with Wire Leads Magnetic Contacts

### Installation Instructions


#### 1085, 1087, 1085W, 1087W, 1087D

Select desired mounting positions for switch and magnet. For wide gap switches (1085W, 1087W) align labels on switch and magnet so labels read in the same direction (switches are polarity sensitive). Attach with screws provided.

#### Lead Colors

Black: Common  
White: Closed Loop (N.O.)  
Red: Open Loop (N.C.)

#### Magnet Part No. 1081 (included)

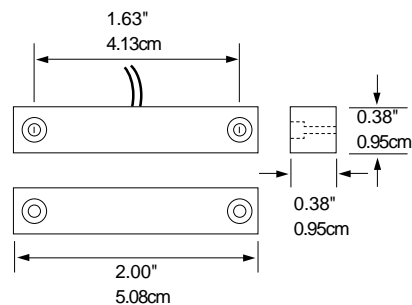

### UL Specifications

\*\*European Union Specifications: 48 VAC/DC Max., 0.5 Amp

Part Number	Loop Type	Electrical Configuration	Gap distance
1085	Closed	N.O.	5/8"
1085W	Closed	N.O.	1 1/2"
1087	Open or Closed	SPDT	5/8"
1087D	Open or Closed	DPDT	3/8"

**\*\*FORM A (1085, 1085W)**  
Voltage: 100 VAC/DC Max  
Current: 0.5 A Max  
Power: 7.5 W

**FORM C (1087)**  
Voltage: 30 V Max  
Current: 0.25 A Max  
Power: 3.0 W Max

### ULC Specifications

All Contacts: 30 V DC, 50 ma max.

Gap Specifications:\*

See UL Gap Specifications



PH 503.692.4052

USA & Canada: 800.547.2556

Technical Service: 800.648.7424 FaxBack: 800.483.2495

www.sentrol.com www.interlogixsecurity.com

©2001 Interlogix, Inc.

Interlogix, Caddx, ESL, ITI and Sentrol are trademarks of Interlogix, Inc.

14090 Rev B 10/01