

EH2400 Enclosure

INDOOR, SECURITY RATED, CORNER MOUNT

Product Features




- Aluminum Construction
- Tamper Resistant
- Adjustable Camera Mount
- Flush Ceiling or Mid-Wall Mounting
- Ideal for Today's Smallest Box Cameras
- Attractive, Rugged Powder Coat Finish

The **EH2400** enclosure is designed to provide low cost, tamper-resistant, corner mounting for fixed camera applications. It can be mounted flush against a ceiling, or placed mid-wall in high ceiling applications, without compromising enclosure integrity.

The smaller frontal area and reduced overall size create an unobtrusive enclosure ideal for today's smaller cameras. The **EH2400** will accommodate Pelco cameras with vari-focal lenses that do not exceed eight inches in total length.

The **EH2400** is constructed from aluminum and has a 3/16-inch thick Lexan® window. Tamper-resistant button-head screws prevent the enclosure from being opened by unauthorized personnel.

Three conduit knockouts allow wires to be delivered from the wall (either side) or ceiling.

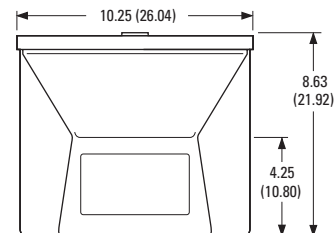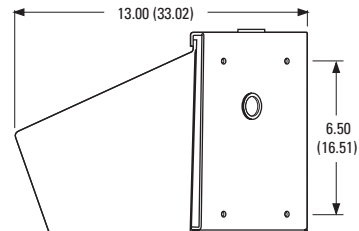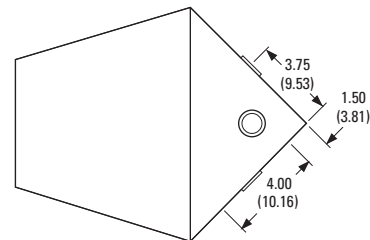

NOTE: VALUES IN PARENTHESES ARE CENTIMETERS;
ALL OTHERS ARE INCHES.



TECHNICAL SPECIFICATIONS

MODEL

EH2400	Indoor enclosure; security rated, corner mount, aluminum
--------	--

MECHANICAL

Camera Mounting	Adjustable tilt table
Maximum Camera and Lens Size	Accepts camera and lens combinations* (including BNC connector) up to 4.0" H x 4.0" W x 8.0" L (10.16 x 10.16 x 20.32 cm)
Viewing Window	0.187-inch (4.76 mm) thick Lexan®
Viewing Window Area	4.25" W x 2.56" H (10.8 x 6.50 cm)
Cable Entry	0.875-inch (2.22 cm) diameter or 1.125-inch (2.86 cm) diameter knockout access through rear walls and top
Enclosure Mounting	Eight 0.25-inch (0.64 cm) diameter openings on protected rear surfaces
Security	Tamper-resistant button-head screws (hollow Allen wrench supplied)

*Assumes lens is fully extended.

GENERAL

Construction	0.125-inch (3.175 mm) thick aluminum
Finish	Gray polyester powder coat
Environment	Indoor
Unit Weight	6.57 lb (2.98 kg)
Shipping Weight	9 lb (4.08 kg)



Pelco, Inc. Worldwide Headquarters:
3500 Pelco Way, Clovis, California 93612-5699 USA
USA & Canada Tel: (800) 289-9100 • FAX: (800) 289-9150
International Tel: +1 (559) 292-1981 • FAX: +1 (559) 348-1120
www.pelco.com

Pelco and the Pelco logo are registered trademarks of Pelco, Inc.
Lexan is a registered trademark of the General Electric Company.
Product specifications and availability subject to change without notice.
©Copyright 2007, Pelco, Inc. All rights reserved.