


CM1450 Mount

WALL MOUNT, CAMERA

Product Features

- Low Cost Wall Mount
- Decorator Styling
- Supports up to 7 Pounds (3.2 kg)
- Adjustable Swivel Head
- Accommodates Light-Duty Cameras
- Can be Adapted for Pole Mount Applications With Use of PA101 Adapter

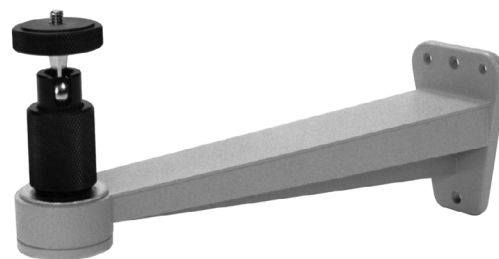


The **CM1450** is a light-duty camera mount designed for wall mount applications.

The **CM1450** is manufactured from aluminum and die-cast for low cost efficiency. It features an easily adjustable swivel head, which allows for 360-degree pan rotation and 90-degree tilt adjustments. The **CM1450** utilizes a set screw for final positioning of the swivel assembly.

The **CM1450** will accommodate cameras weighing up to 7 pounds (3.2 kg).

The **CM1450** can also be adapted for pole mount applications when used with a Pelco PA101 adapter.

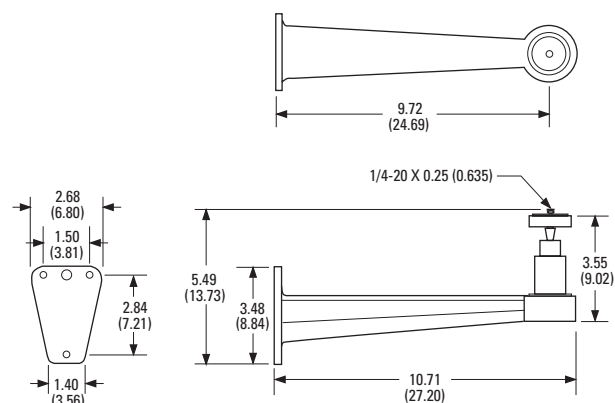

NOTE: VALUES IN PARENTHESES ARE CENTIMETERS;
ALL OTHERS ARE INCHES.



TECHNICAL SPECIFICATIONS

MODEL

CM1450

Light-duty camera mount with adjustable swivel head for wall mount applications

RELATED PRODUCT

PA101

Pole mount adapter for CM1450 mount. Stainless steel straps supplied. Straps fit 3-inch (7.62 cm) to 8-inch (20.32 cm) diameter pole.

MECHANICAL

Pan Adjustment

360°

Tilt Adjustment

90°

Locking Method

Set screw secures swivel assembly

Camera Mounting

1/4-20 threaded stud and nut

Mounting Method

Secure with three 1/4-inch diameter fasteners to solid surface or use one 5/16-inch diameter and one 1/4-inch diameter fastener where wall studs are encountered. (Fasteners not supplied.)

GENERAL

Construction

Aluminum

Finish

Gray polyester powder coat

Maximum Load

7 lb (3.2 kg)

Unit Weight

1.2 lb (0.5 kg)

CM1450

0.88 lb (0.4 kg)

PA101

Shipping Weight

2 lb (0.9 kg)


CM1450

PA101


2 lb (0.9 kg)

CERTIFICATIONS

- UL Listed

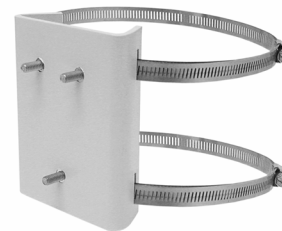

PA101 POLE ADAPTER

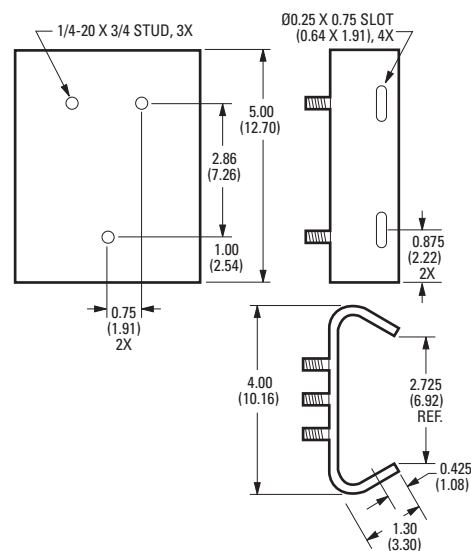

NOTE: VALUES IN PARENTHESES ARE CENTIMETERS; ALL OTHERS ARE INCHES.



Pelco, Inc. Worldwide Headquarters:

3500 Pelco Way, Clovis, California 93612-5699 USA

USA & Canada Tel: (800) 289-9100 • FAX: (800) 289-9150

International Tel: +1 (559) 292-1981 • FAX: +1 (559) 348-1120

www.pelco.com

Pelco and the Pelco logo are registered trademarks of Pelco, Inc. Product specifications and availability subject to change without notice. ©Copyright 2006, Pelco, Inc. All rights reserved.