

## CM1300 Mount

### WALL MOUNT, CAMERA

#### Product Features

- Low Cost
- Wall Mount Applications
- Can Be Mounted Directly to Standard Electrical Box Using WP13 Adapter
- Cable Feedthrough Holes and Removable Bottom Cover Conceal Wiring
- "Keyhole" Mounting Slots for Easy Installation
- Manually Adjustable Head
- Accommodates Light Duty Cameras up to 25 Pounds (11.25 kg)




The **CM1300** is a light duty camera mount designed for indoor use and will accommodate cameras weighing up to 25 pounds (11.2 kg).

The **CM1300** is versatile in that it can be mounted directly to a wall or adapted to a standard 2 x 4-inch (5.08 x 10.16 cm) electrical box when used with the WP13 adapter.

Manufactured from steel, the **CM1300** features a manually adjustable head, "keyhole" mounting slots, feedthrough holes, and removable bottom cover.

The **CM1300** is inexpensive and easy to install.

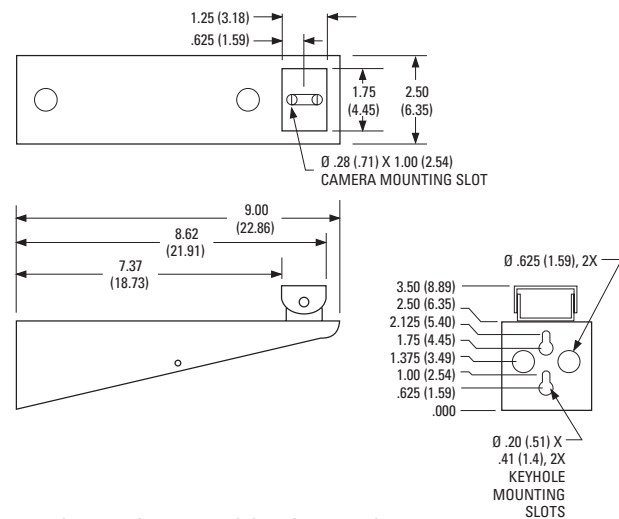

# TECHNICAL SPECIFICATIONS

## MODEL

CM1300	Light duty camera mount with manually adjustable head for wall mount applications
--------	---

## MECHANICAL

Pan Adjustment	360°
Tilt Adjustment	±65°
Mounting Method	Secure to solid surface with two fasteners (minimum #10 screws recommended)

## GENERAL

Construction	0.047-inch (1.19 mm) thick steel
Finish	Gray polyester powder coat
Maximum Load	25 lb (11.25 kg)
Environment	Indoor
Temperature Range	32° to 120°F (0° to 48.89°C)
Unit Weight	
CM1300	1.28 lb (0.58 kg)
WP13	0.18 lb (0.08 kg)
Shipping Weight	
CM1300	2 lb (0.9 kg)
WP13	1 lb (0.45 kg)

## OPTIONAL ACCESSORIES

WP13	Wall plate for use in mounting CM1300 to a standard 2 x 4-inch (5.08 x 10.16 cm) electrical box
------	---



**Pelco, Inc. Worldwide Headquarters:**  
3500 Pelco Way, Clovis, California 93612-5699 USA  
**USA & Canada** Tel: (800) 289-9100 • FAX: (800) 289-9150  
**International** Tel: +1 (559) 292-1981 • FAX: +1 (559) 348-1120  
[www.pelco.com](http://www.pelco.com)

Pelco and the Pelco logo are registered trademarks of Pelco, Inc.  
Product specifications and availability subject to change without notice.  
©Copyright 1998, Pelco, Inc. All rights reserved.