



16-Port DB25M Surge Interface

HIGHLIGHTS


- DB25 male connectors
- RS-232/422/485 software-selectable ports
- Communications speeds up to 460Kbps
- 25KV surge protection
- Rugged steel enclosure
- Works with RocketPort INFINITY or EXPRESS cards
- RoHS compliant



Part Number
30075-5

Product Description

The next-generation RocketPort 16-Port Surge Interface has sixteen DB25M connections that can be configured for RS-232/422/485 serial communications at speeds up to 460Kbps. The interface is connected to the required RocketPort controller card through a host interface cable.

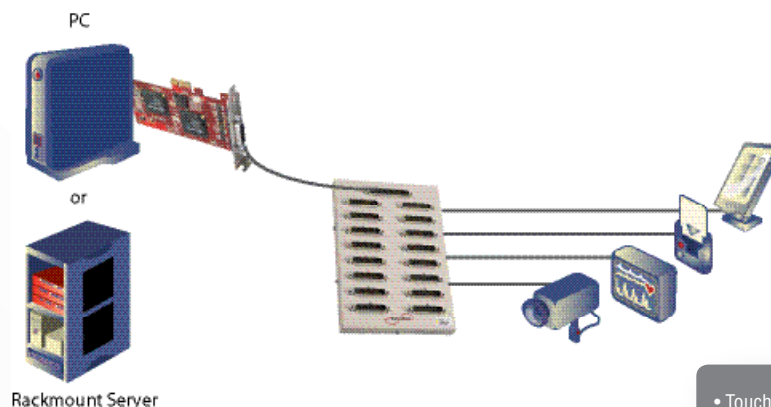

Possible Connectivity Options

- Touch Screen
- Key Card
- Heart Monitor
- Security Camera

SPECIFICATIONS

HARDWARE

Dimensions	8.5" x 0.9" x 5.8"
Product Weight	32 oz

ELECTRICAL SPECIFICATIONS

Device	
ESD Surge Protection	25KV (min)

ENVIRONMENTAL SPECIFICATIONS

Air temperature	
System On	0 to 60° C
System Off	-20 to 85° C
Operating Humidity	
Non-condensing	5% to 95%
Altitude	0 to 10000 Feet
Mean time between failures	31.4 Years

SERIAL COMMUNICATIONS

Connector Type	(16) DB25M
Supported Standards	
RS-232	
RS-422	
RS-485 Full Duplex Master/Slave (4-wire)	
RS-485 Half Duplex (2-wire)	
Baud Rate	300 to 460.8Kbps
Device Driver Data Control	
Modem Control Signals	
RTS, CTS, DSR, DTR, CD, RI	

EXPORT INFORMATION

Packaged Shipping Weight	2.5 lbs
Package Dimensions	9.25" x 2.5" x 7.25"
UPC Code	7-56727-30075-5
Country of Origin	USA
ECCN	EAR99
Schedule B Number	8471.80.1000

REGULATORY STANDARDS

Emission

Emissions Canadian EMC Requirements
ICES-003
European Standard EN55022
FCC Part 15 Subpart B
Class A Limit
AS/NZS CISPR 22

Immunity

European Standard EN55024
IEC 1000-4-2/EN61000-4-2: ESD
IEC 1000-4-3/EN61000-4-3: RF
IEC 1000-4-4/EN61000-4-4: FAST TRANSIENT
IEC 1000-4-5/EN61000-4-5: SURGE
IEC 1000-4-6/EN61000-4-6: CONDUCTED
DISTURBANCE
IEC 1000-4-8/EN61000-4-8: MAGNETIC FIELD
IEC 1000-4-11/EN61000-4-11: DIPS AND
VOLTAGE VARIATIONS

Safety

IEC 60950/EN60950
CSA C22.2 No. 60950/UL60950
Third Edition

Other

European Standard: 2002/95/EC
Directive (RoHS)

REGULATORY APPROVAL MARKS



FEATURES

5 Year Warranty



APPLICATIONS

- Point of Sale
- Kiosks
- Material Handling
- Hospitality
- Medical
- CNC/DNC
- Remote Access
- Automatic Data Collection
- Industrial Control and Monitoring

ORDERING INFORMATION

30075-5 RocketPort 16-Port DB25M Surge Interface

RECOMMENDED PRODUCTS

30015-1 RocketPort INFINITY 16-Port card
30137-0 RocketPort EXPRESS 16-Port card
30010-6 RocketPort INFINITY 32-Port card
30138-7 RocketPort EXPRESS 32-Port card

PRODUCT SUPPORT & SERVICE INFORMATION

Warranty Information
Control offers a 30-day satisfaction guarantee and 5-year limited warranty.

Sales Support
+1.763.957.6000
sales@comtrol.com

Technical Support
+1.763.957.6000
www.comtrol.com/support

Email, FTP and Web Support
info@comtrol.com
ftp.comtrol.com
www.comtrol.com