



WB-K410-B21

Safety Grated Waveguide Bridge Kit, 24 in x 10 ft, with four 21 ft direct burial posts


Dimensions

Width	609.6 mm 24.0 in
Height	6400.8 mm 252.0 in
Length	3.0 m 10.0 ft
Weight	270.4 kg 596.0 lb

General Specifications

Product Type	Waveguide bridge kits
Application	Direct burial
Cable Runs, quantity	24
Includes	Caps Channel Hardware Posts Support brackets Trapeze
Material Type	Hot dip galvanized steel
Package Quantity	1
Pipe Length	6.4 m 21.0 ft
Pipe, quantity	4

Outline Drawing

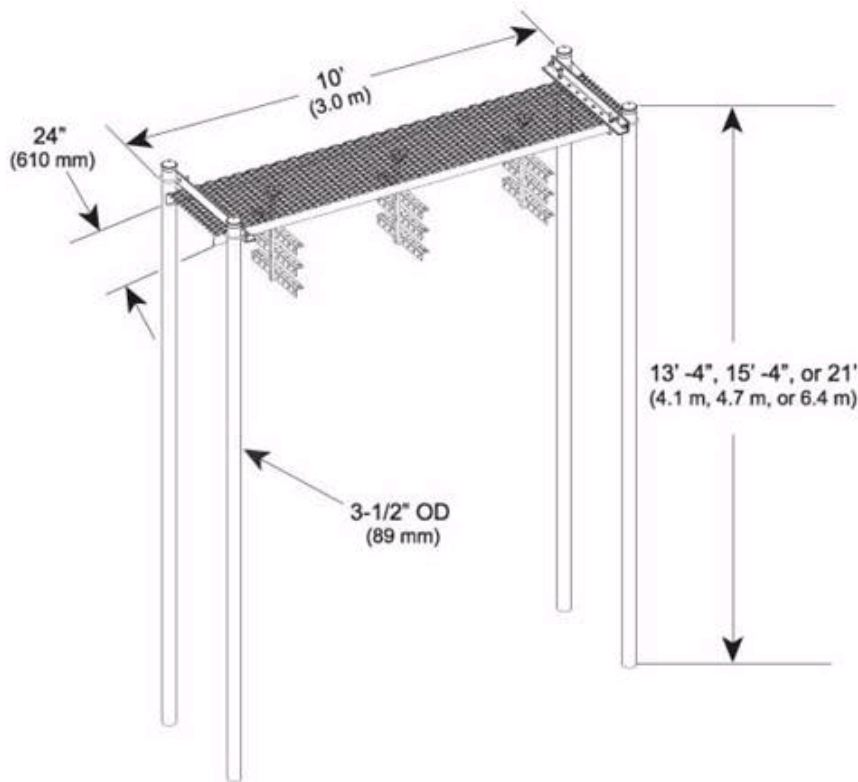

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2008	Designed, manufactured and/or distributed under this quality management system

Included Products

- WB-T24-3 — Trapeze Kit, triple tee, 24 in wide, three rungs
- WB-CS24-3 — Safety Grated Channel Support, 24 in wide for 3-1/2 in OD pipe
- MT-547 — Bulk Pipe, 3-1/2 in OD x 21 ft
- WB-CY210 — Safety Grated Waveguide Bridge Channel, 24 in x 10 ft