

Rittal – The System.

Faster – better – worldwide.

► Data Center Enclosures, Racks and Accessories



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

Interior installation

Component shelves

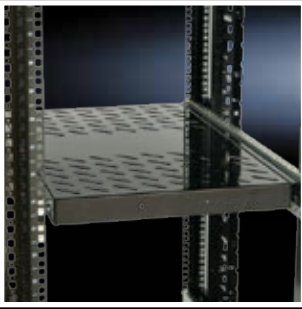

Heavy-duty tool-less shelves for 19" (482.6 mm) rack mounting

These 19" (482.6 mm) heavy-duty enclosure mount shelves are designed for your ease. The tool-less advantage allows quick and simple assembly.

Load capacity:

250 lb (113 kg)

Note:

Cabinet must have a depth of 32" (800 mm)

Mounting	Color	Part No.
Fixed	RAL 7035 light grey	9968.556
Fixed	Cool black	9968.557
Telescopic	RAL 7035 light grey	9968.586
Telescopic	Cool black	9968.587



Component shelves, 2 U

Static installation

If only one pair of 19" (482.6 mm) mounting angles is available for mounting a component shelf, this variant offers a particularly cost-effective solution. Installation of telescopic slides is not possible.

Load capacity:

55 lb (25 kg) surface load, static

Material:

Sheet steel, spray-finished

Component shelf depth inches (mm)	Part No.
10 (250)	7119.250
16 (400)	7119.400

Color:

RAL 7035 light grey

Also required:

Screws, captive nuts



Component shelf, 2 U

Static installation or fully extendable

Suitable for installation in all enclosures with only one 19" (482.6 mm) location point via flange mounting.

Load capacity:

55 lb (25 kg) surface load, static

Material:

Sheet steel, spray-finished

Color:

RAL 7035 light grey

Width x depth inches (mm)	Part No.
15 x 12 (390 x 300)	7148.035

Supply includes:

1 set = 1 component shelf, 2 installation brackets, assembly parts

Accessories:

For fully extendable version, telescopic slides 7051.000 should be ordered additionally.



Handle for component shelves

Material:

Die-cast zinc

Supply includes:

Installation hardware. All component shelves have mounting holes for handles.

Surface Finish:

Spray finished, silver grey

Packs of	Part No.
2	3636.010