

Rittal – The System.

Faster – better – worldwide.

► Data Center Enclosures, Racks and Accessories



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

Component shelves

Tool-less shelves for 19" (482.6 mm) rack mounting

These 19" (482.6 mm) enclosure mount shelves are designed for your ease – the tool-less advantage allows quick and simple assembly.


Load capacity:

150 lb (68 kg)

Note:

Cabinet must have a depth of 28" (700 mm)

Mounting	Color	Part No.
Fixed	RAL 7035 light grey	9968.421
Fixed	Black	9968.422

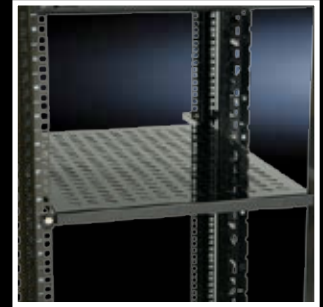

Component shelves, 1/2 U, depth-variable

These space-saving component shelves are screw-fastened to the front and rear 19" (482.6 mm) attachment level. They are infinitely depth-adjustable and may be fitted independently from the enclosure. Combination with telescopic slides is not possible.

Load capacity:

110 lb (50 kg) surface load, static

Distance between levels inches (mm)	Part No.
15.74 – 23.62 (400 – 600)	7063.710
23.62 – 35.43 (600 – 900)	7063.720

Material:

Sheet steel

Surface Finish:

Spray-finished, RAL 7035 light grey

Supply includes:

Component shelf, including assembly parts



Component shelves, 19" (482.6 mm) configuration

The component shelves may be inserted in network enclosures with two pairs of 19" (482.6 mm) mounting angles.

The component shelves offer a number of location points depending on their depth, so that the distance between levels is completely variable in conjunction with the depth-variable installation kit. Each component shelf secured in this way can be retrospectively upgraded to full withdrawal using telescopic slides.

For this purpose, the telescopic slides are screw-fastened in place of the spacers.

Load capacity:

110 lb (50 kg) or 220 lb (100 kg) surface load, static

Material:

Sheet steel

Color:


RAL 7035 light grey

Supply includes:

Component shelf including spacers for static installation

Also required:

Depth-variable installation kit, see page 37

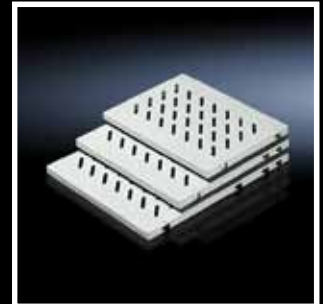

Component shelf width inches (mm)	16.10 (409)				
Component shelf depth inches (mm)	11.81 (300)	15.74 (400)	19.68 (500)	23.62 (600)	27.55 (700)
Part No. 110 lb Shelf	7143.035	7144.035	7145.035	7145.635	7145.735
Part No. 220 lb Shelf	–	–	7063.895	–	7063.897
Handle for component shelf	3636.010	3636.010	3636.010	3636.010	3636.010
Telescopic slides 110 lb (50 kg)	7051.000	7061.000	7081.000	7161.000	7161.700
Telescopic slides 220 lb (100 kg)	–	–	7065.000	–	7066.700

