

Rittal – The System.

Faster – better – worldwide.

► Data Center Enclosures, Racks and Accessories



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

19" (482.6 mm) installation system

Mounting kit

For 19" (482.6 mm) equipment

Facilitates fast, simple integration of additional mounting space within an enclosure by attaching to the enclosure frame or to the existing mounting angles at the sides. The flexible slot fastening of the brackets means that the distance between the two installation brackets may be freely selected, so that other 19" (482.6 mm) attachment dimensions may be implemented.

The second row of holes is used for the optional configuration of additional mounting surfaces.


U	Color	Packs	Part No.
1	Black	2	9970.986
2	Sheet steel	2	7246.420

Material:

Sheet steel, zinc-plated, passivated

Supply includes:

Assembly parts

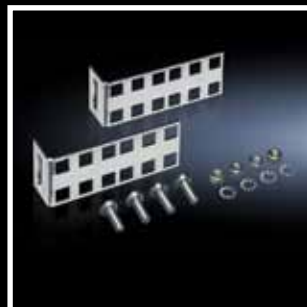

Fan expansion kits

For EL 3-Part enclosures

For retrofitting various fan units or to supplement the fan mounting plate and modular fan roof.

Technical specifications:

Rated voltage: 115 or 230 V

Rated current: 19/18 W for 50/60 Hz

Air displacement (unimpeded airflow):

85/100 cfm/ for 50/60 Hz

Temperature range:

14°F to 131°F (-10°C to +55°C)

Voltage	Packs of	Part No.
230 V fan	1 set	7980.000
115 V fan	1 set	7980.110



Wall mounting brackets

For EL 3-Part enclosures

Utilize pre-drilled holes in rear wall. Version with 1.58" (40 mm) stand-off allows cable routing behind the enclosure.

Material:

Steel, chromated

Stand-off dimension A	Packs of	Part No.
1.58" (40 mm)	4	2503.200
0.39" (10 mm)	4	2508.200



Second pair of mounting angles

To accommodate 19" (482.6 mm) network components or for the attachment of component shelves and slide rails.

19" (482.6 mm) punched profile at the front, hole center distance 18.31" (465 mm) (18.50" (470 mm) at the rear), tailored to the attachment of patch panels and cable routing rails.

The mounting level may be positioned on a 2" (50 mm) pitch pattern.

Minimum distance between levels 6" (150 mm), maximum distance between levels 14" (350 mm).

U	Packs of	Part No.
31	1	7296.000
36	1	7297.000
40	1	7298.000
45	1	7299.000

Material:

Sheet steel, 0.08" (2 mm)

Color:

RAL 7035

Supply includes:

- 1 torsionally stiff profile frame
- Mounting accessories

