



RB1224

Overview

Snap track mountable relay modules.

Specifications

- 12VDC or 24VDC operation.
- 5 amp/220VAC or 28VDC DPDT contacts.
- Current draws: 75mA.
- Snap track mountable (order part # ST1).

Board Dimensions (approximate):

2.75"L x 2"W x 1"H


RB1224 weights (approximate):

Product weight: 0.48 lbs


Shipping weight: 0.5 lbs.

RB1224 Application Drawings


Dry Contacts

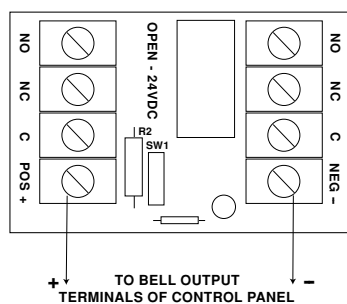

Polarity Reversal

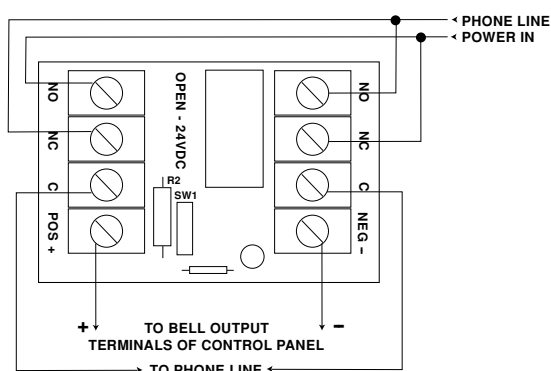

Line Seizure

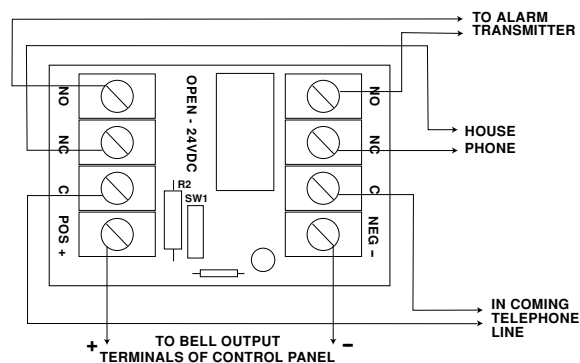

Latching Dry Contacts

