




## **Overview**

Break away relays.

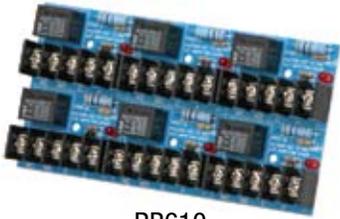

RB610

## **Specifications**

- 12VDC or 24VDC selectable operation.
- Each cluster contains six (6) relay modules which can easily be separated.
- Current draw 50mA.
- 10 amp/120VAC or 28VDC SPDT contacts.

- Screw terminals accommodate up to 12 gauge wire.

### ***RB610 weights (approximate):***

Product weight: 0.6 lbs.

Shipping weight: 1.2 lbs.

## **Board Dimensions (approximate)**

8"L x 4.5"W x 1.25"H

## **Mounting Diagram**

