


Product Data Sheet

1422/1423 (0.005-0.004 in. Wall, Voltage - Not Specified)

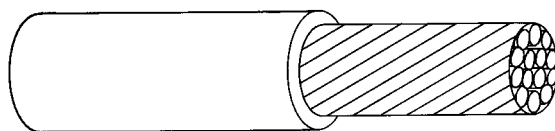

Product Description

Kynar
Solid conductor

Applications

Insulated solid conductor copper wire for "back panel" wiring of computers and other electronic applications where solderless wraps are used.

Specifications

- CONDUCTOR: Silver-coated, solid conductor copper
- INSULATION: Kynar, 0.005 in. wall (UL 1422) or 0.004 in. wall (UL 1423)
- STANDARDS: UL recognized AWM Style 1422/1423 per UL 758 requirements
- TEMPERATURE: 105°C
- VOLTAGE: Not rated

All part numbers require color code designation. See Color Code chart at the end of this section. Diameters and weights may vary among manufacturers.

Part No.	Conductor AWG	Stranding No. x AWG	Conductor Nom. Dia.	Wire O.D.	Approx. Wt. lb./1,000 ft.
1422-30/1-XX	30	Solid	0.010	0.020	0.5
1422-28/1-XX	28	Solid	0.013	0.023	0.8
1422-26/1-XX	26	Solid	0.016	0.027	1.0
1422-22/1-XX	22	Solid	0.020	0.031	1.6