


Product Data Sheet

Lighting-Control Cables

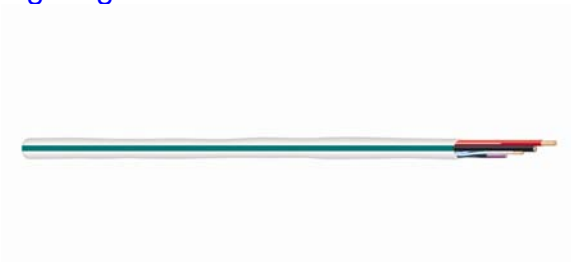

Product Description

Lighting-control cable for permanent LiteTouch or Lutron GRAFIK Eye, Sivoia, Homeworks and Vantage installations. Plenum rated.

Specifications

- COMPOSITE: See Part Number Description
- CONDUCTOR: Stranded or solid bare copper
- SHIELDING: Foil shield, plus tinned-copper drain wire
- INSULATION: Low-smoke polyvinyl chloride (LSPVC)
- JACKET: Low-smoke polyvinyl chloride (LSPVC)
- NEC: CMP or CL3P

Part No.	Description	Nom. O.D. (in.)	Approx. Wt. lb./1,000 ft.
AV-LUTRON-P-EBC	2C 16 AWG Solid BC, overall clear FEP jacket, 105C	0.170	27
AV-LUTRON-P-ESC	5C 22 AWG Solid BC, overall foil shield, overall clear FEP jacket, 200C	0.125	19
AV-LUTRON-P-GRN	Composite: 2C 22 AWG shielded data pair + 2C 18 AWG unshielded power, overall white/green stripe LSPVC jacket	0.352	37
AV-LUTRON-P-RBL	Composite: 2C 22 AWG shielded data pair + 2C 12 AWG unshielded power pair + 1C 18 AWG sense line, overall white with blue stripe LSPVC jacket	0.373	76
AV-LUTRON-P-RED	Composite: 4C 18 AWG quad shielded + 2C 16 AWG unshielded power + 1C 18 AWG ground, overall white with red stripe LSPVC jacket	0.411	76
AV-LUTRON-P-WHT	4C 18 AWG, foil shield, overall white with light blue stripe LSPVC jacket	0.184	33
AV-LUTRON-P-YEL	Composite: 2C 22 AWG shielded data pair + 2C 18 AWG unshielded power, overall white with yellow stripe LSPVC jacket	0.352	37