


Product Data Sheet

Lighting-Control Cables

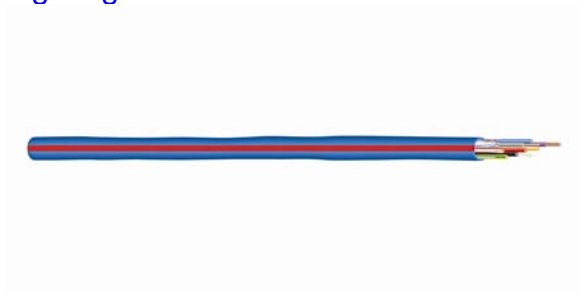

Product Description

Lighting-control cable for permanent LiteTouch or Lutron GRAFIK Eye, Sivoia, Homeworks and Vantage installations.

Specifications

- COMPOSITE: See Part Number Description
- CONDUCTOR: Stranded or solid bare copper
- SHIELDING: Foil shield, plus tinned copper drain wire
- INSULATION: Polyvinyl Chloride (PVC)
- JACKET: Polyvinyl Chloride (PVC)
- NEC: CMR or CL3R

Part No.	Description	Nom. O.D. (in.)	Approx. Wt. lb./1,000 ft.
AV-LUTRON-EBC	2C 16 AWG Solid BC, overall grey PVC jacket, 105C, AWM Style 2919	0.282	41
AV-LUTRON-ESC	5C 22 AWG Solid BC, overall foil shield, overall white PVC jacket, 105C, AWM Style 2919	0.279	44
AV-LUTRON-GRN	Composite: 2C 22 AWG shielded data pair + 2C 18 AWG unshielded power, overall light blue with green stripe PVC jacket	0.387	
AV-LUTRON-PINK	2C 18 AWG shielded, light blue with pink stripe PVC jacket	0.260	41
AV-LUTRON-RBL	Composite: 2C 22 AWG shielded data pair + 2C 12 AWG unshielded power pair + 1C 18 AWG sense line, overall light blue with royal blue stripe PVC jacket	0.404	83
AV-LUTRON-RED	Composite: 4C 18 AWG quad shielded + 2C 16 AWG unshielded power + 1C 18 AWG ground, overall light blue with red stripe PVC jacket	0.435	86
AV-LUTRON-WHT	4C 18 AWG, foil shield, overall light blue with white stripe PVC jacket, Type TC	0.296	59
AV-LUTRON-YEL	Composit: 2C 22 AWG shielded data pair + 2C 18 AWG unshielded power, overall light blue with yellow stripe PVC jacket	0.387	45