


Power-Return Steel Rules – High-Visibility Case

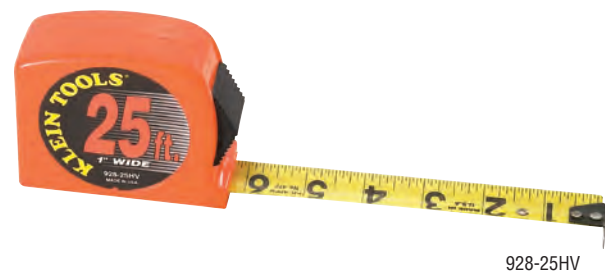


928-25HV

Cat. No.	Blade Length	Width	Weight (lbs.)
928-25HV	25' (7.5 m)	1" (25 mm)	1.00

- High-visibility, high-impact orange case makes it easy to find in a tool box, pouch and on the jobsite.
- 16" (406 mm) and 19.2" (485 mm) stud-center marks.
- Tape measure holders available.
- Made in USA.

Folding Rules

Wood Folding Rules

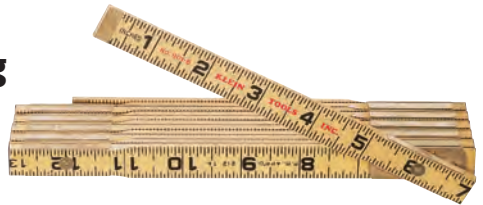


901-6

- Strong, 6' (183 cm) long hardwood rules with clear abrasion-resistant coating.
- Black markings on yellow, with red stud center markings every 16 inches.
- Measurements are marked on both sides and both edges, and graduated to 1/16th inch.
- Riveted lock joints are designed for long wear and maintained accuracy.
- Extension slide moves under friction in a T-slot with stops at each end. (Cat. No. 905-6)

Cat. No.	Reading	Length	Weight (lbs.)
900-6	inside	6' (183 cm)	.33
901-6	outside	6' (183 cm)	.33
6-Ft. Folding Rule — with Extension			
905-6	outside	6' (183 cm)	.33

Fiberglass Folding Rules

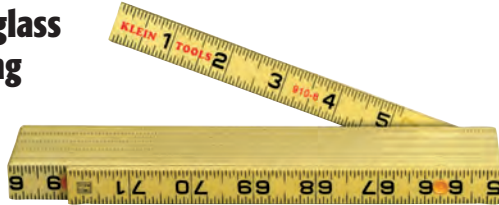

910-6

- Constructed of tough nylon, reinforced with glass fibers for added durability, and resistance to weather, abrasion and most chemicals.
- Positive locking joints and stainless steel spring hinges for added strength.
- Measurements are marked on both sides and both edges, graduated to 1/16th inch.
- Black markings on yellow, with red stud center markings every 16 inches.
- Engraved graduations on both sides.

Cat. No.	Reading	Length	Weight (lbs.)
910-6	inside	6' (183 cm)	.33
911-6	outside	6' (183 cm)	.33

All dimensions are in inches and (millimeters) unless otherwise specified.

- ▲WARNING:** Always wear approved eye protection.
- ▲WARNING:** Do NOT open case. Spring motor is under tension, and opening case may cause injury.

- ▲WARNING:** Never use on or near live electrical circuits.
- ▲CAUTION:** To prevent high speed rewinding, apply slight pressure with forefinger on the underside of the blade.

