

# Specialty Plastic-Handle Screwdrivers

## Screwdriver Replacement Bits

- These precision-milled bits are 1" in length and are 1/4" hex.
- Fits replaceable-bit screwdrivers and other sockets that accept 1/4" hex bits.

Cat. No.	Bit Type	Tip Size	Weight (lbs.)
4HS316	slotted	3/16"	.02
4HS932	slotted	9/32"	.02
4H1P1	Phillips	No. 1	.02
4H1P2	Phillips	No. 2	.02
4H1R1	square recess	No. 1	.01
4H1R2	square recess	No. 2	.01
4H1R3	square recess	No. 3	.01
4HT15	TORX®	T15	.02
4HT20	TORX®	T20	.01
4HT25	TORX®	T25	.02
4HT27	TORX®	T27	.02
4HT30	TORX®	T30	.02




Cat. No.	Weight (lbs.)
<b>Bit Sets</b>	<b>Bit Selection</b>
70036	3/16", 9/32" slotted plus No. 1 and No. 2 Phillips tips
70283	No. 1, No. 2, No. 3 square-recess tips
70432	T15, T20, T25, T27, T30 TORX® tips

TORX® is a registered trademark of Acument Intellectual Properties, LLC.

## 4-in-1 Screwdriver

- Versatile screwdriver with interchangeable, snap-in blades.
- Tool supplied with four different tips on two reversible blades.

Cat. No.	Description	Overall Length	Weight (lbs.)
32460	screwdriver with two dual-tipped blades	7-5/8" (194 mm)	.370
32478	#1 Phillips & 3/16" slotted	-	.036
32479	#2 Phillips & 9/32" slotted	-	.044

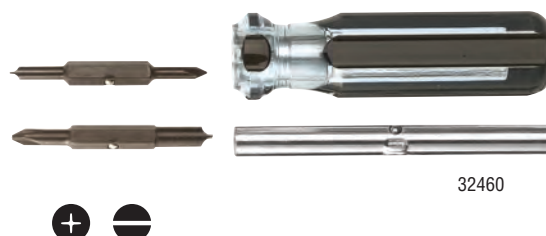

## 3-Piece Slotted Screw-Holding Screwdriver Set

- Not designed for torquing or tightening.

Cat. No.	Set Contains	Weight (lbs.)
SK234		.40
<b>Cat. No.</b>	<b>Shank Size</b>	
K23	3/16" x 3" (5 mm x 76 mm)	
K34	1/4" x 4" (6.3 mm x 102 mm)	
K46	5/16" x 6" (8 mm x 152 mm)	



## Slotted Screw-Holding Screwdrivers

- Split-blade screw-holding driver wedges into screw slot.
- Positive gripping action holds, starts, and drives slotted screws in awkward, hard-to-reach places.
- Not designed for torquing or tightening.

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
K21†	1/16" (1.6 mm)	3" (76 mm)	5-1/4" (133 mm)	.05
K23	3/16" (5 mm)	3" (76 mm)	5-1/4" (133 mm)	.05
K28	3/16" (5 mm)	8" (203 mm)	10-1/4" (260 mm)	.10
K34‡	1/4" (6.3 mm)	4" (102 mm)	7-3/4" (197 mm)	.10
K36‡	1/4" (6.3 mm)	6" (152 mm)	9-3/4" (247 mm)	.15



Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
K38‡	1/4" (6.3 mm)	8" (203 mm)	11-3/4" (298 mm)	.20
K44	5/16" (8 mm)	4" (102 mm)	8-1/4" (209 mm)	.25
K46	5/16" (8 mm)	6" (152 mm)	10-1/4" (260 mm)	.25
K48	5/16" (8 mm)	8" (203 mm)	12-1/4" (311 mm)	.30

† Precision blade for use with small precision screws. Blade thickness of .028" expanding to .045".

‡ Blade thickness of .043" expanding to .085".

Note: K21 and K23 have pocket clips.

All dimensions are in inches and (millimeters).

**⚠ WARNING:** NOT insulated. Will NOT protect against electrical shock.

**⚠ WARNING:** Always wear approved eye protection.

**⚠ WARNING:** Do NOT use to pry or chisel.

