

RFM SERIES 30 & 24 CABINET FRAMES




Standard Features:

- Top c/w cable access openings (cover plates provided)
- 4 Grounding points
 - 2 in top (#10-32 x 1/2" stud)
 - 2 in base (1/4-20 x 1/2" stud)
- Adjustable levelling feet
- Durable textured powder coated finish
- Standard colour is all black
- Custom colours and sizes available upon request

Highlights:

- Heavy gauge steel
- All welded construction
- Provisions for fans and cable access
- Easily bolts to floor
- Seismic rated frame, Zone 4 Telcordia (Bellcore) GR-63-CORE
- Load capacity : 2500 lbs
- Casters available as an option

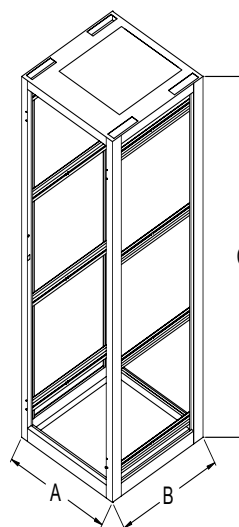

30" Wide cabinet frame

Part Number	A	B	C	# of U's
RFM-302483	30.00	24.00	83.00	44U
RFM-303083	30.00	30.00	83.00	44U
RFM-303072	30.00	30.00	72.00	38U
RFM-303059	30.00	30.00	59.00	30U
RFM-303035	30.00	30.00	35.00	17U
RFM-303683	30.00	36.00	83.00	44U
RFM-303672	30.00	36.00	72.00	38U
RFM-303659	30.00	36.00	59.00	30U
RFM-303635	30.00	36.00	35.00	17U
RFM-304283	30.00	42.00	83.00	44U
RFM-304272	30.00	42.00	72.00	38U
RFM-304259	30.00	42.00	59.00	30U
RFM-304235	30.00	42.00	35.00	17U

24" Wide cabinet frame

Part Number	A	B	C	# of U's
RFM-242483	24.00	24.00	83.00	44U
RFM-243083	24.00	30.00	83.00	44U
RFM-243072	24.00	30.00	72.00	38U
RFM-243059	24.00	30.00	59.00	30U
RFM-243035	24.00	30.00	35.00	17U
RFM-243683	24.00	36.00	83.00	44U
RFM-243672	24.00	36.00	72.00	38U
RFM-243659	24.00	36.00	59.00	30U
RFM-243635	24.00	36.00	35.00	17U
RFM-244283	24.00	42.00	83.00	44U
RFM-244272	24.00	42.00	72.00	38U
RFM-244259	24.00	42.00	59.00	30U
RFM-244235	24.00	42.00	35.00	17U