


Screw clamp

Feed through and ground terminal blocks

Screw clamp, 1 1/3 DIN 1-3

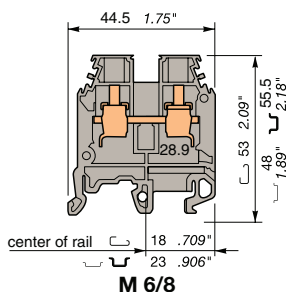

M 6/8 - 6 mm² blocks - 8 mm .315" spacing

Characteristics

		IEC NFC DIN	UL	CSA
Wire size mm² / AWG	Solid	0.5 - 10	22-8 AWG	24-8 AWG
	Stranded	0.5 - 6		
Voltage	V	800	600	600
Current	A	41	50	55
Short circuit current (M 6/8.PI)	A / s	720A/1s		
Rated wire size	mm² / AWG	6 mm²	8 AWG	8 AWG
Wire stripping length	mm / inches	12 mm / .47"		
Recommended torque	Nm / lb.in	0.8-1 Nm / 7.1-8.9 lb.in		

Selection

Description	Type	Order P/N	Packaging
Standard block grey	M 6/8	0115 118.11	50
Standard block blue	M 6/8.N	0125 118.13	50
Standard block yellow	M 6/8	0105 004.22	50
Standard block orange	M 6/8	0105 118.20	50
Standard block beige V0	M 6/8 V0	0195 118.12	50
Standard block blue V0	M 6/8.N.V0	0199 003.27	50
Standard block black	M 6/8	0400 185.20	50
Standard block red	M 6/8	0400 186.21	50
Standard block white	M 6/8	0400 187.22	50
Standard block green	M 6/8	0105 128.22	50
Ground block yellow body/ green marking (without rail contact)	M 6/8.N.V0	0199.003.27	50

Accessories

End stop	BAM2	9.9 mm	0206 351.16	50
End section	grey	FEM6 2.8 mm	0118 368.16	20
	blue	FEM6 2.8 mm	0128 368.10	20
	orange	FEM6 2.8 mm	0103 126.16	20
	yellow	FEM6 2.8 mm	0103 062.21	20
	green	FEM6 2.8 mm	0103 125.15	20
	white	FEM6 2.8 mm	0103 312.20	20
	beige V0	FEM6V0 2.8 mm	0198 368.17	20
	blue V0	FEM6V0 2.8 mm	0199 302.07	20
	yellow V0	FEM6V0 2.8 mm	0199 305.02	20
	black	FEM6 2.8 mm	0107 005.25	20
Separator end section	grey	SCF6 3 mm	0118 707.03	20
Assembled jumper bar (with IP20 protection)	2 poles	BJMI8 41 A	0176 669.16	10
	3 poles	BJMI8 41 A	0176 670.13	10
	4 poles	BJMI8 41 A	0176 671.00	10
	5 poles	BJMI8 41 A	0176 672.01	10
	10 poles	BJMI8 41 A	0176 673.02	10

M 6/8.P - 6 mm² ground block with rail contact - 8 mm .315" spacing

Characteristics

		IEC NFC DIN	UL	CSA
Wire size mm² / AWG	Solid	0.5 - 10	22-8 AWG	24-8 AWG
	Stranded	0.5 - 6		
Short circuit current	A / s	720A/1s		
Rated wire size	mm² / AWG	6 mm²	8 AWG	8 AWG
Wire stripping length	mm / inches	12 mm / .47"		
Recommended torque	Nm / lb. in	0.8-1 Nm / 7.1-8.9 lb.in		

Selection

Description	Type	Order P/N	Packaging
Ground block V2 green/yellow	M 6/8.P	0165 114.17	50
Mounting on rail DIN 3 without screw :			
Ground block V2 green/yellow	D 6/8.P	0165 830.21	50

Accessories

End section	yellow	FEM6 2.8 mm	0103 062.21	20
	yellow V0	FEM6 V02.8 mm	0199 305.02	20
Separator end section	grey	SCF6 3 mm	0118 707.03	20

