


Standard and Ground Terminal Blocks

Compression clamp

M 6/8 Spacing 8mm

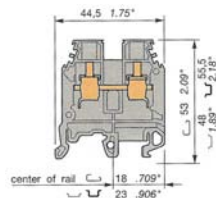


Characteristics		IEC NFC VDE	UL	CSA
Wire size mm ² / AWG	Solid Wire	0.5 - 10	22-8AWG	22-8AWG
	Stranded Wire	0.5 - 6		
Rated voltage	V	800	600	600
Rated current	A	41	50	55
Rated wire size	mm ² / AWG	6mm ²	8AWG	8AWG
Wire stripping length	mm / inches	12mm/ .47"		
Recommended torque	Nm / lb.in	0.8-1 Nm / 7.1-8.9 lb.in		

Selection

Body Colour	Type	Order Code	Pack
● Grey	M 6/8	0115 118.11	50
● Blue	M 6/8.N	0125 118.13	50
● Yellow	M 6/8	0105 118.20	50
● Orange	M 6/8	0105 004.22	50
● Beige VO	M 6/8.VO	0195 118.12	50
● Green+yellow (with contact rail)	M 6/8.P	0165 114.17	50
● Green+yellow VO (with contact rail)	M 6/8.PVO	0195 114.06	50
● Yellow+green (without contact rail)	M 6/8.PI	0165 451.21	50

M 10/10 Spacing 10mm

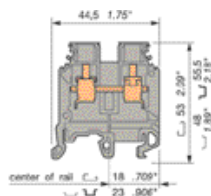

Characteristics		IEC NFC VDE	UL	CSA
Wire size mm ² / AWG	Solid Wire	0.5 - 10	22-8AWG	22-8AWG
	Stranded Wire	0.5 - 6		
Rated voltage	V	800	600	600
Rated current	A	41	50	55
Rated wire size	mm ² / AWG	10mm ²	6AWG	6AWG
Wire stripping length	mm / inches	12mm/ .47"		
Recommended torque	Nm / lb.in	1.2-1.4 Nm / 10.6-12.3 lb.in		

Selection

Body Colour	Type	Order Code	Pack
● Grey	M 10/10	0115 120.17	50
● Blue	M 10/10	0125 120.11	50
● Orange	M 10/10	0105 120.26	50
● Beige VO	M 10/10.VO	0195 120.10	50
● Green+yellow (with contact rail)	M 10/10.P	0165 115.10	50
● Green+yellow VO (with contact rail)	M 10/10.PVO	0195 115.07	50
● Yellow+green (without contact rail)	M 10/10.PI	0165 452.22	50

[Return to main index](#)