



Feed through and ground terminal blocks

Screw clamp, 1 1/2 DIN 1-3


Screw clamp

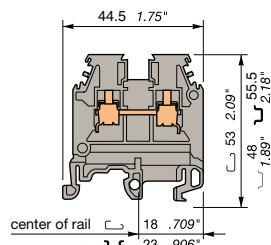

 MA 2,5/5



BAM2

 

SCF6




FEM6



BJMI5




CBM...

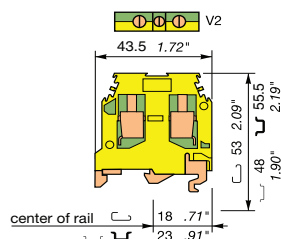

MA 2,5/5.P



 FEM6



SCF6

MA 2,5/5 - 2.5 mm² blocks - 5 mm .200" spacing

Characteristics

		IEC	UL	CSA
		NFC DIN		
Wire size mm ² / AWG	Solid	0.2 - 4	22-12 AWG	22-12 AWG
	Stranded	0.22 - 2.5		
Voltage	V	800	600	600
Current	A	24	30	25
Short circuit current (MA 2,5/5.PI)	A / s	300A/1s		
Rated wire size	mm ² / AWG	2.5 mm ²	12 AWG	12 AWG
Wire stripping length	mm / inches	10 mm / .39"		
Recommended torque	Nm / lb.in	0.4-0.6 Nm / 3.5-5.3 lb.in		

Selection

Description	Type	Order P/N	Packaging
Standard block grey	MA 2,5/5	0115 486.03	50
Standard block white	MA 2,5/5	0105 052.21	50
Standard block blue	MA 2,5/5.N	0125 486.05	50
Standard block yellow	MA 2,5/5	0105 486.12	50
Standard block orange	MA 2,5/5	0105 075.20	50
Standard block black	MA 2,5/5	0105 077.22	50
Standard block red	MA 2,5/5	0400 184.27	50
Standard block beige V0	MA 2,5/5.V0	0195 486.04	50
Ground block yellow body/ green marking (without rail contact)	MA 2,5/5.PI	0165 677.03	50

Accessories

End stop	BAM2	9.9 mm	0206 351.16	50
End section	grey ①	FEM6 2.8 mm	0118 368.16	20
	blue ①	FEM6 2.8 mm	0128 368.10	20
	orange ①	FEM6 2.8 mm	0103 126.16	20
	yellow ①	FEM6 2.8 mm	0103 062.21	20
	green ①	FEM6 2.8 mm	0103 125.15	20
Separator end section	grey	SCF6 3 mm	0118 707.03	20
Assembled jumper bar (with IP20 protection)	2 poles	BJMI5 24 A	0176 278.16	10
	3 poles	BJMI5 24 A	0176 279.17	10
	4 poles	BJMI5 24 A	0176 280.05	10
	5 poles	BJMI5 24 A	0176 281.22	10
	10 poles	BJMI5 24 A	0176 282.23	10
Shield connector	CBM5	0.5 mm	0178 745.14	20
	CBM8	0.8 mm	0178 746.15	20

MA 2,5/5.P - 2.5 mm² ground block with rail contact - 5 mm .200" spacing

Characteristics

		IEC	UL	CSA
		NFC DIN		
Wire size mm ² / AWG	Solid	0.2 - 4	22-12 AWG	22-12 AWG
	Stranded	0.22 - 2.5		
Short circuit current	A / s	300A/1s		
Rated wire size	mm ² / AWG	2.5 mm ²	12 AWG	12 AWG
Wire stripping length	mm / inches	10 mm / .39"		
Recommended torque	Nm / lb.in	0.4-0.6 Nm / 3.5-5.3 lb.in		

Selection

Description	Type	Order P/N	Packaging
Ground block V2 green/yellow	MA 2,5/5.P	0165 488.27	50
Mounting on DIN 3 rail without screw :			
Ground block V2 green/yellow	D 2,5/5.P	0165 909.05	50

Accessories

End section	yellow	FEM6 2.8 mm	0103 062.21	20
	yellow V0	FEM6 V0 2.8 mm	0199 305.02	20
Separator end section	grey	SCF6 3 mm	0118 707.03	20

① Other colors available. Please consult factory.