



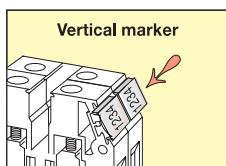

Marking for terminal blocks

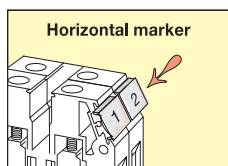

Marking Kit **RC 5 mm spacing**
RC 6 mm spacing

Box with 100 cards with 18 various part/numbers




Standard marker cards RC

Marker sizes	RC410	RC55	RC510	RC65	RC610	RC810	RC1010
Blank cards	0229 000.15	0230 000.12	0231 000.07	0232 000.00	0233 000.01	0234 000.02	0238 000.16
Horizontal marking							
10 strips from 1 to 10	0229 002.03	0230 002.00 (5)	0231 002.25 (25)	0232 002.26 (5)	0233 002.27 (25)	0234 002.20	1 to 8 0238 002.04
10 strips from 11 to 20	0229 003.04	0230 003.01 (2)	0231 003.26 (10)	0232 003.27 (2)	0233 003.20 (10)	0234 003.21	9 to 16 0238 003.05
10 strips from 21 to 30	0229 004.05	0230 004.02	0231 004.27 (6)	0232 004.20	0233 004.21 (6)	0234 004.22	17 to 24 0238 004.06
10 strips from 31 to 40	0229 005.06	0230 005.03	0231 005.20 (4)	0232 005.21	0233 005.22 (4)	0234 005.23	25 to 32 0238 005.07
10 strips from 41 to 50	0229 006.07	0230 006.04	0231 006.21 (3)	0232 006.22	0233 006.23 (3)	0234 006.24	33 to 40 0238 006.00
10 strips from 51 to 60	0229 007.00	0230 007.05	0231 007.22 (2)	0232 007.23	0233 007.24 (2)	0234 007.25	41 to 48 0238 007.01
10 strips from 61 to 70	0229 008.11	0230 008.16	0231 008.03 (2)	0232 008.04	0233 008.05 (2)	0234 008.06	49 to 56 0238 008.12
From 1 to 100	0229 030.02	0230 030.07 (2)	0231 030.24 (15)	0232 030.25 (2)	0233 030.26 (15)	0234 030.27	1 to 80 0238 030.03
From 101 to 200	0229 031.27	0230 031.24	0231 031.11 (2)	0232 031.12	0233 031.13 (2)	0234 031.14	81 to 160 0238 031.20
20 times L1-L2-L3-N-PE		0230 131.25	0231 131.12 (2)	0232 131.13	0233 131.14 (2)		
Vertical marking							
10 strips from 1 to 10	0229 041.01	0230 041.06	0231 041.23 (5)	0232 041.24	0233 041.25 (5)	0234 041.26	1 to 8 0238 051.04
10 strips from 11 to 20	0229 042.02	0230 042.07	0231 042.24 (3)	0232 042.25	0233 042.26 (3)	0234 042.27	9 to 16 0238 052.05
10 strips from 21 to 30	0229 043.03	0230 043.00	0231 043.25 (2)	0232 043.26	0233 043.27 (2)	0234 043.20	17 to 24 0238 053.06
10 strips from 31 to 40	0229 044.04	0230 044.01	0231 044.26 (2)	0232 044.27	0233 044.20 (2)	0234 044.21	25 to 32 0238 054.07
From 1 to 100	0229 060.10	0230 060.15	0231 060.02 (8)	0232 060.03	0233 060.04 (8)	0234 060.05	1 to 80 0238 080.06

RC Standard marker cards

Each marker card contains 10 strips of 10 markers, i.e. 100 markers per card except for RC1010 : 10 strips of 8 markers, i.e. 80 markers per card. Marker cards are white polyamide 6 moulding with black lettering.

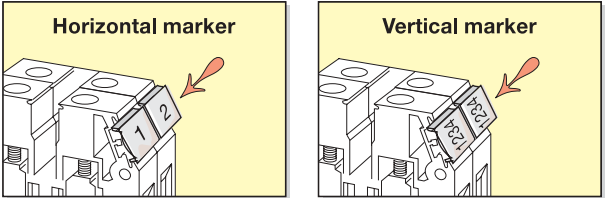

How to use



1

Remove one of the side bands of the card.



2

Separate the chosen strip from the rest of the card.



3

- Strips of 10 markers for blocks spacings 5 mm .197", 6 mm .236" and 8 mm .315" : Press the first marker in place, hold it and slide your thumb on the rest of the strip to snap each marker on the terminal blocks assembly.
- Single markers : Press the chosen marker in place, hold it and tear off the rest of the strip.

Marker sizes

RC55
5 x 5 mm markers
.197" x .197".
Can be used on blocks from 5 mm .197" spacing, with possibility of mounting 2 markers per slot.

RC65
6 x 5 mm markers
.236" x .197".
Can be used on blocks from 6 mm .236" spacing, with possibility of mounting 2 markers per slot.

RC410
4 x 10 mm markers
.157" x .394".
Can be used on blocks from 4 mm .157" spacing, 1 marker per slot.

RC510
5 x 10 mm markers
.197" x .394".
Can be used on blocks from 5 mm .197" spacing, 1 marker per slot.

RC610
6 x 10 mm markers
.236" x .394".
Can be used on blocks from 6 mm .236" spacing, 1 marker per slot.


RC810
8 x 10 mm markers
.315" x .394".
Can be used on blocks from 8 mm .315" spacing, 1 marker per slot.

RC1010
10 x 10 mm markers
.394" x .394".
Can be used on blocks from 10 mm .394" spacing, 1 marker per slot.


The marker that goes into the terminal block slot for each marking method is listed here :

Marker	Marking method
RC410	⇒ ③
RC55	⇒ ⑤ ⑩
RC510	⇒ ⑥ ⑩
RC65	⇒ ⑤ ⑪
RC610	⇒ ⑥ ⑪
RC810	⇒ ⑥ ⑰
RC1010	⇒ ⑳

Standard marker cards	Marker width mm	Marker height, L mm	Use with terminal block thickness
RC410	4	10	4 mm
RC55	5	5	5 mm
RC510	5	10	5 mm
RC65	6	5	6 mm
RC610	6	10	6 mm
RC810	8	10	8 mm and larger
RC1010	10	10	10 mm and larger

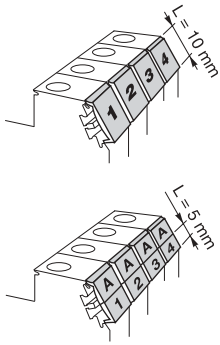

Blank cards

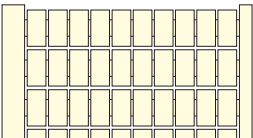

Blank marker cards.

RC410 white 0229 000.15	RC55 white 0230 000.12	RC510 white 0231 000.07	RC65 red 0103 776.01 blue 0103 775.00 white 0232 000.00
RC610 white 0233 000.01	RC810 white 0234 000.02	RC1010 white 0238 000.16	
RC510A white 0231 500.01	RC610A white 0233 500.03	RC810A white 0234 500.04	
Card holder for item above 0205 462.05			

Mürrplastik markers for terminal blocks