
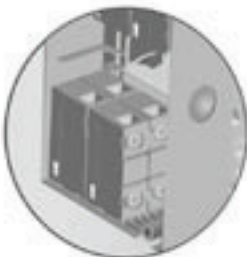


General Information

200A Fusible disconnect switches

600V, UL98

Disconnect
switches
Fusible

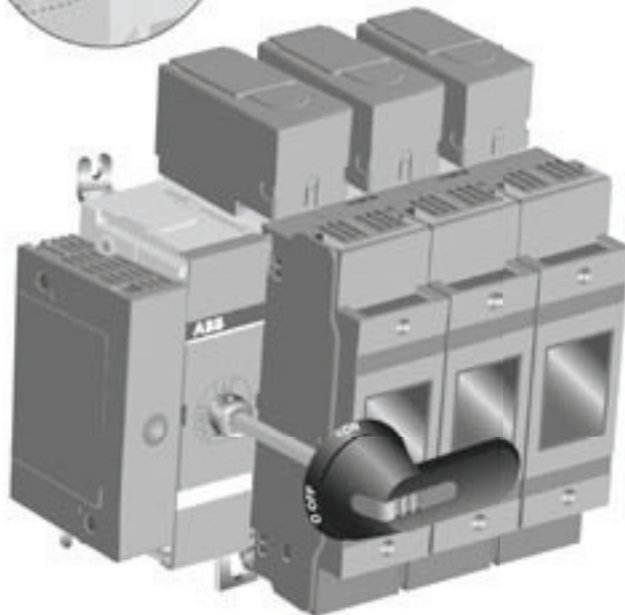

Installation

Fast, simple and easy to install. The shaft does not require precise cutting due to depth adjustability in the mechanism. Accessories, like auxiliary contacts and shrouds, can be snapped on without tools. The terminal positioning is optimally designed for double cabling, decreasing the space requirements. Two small cables allow easier bending thereby simplifying the mounting. The adjustable mounting feet provide mounting flexibility for the switch — they can be mounted both vertically and horizontally.

Electrical Characteristics

The high short circuit capacity guarantees reliable current cut-off up to 100kA and the fusible switch can be enclosed up to the full ratings.

Finger Safe

The control cables are well protected in covered cable channels. The terminal connections may be shrouded, and the fuse covers are interlocked in the ON position, achieving an overall IP30 protection level.

Reliable isolation

The double breaking contacts isolate the fuses on both sides eliminating the risk of back feeds and creating a safe environment to change the fuses in the OFF position.

This patented contact construction is magnetized by the short-circuit current. The higher the current, the more powerful the magnetic pulling effect, thus keeping the contacts closed and achieving superior withstand ratings.

International acceptance

UL listed, CSA approved, IEC rated, CE marked, and meets most other international standards.

UL98 (CSA C22.2 No.4)
UL File # E101914

200A Fusible disconnect switches 600V, UL98

For a complete assembly,
please select one of each:

- 1 Switch
- 1 Handle
- 1 Shaft
- 1 Terminal lug kit



OS200J03




OHB80J6



OXP6X130



OZXA-200

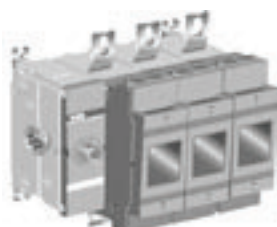

OS200J03



OHB80J6



OXP6X130

200A Fusible disconnect switches, 600V, UL98

UL general purpose amp rating	UL fuse type 600V, UL98	Maximum horsepower rating				Poles	Delivery class	Catalog number	List price
		Three phase							
		200/208V	240V	480V	600V				
200	J	--	--	--	--	1	B	OS200J01	\$ 1120
200	J	--	--	--	--	2	B	OS200J02 OS200J11	1240
200	J	50	60	125	150	3	A B	OS200J03 OS200J12	1380
200	J	50	60	125	150	4	B	OS200J04 OS200J13 OS200J22	1725

200A Fusible disconnect switch kit, 600V

UL general purpose amp rating	Kit components	Delivery class	Catalog number	List price
200	OS200J03, OHB80J6, OXP6X290, OZXA-200	A	OSKJ200B8-290	\$ 1566

Pistol grip handles

For use with:	Padlock- able	Defeat- able	Mark- ing	Color	Nema rating	Shaft dia. (mm)	Delivery class	Catalog number	List price
OS200_	Yes	Yes	O/I & Off/On	Black Red/Yel Black Red/Yel	1, 3R & 12 1, 3R & 12 4, 4X 4, 4X	6	A	OHB80J6 OHY80J6 OHB80L6 OHY80L6	\$ 90 90 130 130

Shafts—for use with pistol grip handles

For use with:	Length in / mm	Square in / mm	Mounting depth ^① in inches	Weight lbs	Delivery class	Catalog number	List price
OS200_	5.1 / 130	0.23 / 6	4.3 - 6.5	0.08	A	OXP6X130	\$ 12
	5.9 / 150		5.0 - 7.2	0.10		OXP6X150	12
	8.3 / 210		7.4 - 9.6	0.13		OXP6X210	16
	11.4 / 290		10.5 - 12.7	0.18		OXP6X290	20
	14.2 / 360		13.3 - 15.5	0.23		OXP6X360	24
	16.9 / 430		16 - 18.2	0.28		OXP6X430	28


Delivery Classes

- A - Standard Item, stock to 2 weeks lead time
- B - Stock to 4 weeks lead time
- C - 6 to 8 week lead time

① Mounting depth is the distance from the outside of the door to the disconnect switch mounting plate. Shaft can be cut to desired length.

200A Fusible disconnect switches 600V, UL98

Disconnect
switches
Fusible

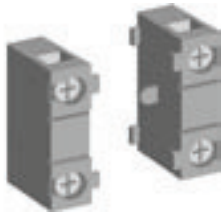

OA1G10
OA3G01



OEA28



OZXA-200



OSS200G1L/3



OSS200G1S/3



OHZX10

Auxiliary contacts blocks

Mounting on the left side of the switch :Max 8 auxilliary contact blocks with the **OEA28 module**

Mounting under the mechanism cover: Max 4 auxilliary contact blocks

Function	Protection degree	Weight lbs	Delivery class	Catalog number	List price
1 NO 1 NC	IP20	0.07	A	OA1G10 OA3G01	\$ 20

Module for auxilliary contacts

Description	Weight lbs	Delivery class	Catalog number	List price
Screw mounting to the left side of the switch	0.1	A	OEA28	\$ 50

Terminal lug kits

For use on	Wire size	Wire type	Description	Lugs /kit	Delivery class	Catalog number	List price
OS200_	#4 - 300kcmil	Cu /Al	—	6	A	OZXA-200	\$ 80
	#4 - 300kcmil		—	3		OZXA-200/3P	40
	(6) 14-6 AWG		Distribution lug	3		OZXA-206	180

Terminal shrouds

Snap-on mounting, grey plastic, IP3X Transparent shrouds available on request.

Includes 3 shrouds for either line or load side

For use with:	Description	Number of poles	Weight lbs	Delivery class	Catalog number	List price
OS200_	Long type	3	0.20	A	OSS200G1L/3	\$ 50
	Short type	3	0.13	A	OSS200G1S/3	50
	Long type	4	0.26	A	OSS200G1L/4	65
	Short type	4	0.18	A	OSS200G1S/4	61

Shaft Guide

Description	Delivery class	Catalog number	List price
Fits all pistol grip handles, mounts on the inside of the enclosure door with provided hardware	A	OHZX10	\$ 12

Delivery Classes

A - Standard Item, stock to 2 weeks lead time
B - Stock to 4 weeks lead time
C - 6 to 8 week lead time