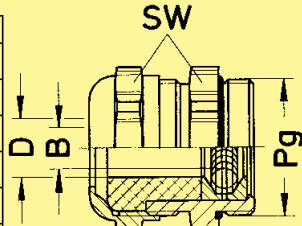
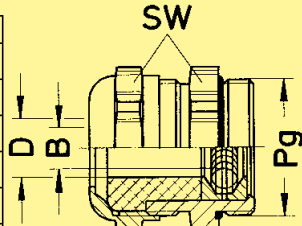
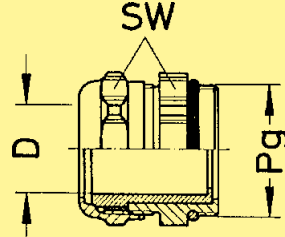
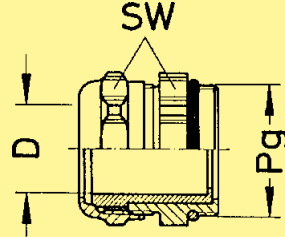
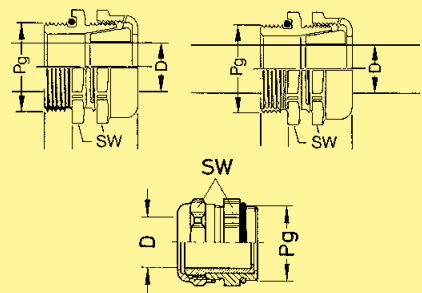
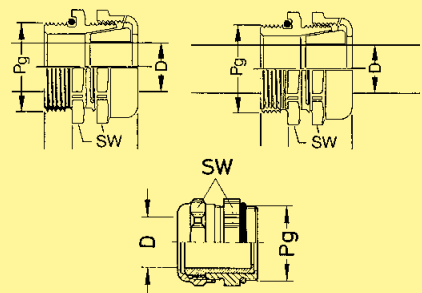


Cable entry protection with Pg cable entries

Identification	Part number	Pg	Drawing	Dimensions in mm																																																															
EMC clamp with Pg cable entries (IP 68) 	09 62 000 5023	11	<table><tr><th>SW</th><th>cable-Ø D</th><th>shield-Ø B</th></tr><tr><td>20</td><td>4 ... 6.5</td><td>2.5 ... 6.5</td></tr><tr><td>20</td><td>6.5 ... 9.5</td><td>3.5 ... 8.5</td></tr><tr><td>22</td><td>8 ... 10.5</td><td>6.5 ... 10.5</td></tr><tr><td>22</td><td>6.5 ... 9.5</td><td>2.5 ... 6.5</td></tr><tr><td>22</td><td>9 ... 13</td><td>6.5 ... 10.5</td></tr><tr><td>24</td><td>6.5 ... 9.5</td><td>3.5 ... 8</td></tr><tr><td>24</td><td>9 ... 13</td><td>4.5 ... 8</td></tr><tr><td>30</td><td>11.5 ... 15.5</td><td>9.5 ... 13.5</td></tr><tr><td>30</td><td>14 ... 18</td><td>10.5 ... 14.5</td></tr><tr><td>40</td><td>17 ... 20.5</td><td>15 ... 20</td></tr><tr><td>40</td><td>20 ... 25</td><td>15 ... 20</td></tr><tr><td>50</td><td>24 ... 28</td><td>18 ... 25.5</td></tr><tr><td>50</td><td>27 ... 32</td><td>24 ... 31</td></tr></table> 	SW	cable-Ø D	shield-Ø B	20	4 ... 6.5	2.5 ... 6.5	20	6.5 ... 9.5	3.5 ... 8.5	22	8 ... 10.5	6.5 ... 10.5	22	6.5 ... 9.5	2.5 ... 6.5	22	9 ... 13	6.5 ... 10.5	24	6.5 ... 9.5	3.5 ... 8	24	9 ... 13	4.5 ... 8	30	11.5 ... 15.5	9.5 ... 13.5	30	14 ... 18	10.5 ... 14.5	40	17 ... 20.5	15 ... 20	40	20 ... 25	15 ... 20	50	24 ... 28	18 ... 25.5	50	27 ... 32	24 ... 31																						
	SW	cable-Ø D		shield-Ø B																																																															
	20	4 ... 6.5		2.5 ... 6.5																																																															
	20	6.5 ... 9.5		3.5 ... 8.5																																																															
	22	8 ... 10.5		6.5 ... 10.5																																																															
	22	6.5 ... 9.5		2.5 ... 6.5																																																															
	22	9 ... 13		6.5 ... 10.5																																																															
	24	6.5 ... 9.5		3.5 ... 8																																																															
	24	9 ... 13		4.5 ... 8																																																															
	30	11.5 ... 15.5		9.5 ... 13.5																																																															
	30	14 ... 18		10.5 ... 14.5																																																															
	40	17 ... 20.5		15 ... 20																																																															
	40	20 ... 25		15 ... 20																																																															
	50	24 ... 28		18 ... 25.5																																																															
	50	27 ... 32		24 ... 31																																																															
09 62 000 5024	11																																																																		
09 62 000 5025	11																																																																		
09 62 000 5003	13.5																																																																		
09 62 000 5004	13.5																																																																		
09 62 000 5005	16																																																																		
09 62 000 5006	16																																																																		
09 62 000 5007	21																																																																		
09 62 000 5008	21																																																																		
09 62 000 5009	29																																																																		
09 62 000 5010	29																																																																		
09 62 000 5011	36																																																																		
09 62 000 5012	36																																																																		
Universal cable gland Pg (IP 68) Metal 	09 00 000 5080	11	<table><tr><th>Colour</th><th>SW</th><th>cable-Ø D</th></tr><tr><td>grey</td><td>20</td><td>5 ... 8</td></tr><tr><td>black</td><td>20</td><td>6.5 ... 9.5</td></tr><tr><td>green</td><td>20</td><td>7 ... 10.5</td></tr><tr><td>black</td><td>22</td><td>6.5 ... 9.5</td></tr><tr><td>green</td><td>22</td><td>7 ... 10.5</td></tr><tr><td>red</td><td>22</td><td>9 ... 13</td></tr><tr><td>black</td><td>24</td><td>6.5 ... 9.5</td></tr><tr><td>green</td><td>24</td><td>7 ... 10.5</td></tr><tr><td>red</td><td>24</td><td>9 ... 13</td></tr><tr><td>white</td><td>24</td><td>11.5 ... 15.5</td></tr><tr><td>green</td><td>30</td><td>7 ... 10.5</td></tr><tr><td>red</td><td>30</td><td>9 ... 13</td></tr><tr><td>white</td><td>30</td><td>11.5 ... 15.5</td></tr><tr><td>blue</td><td>30</td><td>14 ... 18</td></tr><tr><td>blue</td><td>40</td><td>14 ... 18</td></tr><tr><td>brown</td><td>40</td><td>17 ... 21</td></tr><tr><td>orange</td><td>40</td><td>20 ... 25</td></tr><tr><td>light yellow</td><td>40</td><td>24 ... 28</td></tr><tr><td>light blue</td><td>50</td><td>29 ... 34</td></tr><tr><td>pink</td><td>50</td><td>32 ... 36</td></tr></table> 	Colour	SW	cable-Ø D	grey	20	5 ... 8	black	20	6.5 ... 9.5	green	20	7 ... 10.5	black	22	6.5 ... 9.5	green	22	7 ... 10.5	red	22	9 ... 13	black	24	6.5 ... 9.5	green	24	7 ... 10.5	red	24	9 ... 13	white	24	11.5 ... 15.5	green	30	7 ... 10.5	red	30	9 ... 13	white	30	11.5 ... 15.5	blue	30	14 ... 18	blue	40	14 ... 18	brown	40	17 ... 21	orange	40	20 ... 25	light yellow	40	24 ... 28	light blue	50	29 ... 34	pink	50	32 ... 36	
	Colour	SW		cable-Ø D																																																															
	grey	20		5 ... 8																																																															
	black	20		6.5 ... 9.5																																																															
	green	20		7 ... 10.5																																																															
	black	22		6.5 ... 9.5																																																															
	green	22		7 ... 10.5																																																															
	red	22		9 ... 13																																																															
	black	24		6.5 ... 9.5																																																															
	green	24		7 ... 10.5																																																															
	red	24		9 ... 13																																																															
	white	24		11.5 ... 15.5																																																															
	green	30		7 ... 10.5																																																															
	red	30		9 ... 13																																																															
	white	30		11.5 ... 15.5																																																															
	blue	30		14 ... 18																																																															
	blue	40		14 ... 18																																																															
	brown	40		17 ... 21																																																															
	orange	40		20 ... 25																																																															
	light yellow	40		24 ... 28																																																															
	light blue	50		29 ... 34																																																															
	pink	50		32 ... 36																																																															
	09 00 000 5081	11																																																																	
	09 00 000 5082	11																																																																	
	09 00 000 5083	13.5																																																																	
	09 00 000 5084	13.5																																																																	
	09 00 000 5085	13.5																																																																	
	09 00 000 5086	16																																																																	
	09 00 000 5087	16																																																																	
	09 00 000 5088	16																																																																	
09 00 000 5089	16																																																																		
09 00 000 5090	21																																																																		
09 00 000 5091	21																																																																		
09 00 000 5092	21																																																																		
09 00 000 5093	21																																																																		
09 00 000 5094	29																																																																		
09 00 000 5095	29																																																																		
09 00 000 5096	29																																																																		
09 00 000 5097	29																																																																		
09 00 000 5098	36																																																																		
09 00 000 5099	36																																																																		
Cable entry protection with Pg cable entries (IP 68) Metal  Thermoplastic  Thermoplastic 	09 00 000 5183	11	<table><tr><th>SW</th><th>cable-Ø D</th></tr><tr><td>21</td><td>7 ... 12</td></tr><tr><td>24</td><td>7 ... 12</td></tr><tr><td>33</td><td>13 ... 18</td></tr></table> 	SW	cable-Ø D	21	7 ... 12	24	7 ... 12	33	13 ... 18																																																								
	SW	cable-Ø D																																																																	
	21	7 ... 12																																																																	
24	7 ... 12																																																																		
33	13 ... 18																																																																		
09 00 000 5182	11																																																																		
09 00 000 5153	21																																																																		

Stock items in bold type