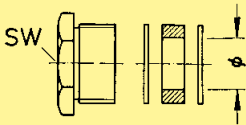
 
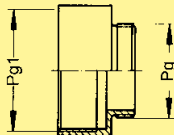
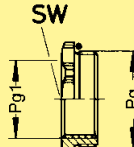
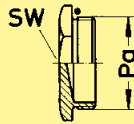


Identification	Part number	Pg	Drawing	Dimensions in mm																				
Cable gland (IP 65) Thermoplastic with normal seal	grey 09 00 000 5164 black 09 00 000 5185	11 11	<table><tr><th>SW</th><th> cable-Ø D</th></tr><tr><td>19</td><td>10 ... 12</td></tr><tr><td>19</td><td>10 ... 12</td></tr></table>	SW	cable-Ø D	19	10 ... 12	19	10 ... 12															
SW	cable-Ø D																							
19	10 ... 12																							
19	10 ... 12																							
Cable gland (IP 65) Metal with multiple seal	09 00 000 5013 09 00 000 5014 09 00 000 5015 09 00 000 5016 09 00 000 5017 09 00 000 5018 09 00 000 5019	11 13.5 16 21 29 36 42	<table><tr><th>SW</th><th> cable-Ø D</th></tr><tr><td>18</td><td>6.5 ... 12</td></tr><tr><td>20</td><td>6.5 ... 13.5</td></tr><tr><td>22</td><td>6.5 ... 16</td></tr><tr><td>28</td><td>9 ... 20</td></tr><tr><td>37</td><td>17 ... 28</td></tr><tr><td>47</td><td>23 ... 34</td></tr><tr><td>54</td><td>29 ... 40</td></tr></table>	SW	cable-Ø D	18	6.5 ... 12	20	6.5 ... 13.5	22	6.5 ... 16	28	9 ... 20	37	17 ... 28	47	23 ... 34	54	29 ... 40					
SW	cable-Ø D																							
18	6.5 ... 12																							
20	6.5 ... 13.5																							
22	6.5 ... 16																							
28	9 ... 20																							
37	17 ... 28																							
47	23 ... 34																							
54	29 ... 40																							
Increasesers for Pg cable entries Metal	09 00 000 5050 09 00 000 5051 09 00 000 5052 09 00 000 5053 09 00 000 5054 09 00 000 5055 09 00 000 5056	11 13.5 16 21 29 36 42 48	<table><tr><th>Pg1</th></tr><tr><td>13.5</td></tr><tr><td>16</td></tr><tr><td>21</td></tr><tr><td>29</td></tr><tr><td>36</td></tr><tr><td>42</td></tr><tr><td>48</td></tr></table>	Pg1	13.5	16	21	29	36	42	48													
Pg1																								
13.5																								
16																								
21																								
29																								
36																								
42																								
48																								
Reducers for Pg cable entries Metal	09 00 000 5060 09 00 000 5061 09 00 000 5062 09 00 000 5063 09 00 000 5064 09 00 000 5065 09 00 000 5066 09 00 000 5067 09 00 000 5068	11 11 13.5 13.5 16 21 21 29 29	<table><tr><th>SW</th><th>Pg1</th></tr><tr><td>20</td><td>7</td></tr><tr><td>20</td><td>9</td></tr><tr><td>22</td><td>9</td></tr><tr><td>22</td><td>11</td></tr><tr><td>24</td><td>13.5</td></tr><tr><td>30</td><td>13.5</td></tr><tr><td>30</td><td>16</td></tr><tr><td>40</td><td>16</td></tr><tr><td>40</td><td>21</td></tr></table>	SW	Pg1	20	7	20	9	22	9	22	11	24	13.5	30	13.5	30	16	40	16	40	21	
SW	Pg1																							
20	7																							
20	9																							
22	9																							
22	11																							
24	13.5																							
30	13.5																							
30	16																							
40	16																							
40	21																							
Blanking piece for Pg cable entries Metal	09 00 000 5070 09 00 000 5071 09 00 000 5072 09 00 000 5073 09 00 000 5074 09 00 000 5075	11 13.5 16 21 29 36	<table><tr><th>SW</th></tr><tr><td>20</td></tr><tr><td>22</td></tr><tr><td>24</td></tr><tr><td>30</td></tr><tr><td>40</td></tr><tr><td>50</td></tr></table>	SW	20	22	24	30	40	50														
SW																								
20																								
22																								
24																								
30																								
40																								
50																								
Adapter Han® 3 A for motor connection	09 20 000 9962	13.5																						