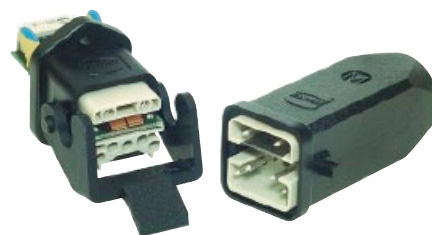

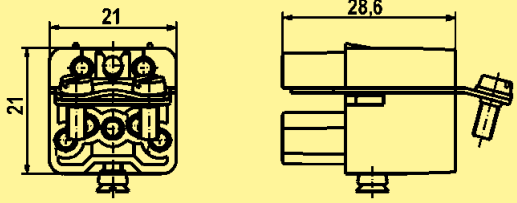
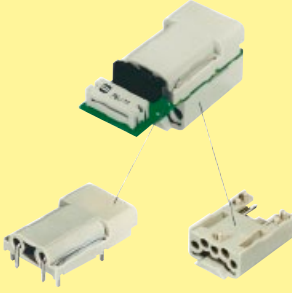
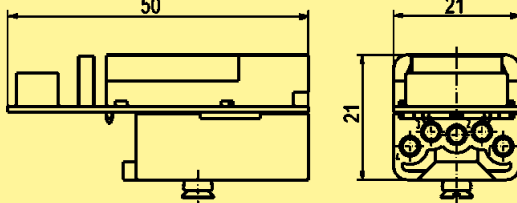

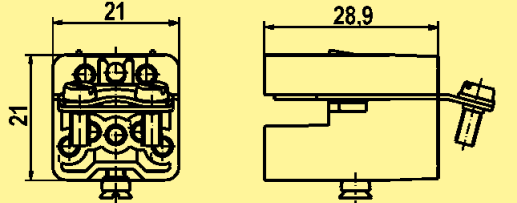
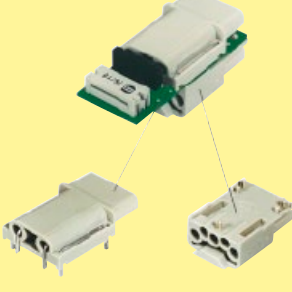
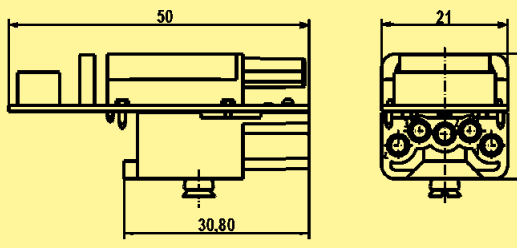


Hybrid field bus connector  
for shielded twisted pair  
+ 4 electrical contacts 10 A  
+ option for PE



Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
<b>Cable side</b> Female insert 		<b>09 12 006 3111</b>	 view from termination side	
<b>Device side</b> Male insert 	09 12 006 2611  Also available as single part  loaded 09 12 002 2611 unloaded 09 12 002 3011 unloaded 09 12 004 3011			
<b>Cable side</b> Male insert 	<b>09 12 006 3001</b>		 view from termination side	
<b>Device side</b> Female insert 		<b>09 12 006 2701</b>  Also available as single part  loaded 09 12 002 2701 unloaded 09 12 002 3101 unloaded 09 12 004 3101		

Stock items in bold type