
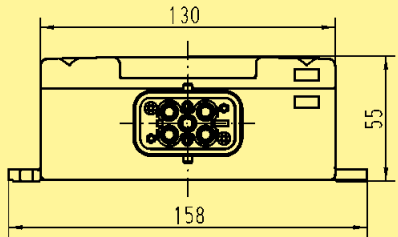
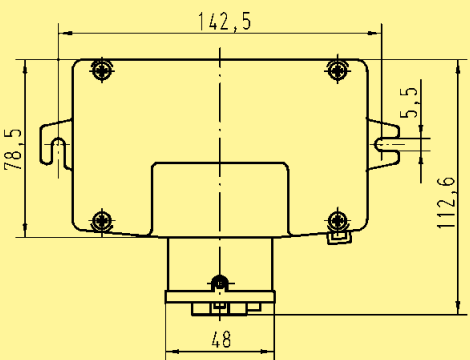


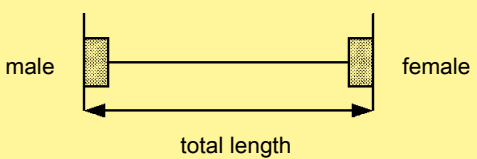

with 1x Han® Q 4/2

| Identification                                                                                                                                                                                                                          | Part number           | Drawing                                                                              | Dimensions in mm |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------------|--------------------------------------------------------------------------------------|------------------|
| <b>Han-Power® S</b><br>Power supply<br>Han® Q 4/2; 1 moulded<br>Han-Compact® Hoods                                                                                                                                                      |                       |                                                                                      |                  |
| 2.5 - 4 mm²                                                                                                                                                                                                                             | <b>09 12 008 4804</b> |    |                  |
| 4 - 6 mm²                                                                                                                                                                                                                               | <b>09 12 008 4806</b> |   |                  |
| Identification                                                                                                                                                                                                                          | Part number           | Drawing                                                                              | Dimensions in mm |
| <b>System cables in fixed lengths</b><br>Cable lengths (total length) in m<br>pre-assembled on both sides<br>plastic hood, black<br>top entry<br>cable to cable hood with male insert<br>and hood with female insert<br>cable: 5x 4 mm² |                       |                                                                                      |                  |
| 1.5                                                                                                                                                                                                                                     | <b>20 88 641 1015</b> |                                                                                      |                  |
| 3                                                                                                                                                                                                                                       | <b>20 88 641 1030</b> |                                                                                      |                  |
| 5                                                                                                                                                                                                                                       | <b>20 88 641 1050</b> |                                                                                      |                  |
| 10                                                                                                                                                                                                                                      | <b>20 88 641 1100</b> |                                                                                      |                  |
| 15                                                                                                                                                                                                                                      | <b>20 88 641 1150</b> |                                                                                      |                  |
| 30                                                                                                                                                                                                                                      | <b>20 88 641 1300</b> |                                                                                      |                  |
|                                                                                                                                                                                                                                         |                       |  |                  |